

## FS/FD Mount Weatherproof Covers

For strap mount and flanged devices in FD box and panel mount applications



Available in gray,  
black or yellow

### Features & Benefits

- Vertical self-closing lid constructed of glass-filled thermoplastic provides ultimate impact resistance for use in abusive environments
- Includes provision for 2 padlocks for OSHA compliant lockout/tagout
- Molded-in label area on cover allows for circuit or ratings identification
- Pre-assembled gasket provides an easier installation and tighter seal from harsh elements
- Stainless steel mounting screws and springs offer added corrosion resistance
- NEMA Type 3R and IP64 ratings with cover closed ensure protection for indoor and outdoor use
- Covers may be held open with a Hex Key or pin to ease installation

### Common Applications

- Portable Generators
- Shipyards & Marinas
- Power Distribution Boxes
- Construction Sites
- Carnivals & Fairs

## Key Features



Provisions for lockout/tagout for OSHA compliance



Convenient space for circuit id label



Pre-mounted flange gasket speeds installation\*



Stay open feature makes installation simple

### 7420

Fits 20A & 30A strap mount single locking receptacles



### WP1

Fits 15A locking flanged inlets & outlets and 15A/20A straight blade flanged inlets & outlets



### WP2

Fits 20A/30A locking flanged inlets & outlets, and 30A/50A power receptacles




### WP3

Fits 50A non-NEMA flanged inlets & outlets for applications where mounting of the device is behind the panel



### WP4

Fits 50A non-NEMA flanged inlets & outlets for applications where mounting of the device is in front of the panel

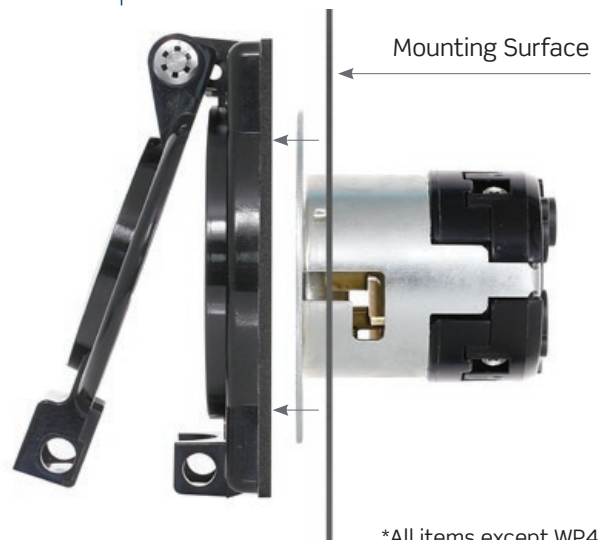

\*All items except WP4

## Ordering Information

Description	Color	Diameter Opening	Cat No
For 20 amp or 30 amp strap-mount single flush mount receptacle	Yellow	1.60"	7420-YL
	Gray		7420-G
	Black		7420-EB
For 3-wire 15 amp and 20 amp straight blade or 15 amp locking flanged outlets or inlets	Yellow	1.72"	WP1-YL
	Gray		WP1-G
	Black		WP1-EB
For 3-, 4- or 5-wire 20 amp or 30 amp locking flanged inlets or outlets	Yellow	2.25"	WP2-YL
	Gray		WP2-G
	Black		WP2-EB
For 50 amp flanged inlets and outlets mounted from behind the panel with 2.6" panel cutout	Yellow	3"	WP3-YL
	Gray		WP3-G
	Black		WP3-EB
For 50 amp flanged inlets and outlets mounted from in front of the panel with 2.6" panel cutout	Yellow	2.6"	WP4-YL
	Gray		WP4-G
	Black		WP4-EB


## Specifications

Description	WP1, WP2, WP3, 7420-CR	WP4
<b>Material Specifications</b>		
Cover Plate	Glass-Filled Thermoplastic	
Mounting Screws & Springs	Stainless Steel	
<b>Standards &amp; Certifications</b>		
UL Standard	UL514C & UL514D	UL498
CSA	C22.2 No. 18.1 and/or 42.1	
NEMA	Type 3R	
RoHS	Compliant	
IP Rating	IP64	
<b>Guarantees</b>		
Product Warranty	10 Year Limited	




## Dimensions

### WP1, WP2, WP3, 7420

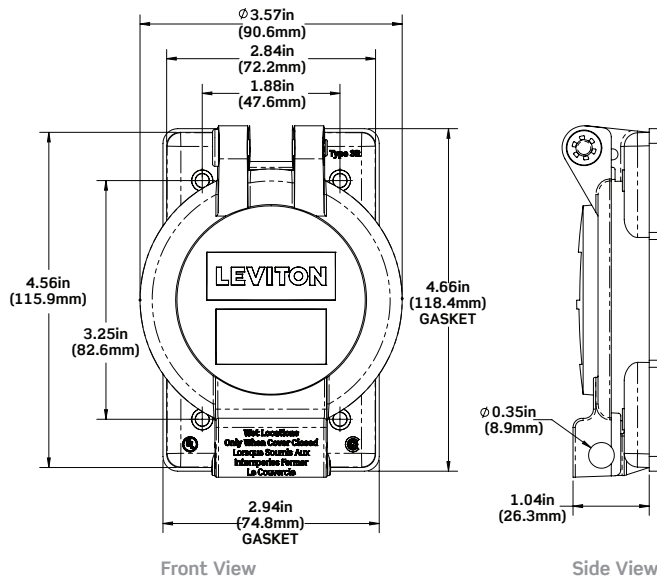

### WP4

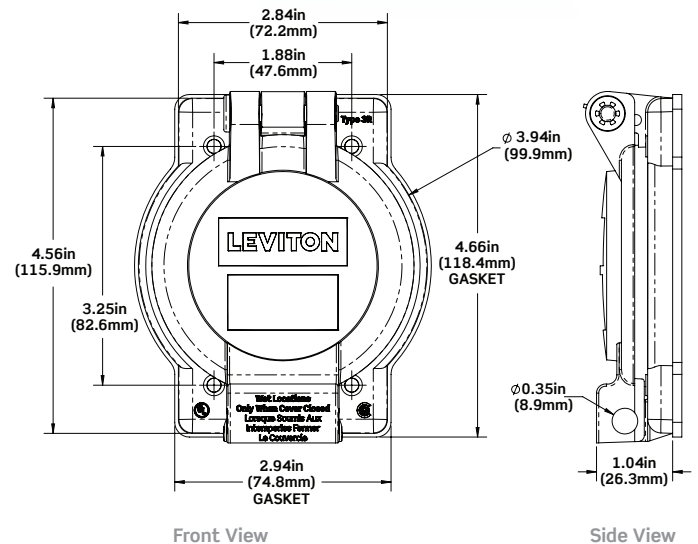

## Also Available

For use with 50A single locking receptacles



## Ordering Information


Description	Color	Diameter Opening	Cat No
1-Gang device cover for 50A locking receptacles	Yellow Thermoplastic	2.15"	7788-CR
	Gray Aluminum		7770

## Specifications

Description	7770	7788-CR
<b>Material Specifications</b>		
Cover Plate	Powder Coat Cast Aluminum	Glass-Filled Thermoplastic
Mounting Screws & Springs	Stainless Steel	
<b>Standards &amp; Certifications</b>		
UL Standard	UL514C & UL514D	
CSA	C22.2 No. 18.1 and/or 42.1	
NEMA	Type 3R	
RoHS	Compliant	
IP Rating	IP64	
<b>Guarantees</b>		
Product Warranty	10 Year Limited	

## Dimensions

7770 & 7788-CR

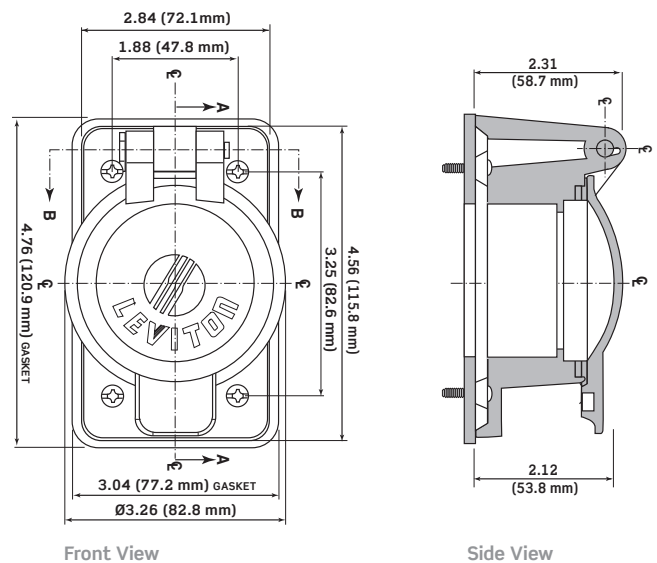

Visit our Website at:  
[www.leviton.com/industrial](http://www.leviton.com/industrial)  
 email: [industrial@leviton.com](mailto:industrial@leviton.com)

Q-936A

### Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747  
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538  
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2017 Leviton Manufacturing Co., Inc. All rights reserved.

040717

