



# ORDER FORM

## Dockhead DH2 Large Power Outlet Box

### 10" X 12" POWER OUTLET BOX FOR MARINE:

- Preassembled with distribution block, wiring devices with weather-resistant covers, and front and bottom LED lights
- Allows up to 4 wiring devices (see locations A, B, C, D per diagram on next page)
- Can be ordered with or without stand

### CONSTRUCTION:

- Polycarbonate housing

### STANDARDS:

- NEMA 3R, UL-231, CSA 22.2 No. 29, NFPA 303, NFPA 70

### WARRANTY:

- Housing: 5 years
- Wiring Devices: 1 year



DATE: \_\_\_\_\_

JOB NAME: \_\_\_\_\_

DISTRIBUTOR NAME & ACCOUNT NUMBER: \_\_\_\_\_

CITY: \_\_\_\_\_

STATE: \_\_\_\_\_

ZIP: \_\_\_\_\_

PO NUMBER: \_\_\_\_\_

CONTACT NAME: \_\_\_\_\_

EMAIL: \_\_\_\_\_

PHONE: \_\_\_\_\_

LEVITON SALES PERSON: \_\_\_\_\_



Visit our Website at:  
[www.leviton.com/powerpedestals](http://www.leviton.com/powerpedestals)  
 email: [industrial@leviton.com](mailto:industrial@leviton.com)  
 Q-1491B 121523

**Leviton Manufacturing Co., Inc.**  
 201 N Service Rd, Melville, NY 11747  
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538  
 Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)  
 © 2024 Leviton Manufacturing Co., Inc. All rights reserved.

**ORDERING NUMBER:**

Ordering example: DH2-20S-20S-30S-20S-W-A-SD-W0-DE1-SE1



DH2 - - - - - 1 2 3 4 5 6 7 8 9 10 11 12 13 14

1	MODEL
DH2	<b>Dockhead 10" x 12" Base Unit</b> Includes Box and LED Clear or Amber with Front and Bottom Lens

2	RECEPTACLE/BREAKER Device Location A
RO	No Receptacle
20S	20A GFI Recept. w/Std. Brkr.
30S	30A (125V) Recept. w/Std. Brkr.
30E	30A (125V) Recept. w/30mA EPD Brkr.
50S	50A (125V) Recept. w/Std. Brkr.
50E	50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.)
50S2	50A (125/250V) Recept. w/Std. Brkr.
50E2	50A (125/250V) Recept. w/30mA EPD Brkr.
CO	Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White)
C5	CAT5 Internet Conn.

3	RECEPTACLE/BREAKER Device Location B
RO	No Receptacle
20S	20A GFI Recept. w/Std. Brkr.
30S	30A (125V) Recept. w/Std. Brkr.
30E	30A (125V) Recept. w/30mA EPD Brkr.
50S	50A (125V) Recept. w/Std. Brkr.
50E	50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.)
50S2	50A (125/250V) Recept. w/Std. Brkr.
50E2	50A (125/250V) Recept. w/30mA EPD Brkr.
CO	Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White)
C5	CAT5 Internet Conn.

4	RECEPTACLE/BREAKER Device Location C
RO	No Receptacle
20S	20A GFI Recept. w/Std. Brkr.
30S	30A (125V) Recept. w/Std. Brkr.
30E	30A (125V) Recept. w/30mA EPD Brkr.
50S	50A (125V) Recept. w/Std. Brkr.
50E	50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.)
50S2	50A (125/250V) Recept. w/Std. Brkr.
50E2	50A (125/250V) Recept. w/30mA EPD Brkr.
CO	Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White)
C5	CAT5 Internet Conn.

5	RECEPTACLE/BREAKER Device Location D
RO	No Receptacle
20S	20A GFI Recept. w/Std. Brkr.
30S	30A (125V) Recept. w/Std. Brkr.
30E	30A (125V) Recept. w/30mA EPD Brkr.
50S	50A (125V) Recept. w/Std. Brkr.
50E	50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.)
50S2	50A (125/250V) Recept. w/Std. Brkr.
50E2	50A (125/250V) Recept. w/30mA EPD Brkr.
CO	Cable Only Recept. Cvr - 1 Conn. (Only Available in White)
C5	CAT5 Internet Conn.

6	RECEPTACLE COVER COLOR
WH	White
B	Blue
GR	Green
T	Tan
GY	Gray
Y	Yellow

7	LED LIGHT COLOR
W	Clear White
A	Amber

8	BUS BAR
SD	Straight Distrib. Block
SPD	Single Phase Loop Distrib. Block
SPS	Single Phase Loop Studded Distrib. Block
T30	Three Phase Loop 300MCM Distrib. Block
T50	Three Phase Loop 350MCM Distrib. Block
SMS	Split Mini Straight Distrib. Blocks

9	STAND
ST0	No Stand
ST2	4 x 6 Stand - 2 Hangers

10	WATER HOOKUP TYPE*
W0	No Water
W11	3/4" 1/4 Turn Water Valve - QTY 1
W21	3/4" Water Valve w/Backflow Preventer - QTY 1
W31	1/2" 1/4 Turn Water Valve - QTY 1
W41	1/2" Water Valve w/Backflow Preventer - QTY 1
W12	3/4" 1/4 Turn Water Valve - QTY 2
W22	3/4" Water Valve w/Backflow Preventer - QTY 2
W32	1/2" 1/4 Turn Water Valve - QTY 2
W42	1/2" Water Valve w/Backflow Preventer - QTY 2

11	KILOWATT HOUR METERS Meter Location 1
M0	NONE
SE1	Single Element Meter - QTY 1
DE1	Dual Element Meter - QTY 1
SE2	Single Element Meter - QTY 2
DE2	Dual Element Meter - QTY 2
SE3	Single Element Meter - QTY 3
DE3	Dual Element Meter - QTY 3

12	KILOWATT HOUR METERS Meter Location 2
M0	NONE
SE1	Single Element Meter - QTY 1
DE1	Dual Element Meter - QTY 1
SE2	Single Element Meter - QTY 2
DE2	Dual Element Meter - QTY 2
SE3	Single Element Meter - QTY 3
DE3	Dual Element Meter - QTY 3


13	SPARE BREAKER OPTION 1**
B0	No Breaker
B1	20A 1-Pole Std. Breaker
B1GFI	20A 1-Pole GFI Breaker
B2	20A 2-Pole Std. Breaker
B2GFI	20A 2-Pole GFI Breaker
B3	30A 1-Pole Std. Breaker
B32	30A 2-Pole Std. Breaker
B32GFI	30A 2-Pole GFI Breaker
B5	50A 1-Pole Std. Breaker
B52	50A 2-Pole Std. Breaker
B52GFI	50A 2-Pole GFI Breaker

14	SPARE BREAKER OPTION 2**
B0	No Breaker
B1	20A 1-Pole Std. Breaker
B1GFI	20A 1-Pole GFI Breaker
B2	20A 2-Pole Std. Breaker
B2GFI	20A 2-Pole GFI Breaker
B3	30A 1-Pole Std. Breaker
B32	30A 2-Pole Std. Breaker
B32GFI	30A 2-Pole GFI Breaker
B5	50A 1-Pole Std. Breaker
B52	50A 2-Pole Std. Breaker
B52GFI	50A 2-Pole GFI Breaker

NOTES: \* Water Hookup Types can only be selected if Stand (ST2) is selected.  
If No Stand (ST0) is selected, Water Hookup Type should default to "W0" No Water.  
\*\* Spare breaker location will vary.

**QUANTITY:**

**NOTES:**

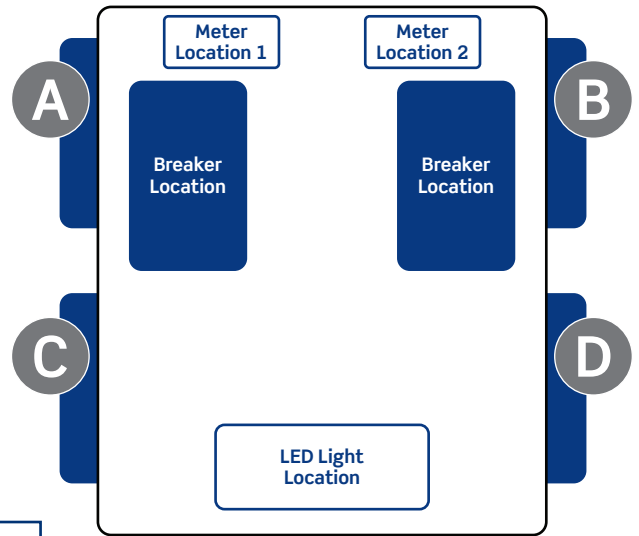

**CUSTOMER SIGNATURE**

(Indicates build approval)



With this signature the customer acknowledges being advised that these Made-To-Order pedestals are non-cancelable, non-refundable, and non-returnable.