

Lever Edge™


The Future of Wiring




Installation as easy as Push. Click. Done.

Leviton's **Lever Edge** wiring devices provide the classic appearance and superior performance of Decora® devices in a new, **easier-to-install, safe** design. In addition to the Single Pole Switch, 3-Way Switch, and Tamper-Resistant Duplex Receptacles, the line was expanded to include Tamper-Resistant and Weather-Resistant GFCIs and a Dimmer to meet customer demand. Innovative installation features such as color-coded lever terminals (including the ground terminal) for faster, efficient wiring, a larger strap with a unique tongue and groove alignment feature for quicker trim out on multi-gang installations, and no exposed metal parts for safety, make **Lever Edge** ideal for new home construction and MDU projects as well as retrofit applications.


Installers using **Lever Edge** will experience an installation process as unique as it is practical. The color-coded levers provide the foundation for quick installation by helping to rapidly identify the correct terminal for wiring, including a first of its kind lever terminal for the ground wire. The lever termination feature assures a positive connection has been made. This patented design also has a snap feature with an audible 'click' so installers can be confident with every termination.

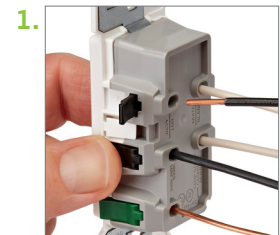

1. PUSH.
Faster and easier to wire

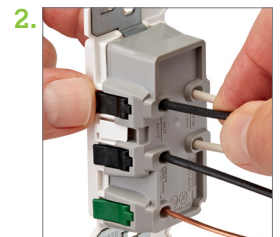


2. CLICK.
Audible 'click' confirms secure connection

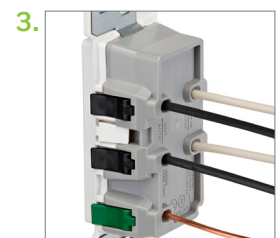

3. DONE.
Terminate with confidence

Expanded line to meet all your wiring needs.

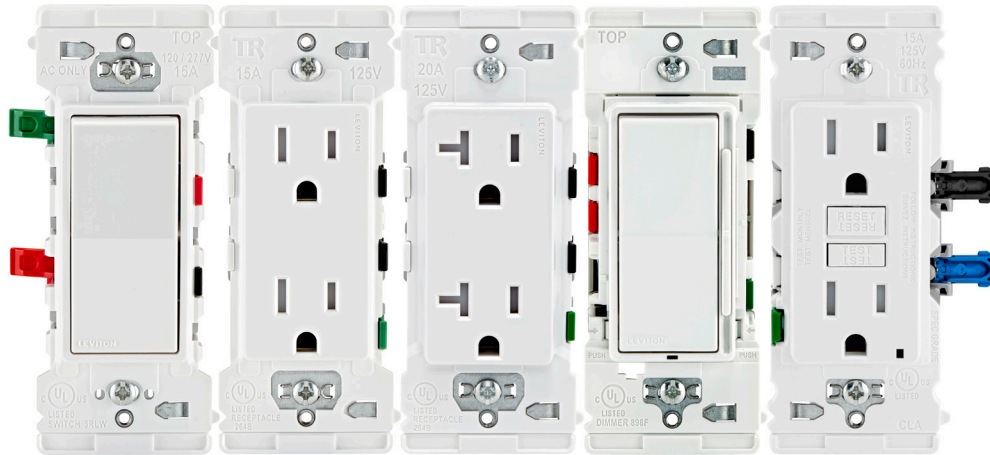

Lever Edge Installation Features:

- Color-coded lever terminals for fast, efficient wiring and reduces risk of miswiring
- Lever doors have snap feature to assure connection has been made; audible click confirms lever door is closed
- Only Residential device on the market with a quick termination ground wire
- No exposed metal parts for enhanced safety; eliminates need for electrical tape
- 15 Amp lever connectors work with 14 gauge and 12 gauge stranded and solid copper wire, 20 Amp works with 12 gauge and 10 gauge stranded and solid copper wire
- Wire openings prevent wire insulation from being inserted into the terminals
- One standard strip gauge for all devices
- Convenient test openings on switches, dimmer and GFCIs for circuit testers
- Receptacle allows for split circuit applications
- Strap's unique tongue and groove alignment offers quicker trim out on multi-gang installations
- Strap works with any sized wallplate
- Devices coordinate seamlessly with other Decora devices
- Can be used with Decora wallplates and Decora Plus™ screwless wallplates


GFCI

- Available in 15A Tamper-Resistant and Tamper/Weather-Resistant models
- Unique blue lever quickly identifies the Load Hot connection to minimize Line/Load Reversals
- Safety features include Self-Test and patented Reset Lockout
- Latest technology minimizes unwanted tripping in response to high-frequency noise from modern loads

Dimmer


- Superior dimming performance
- Designed for LED bulbs
- Works with existing wiring: No neutral required, single pole and 3-way capable
- Ideal for new and older homes
- Setup button to easily adjust settings such as dimming range, fade on, and kickstart
- Color change faceplates available



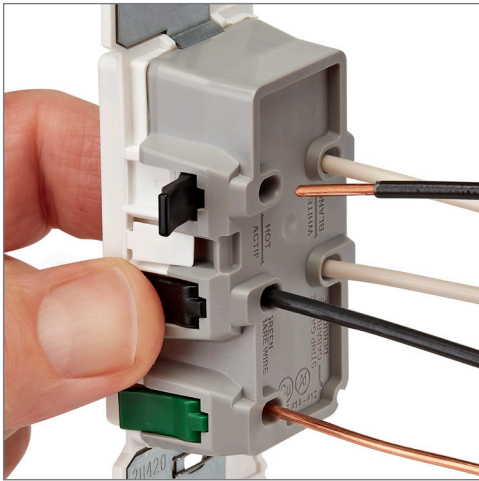


PUSH.

Faster and easier to wire

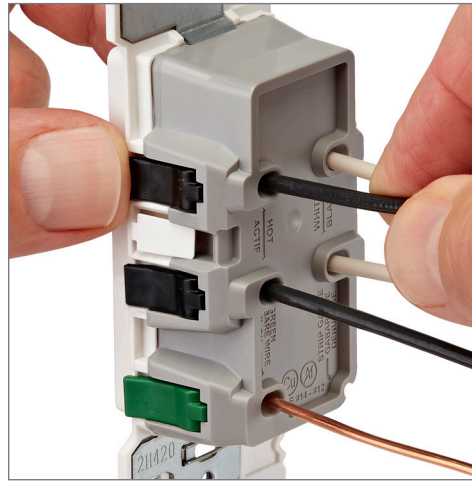


CLICK.

Audible 'click' confirms secure connection

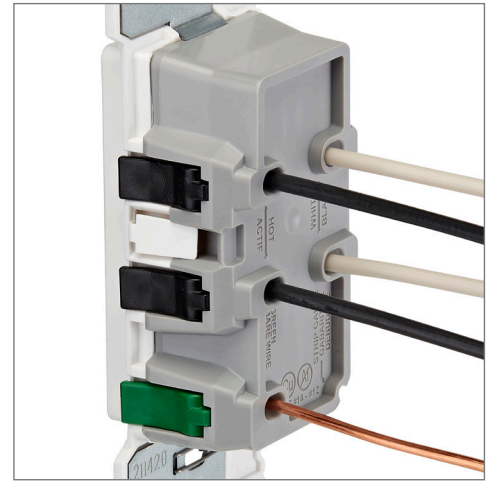

DONE.

Terminate with confidence

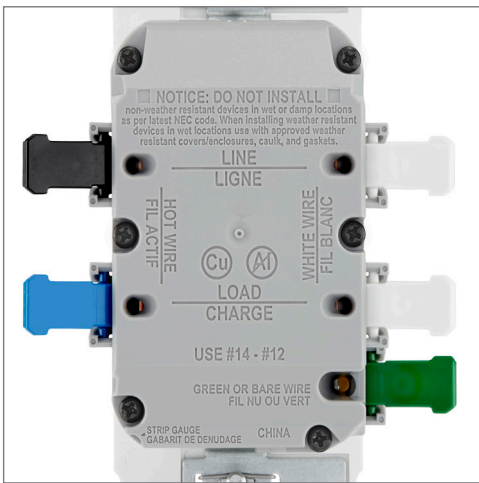


Color-coded lever terminals, including ground



15 Amp lever connectors work with 14 gauge and 12 gauge stranded and solid copper wire



No exposed metal parts for safer installations

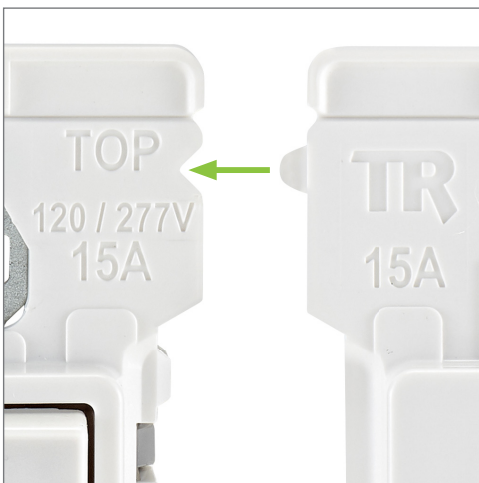

Strap's unique tongue and groove alignment feature offers quicker trim out on multi-gang installations



Large strap makes installations easier



Longer and wider strap is compatible with Midway wallplates, and with Standard sized wallplates when breakaway tab is removed

Ordering Information

Cat. No.	Description	Rating	Color
Receptacle			
EGFT1-W	15 Amp Tamper-Resistant GFCI Duplex Receptacle with LED Indicator (with self-grounding clip)	15 AMP, 125V	White
EGFW1-KW	15 Amp Weather/Tamper-Resistant GFCI Duplex Receptacle/ Outdoor Grade with LED Indicator	15 AMP, 125V	White
E5325	15 Amp Tamper-Resistant Duplex Receptacle	15 AMP, 125V	White
E5825	20 Amp Tamper-Resistant Duplex Receptacle	20 AMP, 125V	White
Switch			
E5601	Single Pole Switch	15 AMP, 120/277V	White
E5603	3-Way Switch	15 AMP, 120/277V	White
Dimmer			
ESL01-1LW	Decora Rocker Slide Dimmer	120VAC, 60Hz, 150W LED/CFL/INC	White



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am-5pm EST

For 24/7 product support visit www.leviton.com/support

Visit our Website at: www.leviton.com/leveredge

© 2025 Leviton Manufacturing Co., Inc. All rights reserved.
All trademarks are the property of their respective owners.



Scan to learn more.
leviton.com/LeverEdge