



CYLINDER LUMINAIRE FAMILY





Platform of flat-back cylinder luminaires designed to provide uniformity in form and function

- Sleek design with superior performance
- Multiple mounting styles for any application
- Wide range of wattage/lumen outputs, luminaire sizes, and beam distributions
- Specification grade performance TIR optics
- Field interchangeable optics within each fixture size to allow for changing environments



CEILING MOUNT

Mounts to a standard recessed junction box for downlighting applications; ideal for open floor plans



MONO-POINT

Precision aiming adjustment: 315° horizontal rotation and 90° vertical tilt; perfect for accent lighting



FLEXIBLE CABLE

Includes 48" of Field Adjustable Cable; impeccable over tables, bars, desks and islands



TRACK MOUNT

Versatile and flexible; excellent for highlighting merchandise in retail applications

AT A GLANCE

	CTL9050	CTL9051	CTL9052	CTL9053	CTL9054
WATTAGE	7W	9W	14W	20W	34W
LUMEN OUTPUT ¹	651Lm	1021Lm	1462Lm	2123Lm	3441Lm
DIMMING TYPE	INCANDESCENT, FORWARD PHASE				

1. Lumen values are approximate, see photometric test results

- Constructed of extruded and machined aluminum
- Single, high lumen output multi-chip LED array, available in 2700K, 3000K, 3500K and 4000K CCT; 90+ CRI
- Engineered TIR optics provide a smooth uniform beam, maximizing output and minimizing glare
- cETLus Certified to UL standards on base models; suitable for dry locations
- Many models are ENERGY STAR® Certified, can be used to comply with the 2019 Title 24 Part 6 JA8 High Efficacy LED Light Source Requirements and are DLC Listed for many models except CTL9054WF27CD, CTL9054WF3CD and CTL9054WF35CD
- Fixtures are covered by ConTech's full five (5) year replacement guarantee after date of purchase



ORDERING INFORMATION

System	Wattage/Lumens	Mounting	Beam	Color Temp	Options	Finish
CTL ² - ConTech	9050 - 7W/651Lm	- Leave Blank for Track Mount Luminaires	S ⁶ - Spot	90+ CRI	D - Dimming	B - Black
HTL ⁴ - Halo	9051 - 9W/1021Lm		M ⁷ - Medium	27C - 2700K		P - White
LTL ⁵ - Lightolier	9052 - 14W/1462Lm	CM - Ceiling Mount FC* - Flexible Cable MP - Mono-Point	F - Flood	3C - 3000K		S - Silver
NCTL - Nordic Tek Fixture includes 120V 2C/2N Adapter	9053 - 20W/2123Lm		WF - Wide Flood	35C - 3500K		
	9054 - 34W/3441Lm			4C - 4000K		

* Consult factory for longer cable drops, up to 96" (8 ft) maximum

Black Flex Cable luminaire provided with Black Fabric Cord, White luminaire with White Fabric Cord and Silver luminaire with Gray Fabric Cord

For Luminaire Accessories (Snoots, Barn Doors, Lenses and Louvers), Accessory Holders and Replacement Optics, see Product Specification Sheets

2. Standard ConTech track luminaires (CTL Units) are cCSAus certified as-is for use with ConTech Lighting LT/LT2 Single Circuit/Two Circuit Track Systems and Luxbeam Track Systems, as well as Juno^{®3} Lighting Trac-Master™ Systems.

By changing the prefix in the part number, ConTech can install inserts to make fixtures compatible with other manufacturers. For more information, please consult factory.

3. Juno is a registered trademark of Juno Lighting
4. Halo is a registered trademark of Cooper Lighting
5. Lightolier is a registered trademark of Signify
6. Spot Beam available only for CTL9050 Series
7. Medium Beam not available for CTL9050 Series



Platform of flat-back cylinder luminaires designed to provide uniformity in form and function




CEILING MOUNT



FLEXIBLE CABLE

48" Field Adjustable Cable Standard

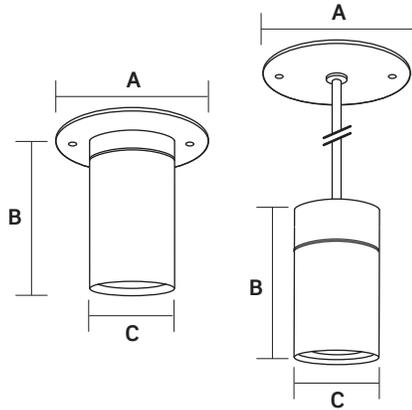


	A	B	C
CTL9050	4-3/4"	4-3/4"	2-3/8"
CTL9051	4-3/4"	5-1/4"	2-3/4"
CTL9052	4-3/4"	5-1/4"	2-3/4"
CTL9053	4-3/4"	6-1/8"	3-3/16"
CTL9054	4-3/4"	6-7/8"	3-15/16"



MONO-POINT



TRACK MOUNTING

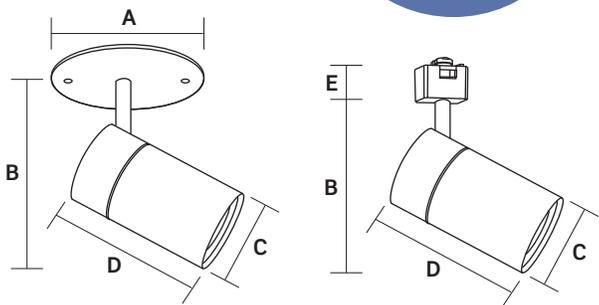

	A	B Min to Max	C	D	E
CTL9050	4-3/4"	3-11/32" to 5-1/8"	2-3/8"	4-3/4"	1"
CTL9051	4-3/4"	3-3/4" to 5-3/4"	2-3/4"	5-1/4"	1"
CTL9052	4-3/4"	3-3/4" to 5-3/4"	2-3/4"	5-1/4"	1"
CTL9053	4-3/4"	4-1/2" to 6-13/16"	3-3/16"	6-1/8"	1"
CTL9054	4-3/4"	5" to 7-7/8"	3-15/16"	6-7/8"	1"

