

# wayFLEX


Baffle Slim Downlights



Direct mount, slim profile downlight for installation flexibility and enhanced visual comfort

# wayFLEX

Baffle Slim Downlights

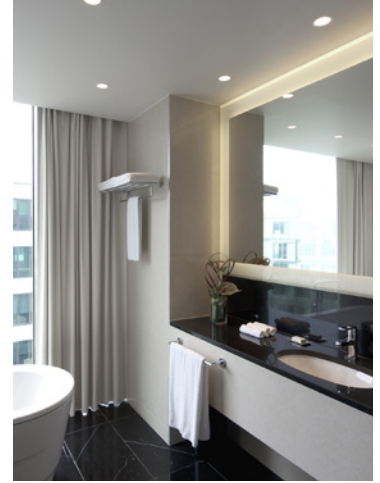

- Designed for a wide range of applications: Residential, Multi-Family, Hospitality, and Light Commercial spaces
- Can be used in Retrofit, Remodel or New Construction applications
- Five Color selectable CCT with 90+ CRI
- Die-cast regressed baffle trim provides enhanced visual comfort
- Slim design requires only a 2-inch plenum and eliminates the need for a recessed housing



selectable CCT



120V TRIAC dimming  
down to 10%

Edge-Lit optical system creates soft, uniformly lit surface

## Round Downlights




- 4-, 6- and 8-Inch Diameters
- Delivering between 900 and 1400 Lumens



## Square Downlights


- 4- and 6-Inch Squares
- Delivering between 850 and 1100 Lumens



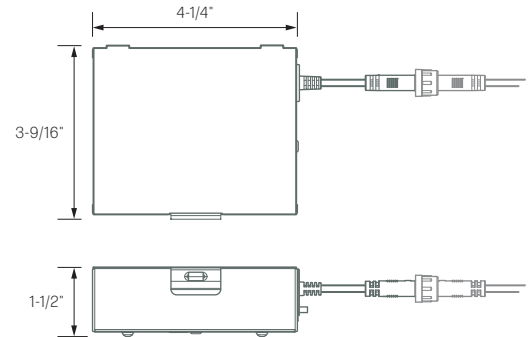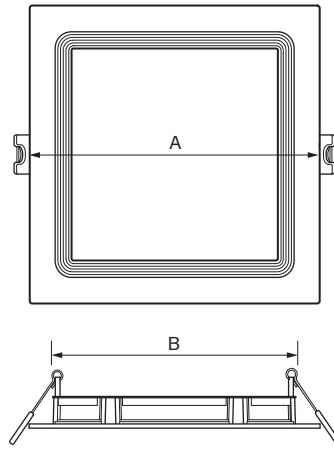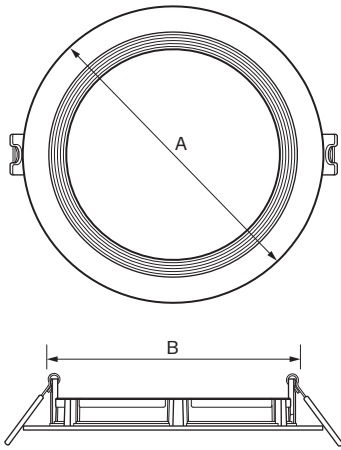

ROUND	A	B
<b>WFBR4</b>	5-1/16"	4-1/8"
<b>WFBR6</b>	7-3/16"	6-1/8"
<b>WFBR8</b>	9"	8-1/8"

SQUARE	A	B
<b>WFBS4</b>	5-1/16"	4-1/8"
<b>WFBS6</b>	7-1/4"	6-1/8"

 

## ORDERING INFORMATION

Example Order:  -  -

### Round Housings

**WFBR4** - 4-In.: 11W / 900Lm  
**WFBR6** - 6-In.: 14W / 1200Lm  
**WFBR8** - 8-In.: 18W / 1400Lm

### Square Housings

**WFBS4** - 4-In.: 11W / 850Lm  
**WFBS6** - 6-In.: 14W / 1100Lm

### Color Temp/CRI

**SW5C** - 5-CCT Selectable / 90+ CRI  
 2700K / 3000K / 3500K / 4000K / 5000K

### Driver/Dimming

**12D** - 120V TRIAC Dimming  
 (Forward/Reverse Phase)

### Finish

**MW** - Matte White

Nominal lumen values based on 3000K performance;  
 see photometric test results specification sheets for additional information

## ACCESSORIES

### New Construction Mounting Plate

**WFRPLU** - Universal Fit New Construction Mounting Plate for Round Downlights



### Driver / Junction Box Extension Cables

**WFEC6** - 6 Ft Extension Cable  
**WFEC10** - 10 Ft Extension Cable  
**WFEC20** - 20 Ft Extension Cable



### Trim Insert

**WFBR4TI** - 4-In. Round  
**WFBR6TI** - 6-In. Round  
**WFBR8TI** - 8-In. Round  
**WFBS4TI** - 4-In. Square  
**WFBS6TI** - 6-In. Square

### Finish

**B** - Black  
**BZ** - Bronze  
**NK** - Brushed Nickel



Black

Bronze

Brushed Nickel

ConTech Lighting combines the latest energy efficient technology and design styles to create an extensive range of attractive and sustainable luminaires, including many that can't be found anywhere else. We believe that lighting can be environmentally responsible and energy efficient while providing high-quality performance and outstanding aesthetic design.

Our responsive, personalized customer focus and market expertise represents an oasis of outstanding service in an industry that values it, but frequently doesn't receive it. Lighting is more than numbers on a specification sheet and changes are constantly developing, meaning each project can bring its own unique challenges. Our sales professionals and in-house teams stand ready to provide responsive and personalized support that you can trust from concept to completion. We welcome you to lean on us Monday through Friday, 7:30am till 5:30pm CST at 847.559.5500.

