

Baffle Slim LED Downlight with Selectable CCT



Designed for a wide range of applications: Residential, Multi-Family, Hospitality, and Light Commercial spaces

A direct mount downlighting solution that does not require an existing junction box or housing that can be used in Remodel or New Construction applications. Slim design requires only a 2-inch plenum and eliminates the need for a recessed housing. The Regressed Lens with Baffle provides less glare and improves visual comfort. Field selectable color temperature (CCT) from 2700K, 3000K, 3500K, 4000K and 5000K. IC-Rated die-cast Aluminum Housing in a Matte White Painted Finish. Available in 4-, 6- and 8-Inch round and 4- and 6-Inch square apertures.

ENERGY STAR® Certified. Can be used to comply with the Title 24 Part 6 JA8 High Efficacy LED Light Source Requirements. Air-tight Certified in accordance with ASTM E283, Insulated Ceiling (IC) Rated. Suitable for use in clothes closets when installed in accordance with NEC® 410.16 (A)(1) (C)(3) spacing requirements. Suitable for Wet Locations.



Edge-Lit optical system
creates a soft,
uniformly lit surface

Selectable CCT

120V Phase Dimming
down to 10%

Round Downlights

- 4-, 6- and 8- Inch Diameters
- 900, 1200, and 1400 Lumens

Square Downlights

- 4- and 6- Inch Squares
- 850 and 1100 Lumens



Features and Benefits

- Direct mount downlighting solution; no existing housing or junction box required
- Available in 4-, 6- and 8-Inch diameter Rounds and 4- and 6-Inch Squares
- Regressed Lens with Baffle for less glare and improved visual comfort
- Field selectable Color Temperature (CCT)
- IC-Rated die-cast aluminum Housing
- Diffuse Polycarbonate Lens
- Edge-Lit Optical System
- Closed Cell Gasket included for use in wet location environments or for restrictive airflow
- 120VAC, 60Hz
- 120V Forward or Reverse Phase Dimming
- Five (5) year replacement after date of purchase

Selectable Color Temperature (CCT)

- Select from 2700K, 3000K, 3500K, 4000K and 5000K
- Light engine consists of 90+ CRI LEDs with color accuracy within 4 SDCM
- 50,000 Hours @ 70% Lumen Maintenance

Rating

- 120VAC
- Meets Class A sound rating

Agency Standards


- cETLus Listed
- Suitable for Wet Locations
- ENERGY STAR® Certified
- Can be used to comply with the Title 24 Part 6 JA8 High Efficacy LED Light Source Requirements
- Air-tight certified in accordance with ASTM E283 (Air Leakage Rate 2.0 CFM or Less)
- Insulated Ceiling (IC) Rated
- Suitable for use in clothes closets when installed in accordance with NEC® 410.16 (A)(1) (C)(3) spacing requirements

DBR Series Specifications

	DBR40-S1W	DBR60-S1W	DBR80-S1W
SIZE	4-Inch Round	6-Inch Round	8-Inch Round
LUMEN OUTPUT ¹	900Lm	1200Lm	1400Lm
INPUT POWER	12W	15W	18W
DIMENSIONAL DRAWINGS			
A	5-1/16"	7-3/16"	9"
B	4-1/8"	6-1/8"	8-1/8"
C	1-3/16"	1-3/16"	1-3/16"
CEILING CUT-OUT	4-1/4" Dia.	6-1/4" Dia.	8-1/4" Dia.


1. Lumen values are nominal and vary based on CCT

DBR Series

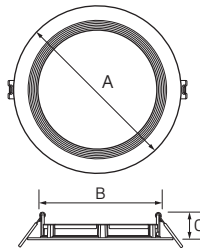

Driver/Junction Box

Included with Downlight
4-1/4" L x 3-9/16" W x 1-1/2" High

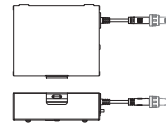

Total Cable Length: 14-3/8"
Recommended Ceiling Thickness: 1" Max.

 
DBRUX-H00

4" 7/8" Round
New Construction Mounting Plate
10" Wide x 26" Long



DBRCX-H00

4" 7/8" Round
New Construction Mounting Plate
8-5/16" Wide x 26" Long




DBS Series Specifications

	DBS40-S1W	DBS60-S1W
SIZE	4-Inch Square	6-Inch Square
LUMEN OUTPUT ¹	850Lm	1100Lm
INPUT POWER	12W	15W
DIMENSIONAL DRAWINGS		
A	5-1/16"	7-1/4"
B	4-1/8"	6-1/8"
C	1-3/16"	1-3/16"
CEILING CUT-OUT	4-1/4" Sq.	6-1/4" Sq.


1. Lumen values are nominal and vary based on CCT

DBS Series

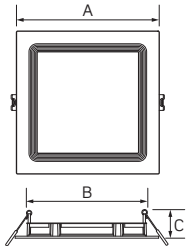

Driver/Junction Box


Included with Downlight
4-1/4" L x 3-9/16" W x 1-1/2" High

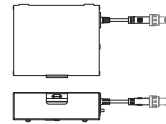

Total Cable Length: 14-3/8"
Recommended Ceiling Thickness: 1" Max.

DBSUX-H00

 4" 7/8" Square
New Construction Mounting Plate
8-5/16" Wide x 26" Long



Leviton Compatible Dimmers

	Dimmer Model
SureSlide	6674, 6674N
Decora Smart Wi-Fi	D26HD, DN6HD, D2MSD, DWVAA
Decora Digital	DDL06-1L, DDL06-BL, DDM06, DDMX1
Decora Slide	DSE06, DSM10, DSL06
Decora Smart Z-wave	ZW6HD
Decora Evolve	VM2D3, VMDD3
IllumaTech	IPE04, IPL06
Trimatron Rotary	RDL06, RNL06
Toggle Slide	TSL06, TSM10

Ordering Information

Cat. No.	Description	UPC #	Std. Pack
DBR40-S1W	4" Round Baffle Slim LED Downlight	0 78477 01463 9	12
DBR60-S1W	6" Round Baffle Slim LED Downlight	0 78477 01462 2	12
DBR80-S1W	8" Round Baffle Slim LED Downlight	0 78477 01461 5	12
DBRCX-H00	4" 7/8" Round Mounting Plate	0 78477 02352 5	15
DBRUX-H00	4" 7/8" Round Mounting Plate	0 78477 02024 1	15
Cat. No.	Description	UPC #	Std. Pack
DBS40-S1W	4" Square Baffle Slim LED Downlight	0 78477 01456 1	12
DBS60-S1W	6" Square Baffle Slim LED Downlight	0 78477 01460 8	12
DBSUX-H00	4" 7/8" Square Mounting Plate	0 78477 02028 9	15



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am-5pm EST

For 24/7 product support visit www.leviton.com/support

© 2024 Leviton Manufacturing Co., Inc. All rights reserved. All trademarks are the property of their respective owners.