



# Residential Solutions

---

Ambient, Task & Accent  
Recessed Lighting



# Bring Intense Home



Never before has a home been more important than today. Thanks to the advancements in LED technology, residential lighting can be tailored to your personal needs, contributing to a happier and healthier home.

Intense Lighting offers a collection of products that provide beautiful, efficient illumination that customizes any room perfectly.

## Live, Work & Play





Lighting That Works  
**With Your Space**




# Light Quality Matters




Vibrant Colors


82 & 92 CRI Option

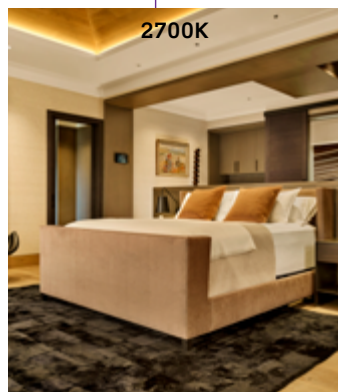


2700K

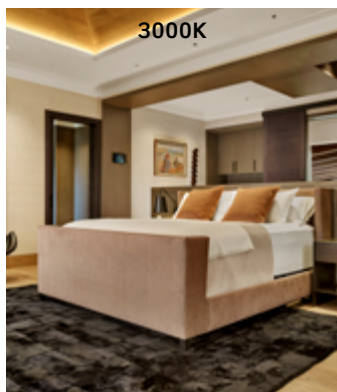

3000K

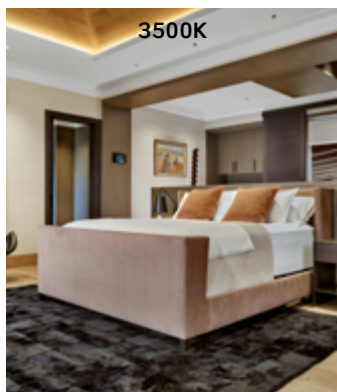

3500K

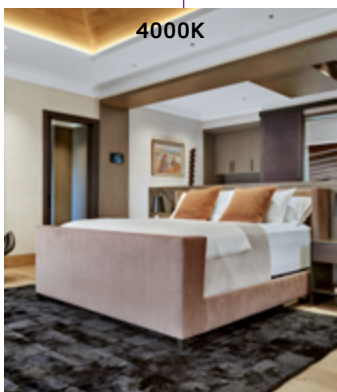

4000K

Full Range of CCT's

# Because Details Make the Difference



Uniform Illumination



Consistent Tones

Bring a home to life under vivid 80 and 90+ CRI. High CRI lets you enjoy more vibrant, realistic colors for anything from applying makeup, cooking dinner, or illuminating art on a wall.

2 Step Binning throughout our downlight portfolio brings industry leading color consistency for a perfectly illuminated home.





Low Glare Adjustable Pinholes



Adjustability For Every Angle

### Let It Shine

with perfectly aimed light. Flexibility to aim your lights provides the control needed to highlight that beautiful art. Pinhole trims yield low glare while hitting the target.

With expansive options like downlights, adjustables, and wall washers that utilize the same housings, mechanisms and modules, quick on the spot change orders have never been easier.

Small Apertures For High to Low Ceilings



# Highly Configurable & Adaptable Lighting



# Take Control, Set The Mood

Our homes are working harder than ever for us and the need for multipurpose spaces has grown exponentially. Living rooms have become offices and classrooms, making the right light at the right time more important than ever. Using Tunable White to simulate natural light and intensity can better work performance, mood, sleep and overall health.

6500K  
to 2700K

**Tunable White**  
Dynamic White Illumination





# Wind Down, **Get Comfortable**

There's no denying the comfort we all feel from warm incandescent light sources. Providing an old school feel with new school performance, Warm Dim emulates the same warm glow with the flexibility of LEDs. With deep architectural dimming that warms as it dims, creating your ideal ambiance is at your fingertips.

3000K  
to 1800K



**Warm Dim**  
Enhance Your Space



# Multiple Control Options



Stay connected with **countless options** compatible with **modern control systems.**

From Bluetooth to DALI, Intense luminaires provide interoperability with a host of different control protocols to keep the entire house connected.

A well-equipped home is ready for any task, especially when outfitted with devices that add safety, convenience and ambiance to daily living.

**Architectural Dimming Down to 0.1%**



**DALI & DMX Options**

Stay Connected



# The Perfect Downlight for Any Space




## MX 3.5-Inch Downlighting

### Extensive Housing Options

- Air-Tight IC
- Chicago Plenum
- Non-IC & Remodel Options


Title 24 and Energy Star Compliant

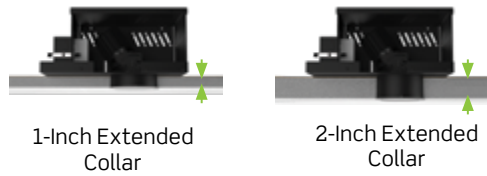

5/8 to 2 inches  
Extended Collar



Horizontal Adjustment  
368° of Rotation  
Vertical Adjustment  
35° of Tilt

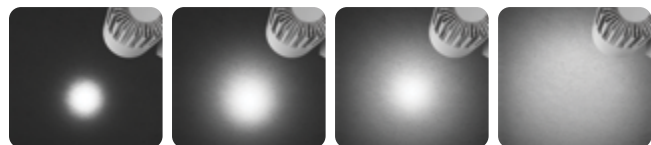

Performance Optics  
9°, 12°, 24°, 36° & 50°

Trim, Trimless & Wood Ceiling in Multiple Applications



Trimmed

Trimless

Wood Ceiling



Downlight

Adjustable

Wall Wash

Pinhole




Standard 2-Inch Regressed


Half-Inched Regressed

Non-Conductive, Wet Location

Flat Mount

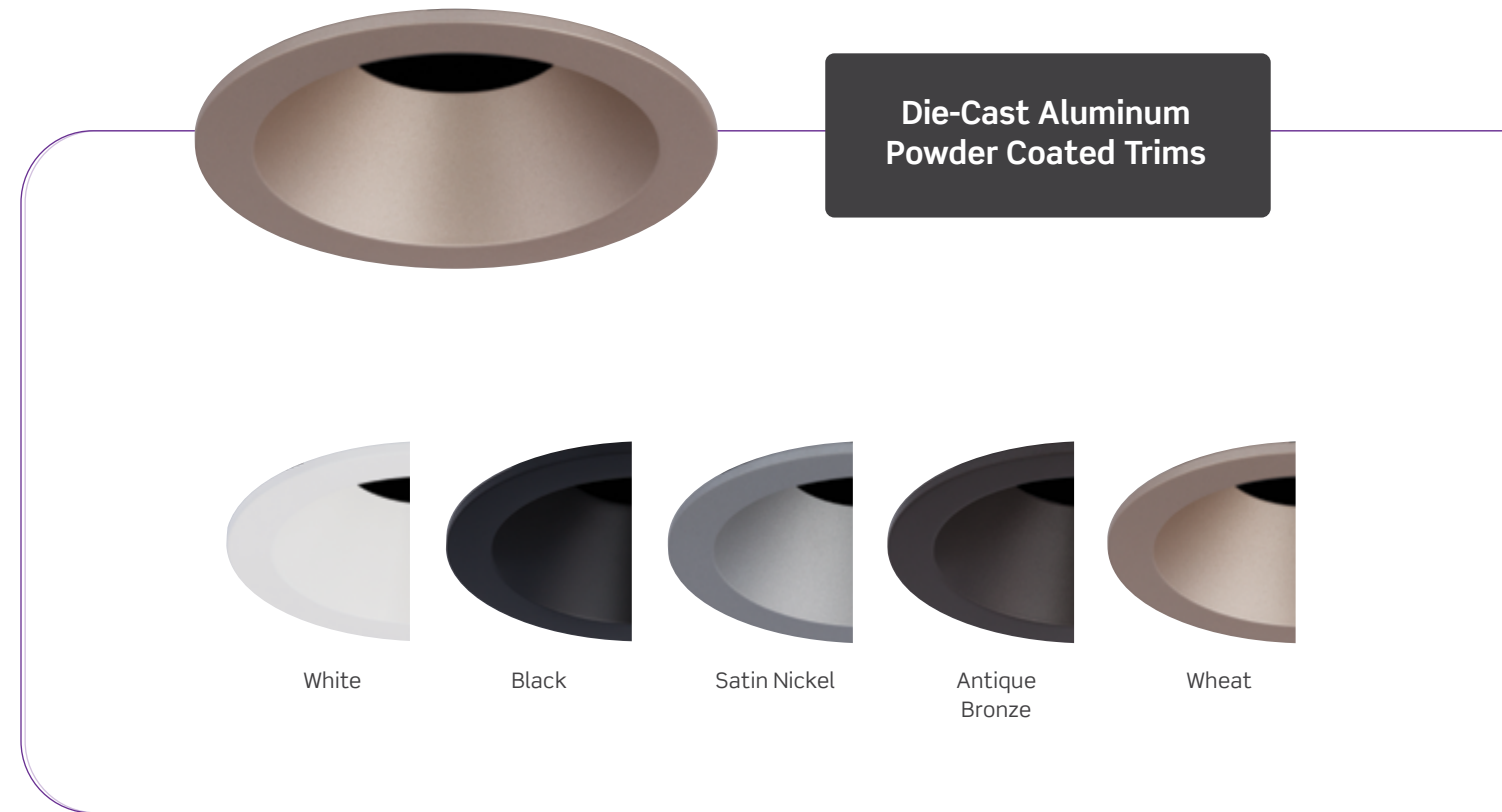

Die-Cast Aluminum Powder Coated Trims

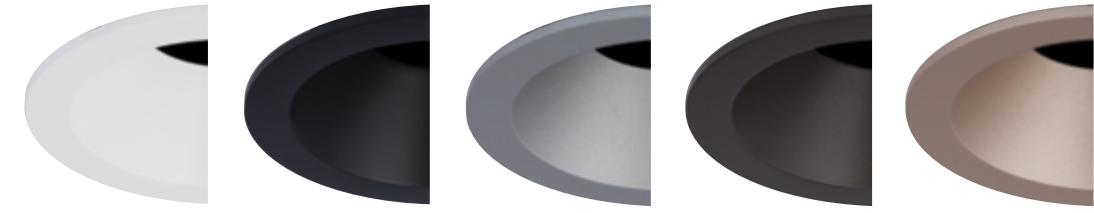

White

Black

Satin Nickel

Antique Bronze


Wheat



# Solutions for Any Room

## Gravity 2-Inch

- Up to 1500 lumens
- Round or Square Aperture
- Downlight, Adjustable, Wall Wash & Shallow
- Easy New Construction (Non-IC/IC Rated) & Remodel (Non-IC) Installation
- Extensive Dimming Options

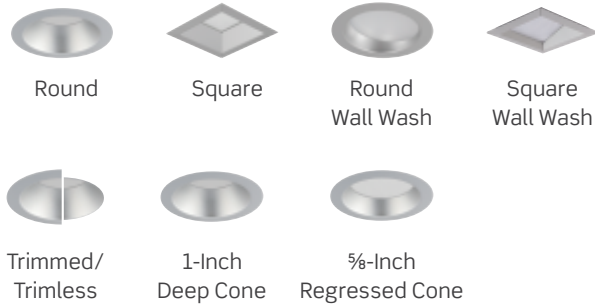

Shallow Housing

3.9"


Industry First Fold Frame



Interchangeable Mechanisms



Award Winning 7° Delivering over 30,000 CBCP

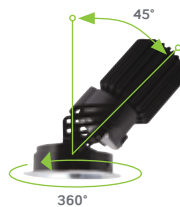

Class Leading 45° Tilt 360° Rotation




Adjustable Collar Heights 1/2 - 1-1/4 Inch



## LC 4-Inch

- Up to 1000 lumens
- 2hr fire rating per UL514A
- Inherent Airtight IC and CCEA rated for Chicago Plenum
- 2-Step MacAdam binning and 92 CRI Standard

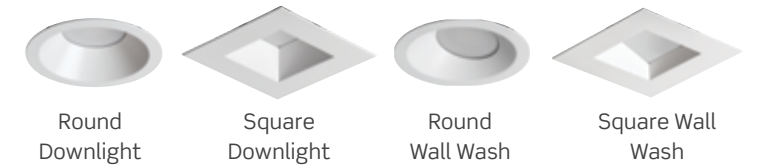

## XS 2-Inch

- Up to 1100 lumens
- Dual purpose housing in remodel or new construction
- All-in-one driver with 0-10V and phase dimming
- 2-Step MacAdam ensuring color consistency





**Intense Lighting**

3340 E. La Palma Ave.  
Anaheim, CA 92806

**tel** 714 630-9877

**fax** 714 630-9883

[info@intenselighting.com](mailto:info@intenselighting.com)  
[www.intenselighting.com](http://www.intenselighting.com)

**A Leviton Company**

[www.leviton.com](http://www.leviton.com)

Printed in the U.S.A  
©2021. Intense Lighting, LLC. All Rights Reserved.

INT0321-MX-1