

BEST

# Gravity™ High Performance



**TYPE:**  
Downlight | Adjustable | Wall Wash

**APERTURE:**  
2, 4, 6 or 8-Inch Round & Square

**LUMEN/WATT:**  
900lm (10W) - 10,000lm (87W)

**DIMMING:**  
Phase | 0-10V | Lutron® | DALI | DMXR

**OPTICS:**  
7° | 14° | 20° | 30° | 40° | 50°


**LED MODULE:**  
82/92 CRI at 2700K, 3000K, 3500K, 4000K w/ 2 SDCM

**HOUSING:**  
New Construction | Remodel | Shallow

**LIGHT SOURCE FEATURE:**  
Warm Dim | Tunable White

BEST

# MX 3.5-Inch Downlighting

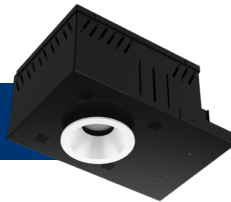

**TYPE:**  
Downlight | Adjustable | Wall Wash

**APERTURE:**  
3.5-Inch Round & Square

**LUMEN/WATT:**  
950lm (10W) - 1850lm (26W)

**DIMMING:**  
Phase | 0-10V | Lutron® | DALI | DMXR

**OPTICS:**  
9° | 12° | 24° | 36° | 50°

**LED MODULE:**  
92/82 CRI at 2700K, 3000K, 3500K, 4100K w/ 2 SDCM

**HOUSING:**  
New Construction | Remodel | Naked Non-IC

**LIGHT SOURCE FEATURE:**  
Warm Dim | Tunable White

BETTER

# SD Performance For Every Budget



**TYPE:**  
Downlight | Wall Wash

**APERTURE:**  
4-Inch (Round & Square), 6 or 8-Inch (Round)

**LUMEN/WATT:**  
1000lm (10W) - 4000lm (38W)

**DIMMING:**  
Phase | 0-10V | Lutron® | Osram | DMXR

**OPTICS:**  
30° | 50° | 70°

**LED MODULE:**  
80/90 CRI at 2700K, 3000K, 3500K, 4000K w/ 2 SDCM

**HOUSING:**  
New Construction | Remodel

**OPTION:**  
Intellect Enabled

BETTER

# XS 2-Inch Downlighting



**TYPE:**  
Downlight | Adjustable | Wall Wash

**APERTURE:**  
2-Inch Round & Square

**LUMEN/WATT:**  
700lm (10W) - 1100lm (15W)

**DIMMING:**  
Phase | 0-10V

**OPTICS:**  
18° | 24° | 36°


**LED MODULE:**  
82 CRI in 2700K, 3000K, 3500K, 4100K w/ 2 SDCM  
92 CRI in 2700K w/ 2 SDCM

**LISTING:**  
Title 24 | Wet Location | ETL Listed (IC Only)

**HOUSING:**  
New Construction | Remodel (Non-IC, Airtight IC)

GOOD

# LD Built With Simplicity

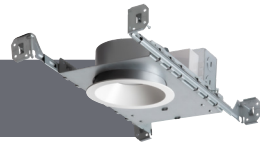

**TYPE:**  
Downlight | Wall Wash

**APERTURE:**  
4-Inch Round & Square

**LUMEN/WATT:**  
400lm (5W) - 1500lm (17W)

**DIMMING:**  
Phase | 0-10V | Lutron® | eldoLED

**OPTICS:**  
90° Standard

**LED MODULE:**  
90 CRI in 2700K, 3000K, 3500K, 4000K w/ 2 SDCM

**LISTING:**  
Wet Location

**HOUSING:**  
New Construction Non-IC

GOOD

# LC Fire-Rated Downlighting



**TYPE:**  
Downlight | Adjustable | Wall Wash

**APERTURE:**  
2-Inch Round & Square

**LUMEN/WATT:**  
600lm (8W) - 1000lm (12W)

**DIMMING:**  
Phase | 0-10V

**LED MODULE:**  
92 CRI in 2700K, 3000K, 3500K w/ 2 SDCM

**LISTING:**  
Title 24 | JA8 | Energy Star | Wet Location

**HOUSING:**  
Fire-Rated, J-box housing

## Gravity Cylinders

**TYPE:**

Downlight

**APERTURE:**

2, 4, 6, & 8-inch

**LUMEN/WATT:**

850lm (10W) - 8000lm (73W)

**DIMMING:**

Phase | 0-10V | Lutron® | eldoLED | DMXR

**MOUNTING:**

Cable | Pendant | Surface | Wall Mount

**LIGHT SOURCE FEATURE:**

Warm Dim | Tunable White



## MX Cylinders

**TYPE:**

Downlight | Wall Wash

**APERTURE:**

3.5-Inch Round or Square

**LUMEN/WATT:**

900lm (10W) - 1500lm (20W)

**DIMMING:**

Phase | 0-10V | Lutron® | eldoLED | DMXR

**MOUNTING:**

Cable | Pendant | Wall Mount/Sconce

**LIGHT SOURCE FEATURE:**

Warm Dim | Tunable White



## SD Cylinders

**TYPE:**

Downlight

**APERTURE:**

4, 6, & 8-Inch

**LUMEN/WATT:**

1000lm (9W) - 3500lm (32W)

**DIMMING:**

Osram | Phase | Lutron® | eldoLED | DMXR

**MOUNTING:**

Cable | Surface | Wall Mount

**OPTIC:**

30° | 50° | 70°



intense | a **LEVITON**  
LIGHTING company

**Intense Lighting**

3340 E. La Palma Ave.  
Anaheim, CA 92806

tel 714 630-9877

fax 714 630-9883

info@intenselighting.com

www.intenselighting.com

**A Leviton Company**

www.leviton.com


Printed in the U.S.A

© Copyright 2020. Intense Lighting. All Rights Reserved.

INT1120-DL-1

# Downlighting

## Reference Guide

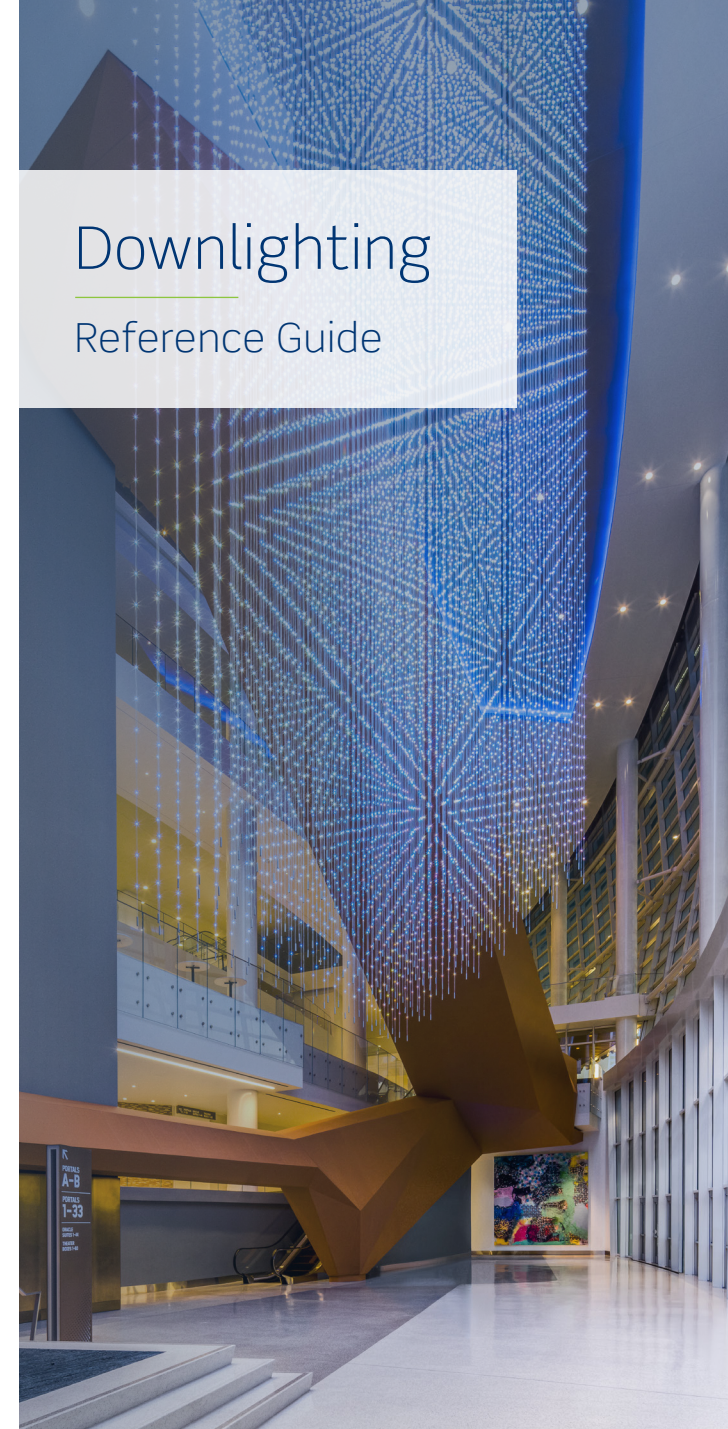

intense | a **LEVITON**  
LIGHTING company