

JC14223BLK

Starspot 600

Starspot 600 Mains Dimmable IP20 Track Spotlight LED 7W 4000K 600lm 36°
Black

Features & Benefits

- Exceeds 50W halogen light output
- Triac dimmable as standard
- 36° beam angle



BEAM



DIMMABLE



CLASS I



WARRANTY



CRI:RA



RATING

General Information

Trade Name	Starscoop
Environment	Indoor
Suitable For Zones	Outside zone 2
Product Group	LED - Track
Color Finish	Black
Product Shape	Cylinder
Product Range	Starspot 600
Overall Dimensions	91.8 x 132.5 mm
Product Weight(kg)	0.33
Light Source	LED
Light Source Features	Neutral White
Recommended Product Location	Retail areas, displays museums etc
Method Of Fix	Fixed to single circuit track 3or 3 circuit with JC88118
Distance From Lighted Object	0.3m
Max Angle Of Tilt & Rotation	350° rotation / 0-90° tilt
IP Rating	IP20
Origin of manufacturer	Made in Taiwan
Warranty	2 years standard warranty extends to 5 years when registered within the first year of purchase (See Website for

Dimming Protocol Compatibility

Driver Manufacturer

LED Manufacturer/Type

Lighting Product Type 1

Electrical

Voltage Rating

Operating Frequency Hz

Luminaire Circuit Wattage

Class

Dimmable

terms and conditions)

Triac

Mains LED CHIP

EDC/38C/8W/830/230V/A001/LUMENS

Track Head

Thermals

Operating Temperature Range °C

0 to +26

Performance Data

LED Life (Hours)

30000

Hours life stated is an indication of expected L70 chip and light output calculations when operating in optimum conditions. Product warranty period supports the full product during the term given. The L70 hours expectancy is not correlated with the full product warranty term, nor is it a representation of lumen depreciation during the warranty period.

Energy Rating

Actual Lumen Output

Lumens Per Circuit Watt

Color Rendering Index

CRI: Ra

Correlated Color Temperature

Beam Angle °

LOR (Light Output Ratio) %

Photometry Available

This product contains a light source of energy efficiency class

F

600

86 LpcW

80-89

85

4000K

36

100

Yes

Construction

Primary Material

Lens

Heat Sink

Aluminium

Polycarbonate

Aluminium

Packaging

Product Packaged Weight(kg)

Quantity Per Outer Carton

Product Bar Code EAN-13 Number

0.37

24

5052544051395



Standards & Approvals

Manufactured In Accordance To

BS EN 60598-2,BS EN 60570:2003

CE Marked
UKCA Marked
Date code/Purchase order No.
Certificate Of Conformity
Accredited Members

Yes
Yes
Yes
Available on request
LIA, ISO9001-2015, ISO14001-2015

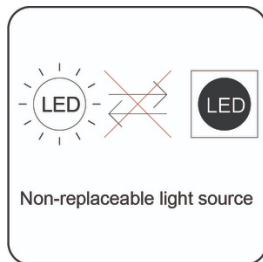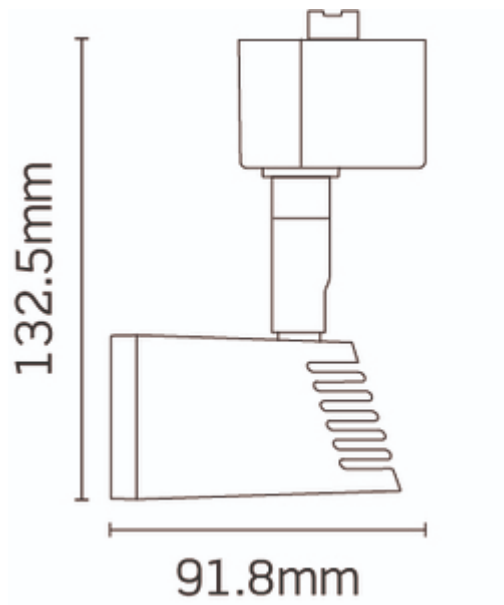

JCC Lighting LTD, Lux Park, Chichester Business Park, City Fields Way, Tangmere, Chichester, West Sussex, PO20 2FT.
Sales: 01243 838999 (8am to 5pm Monday to Friday) Fax: 01243 838998 | sales@jcc.co.uk | www.jcc.co.uk
Company Registration Number: 03044848 | VAT Number: 918544112

This document is uncontrolled if printed, all information is subject to change

Version 91 [06/02/2023]