

THE FUTURE IS ON®

LEVITON®



Hospital Grade Devices



Hospital Grade Receptacles



TABLE OF CONTENTS

- Standard Receptacles4
- Time Savings7
 - Lev-lok® Modular Wiring Devices: Receptacles7
- Protection 13
 - SmartlockPro® AFCI Receptacles..... 13
 - SmartlockPro® GFCI Receptacles 13
 - SmartlockPro® Dual Function AFCI/GFCI Receptacles. 15
 - Surge Protective Receptacles 16
- Specialty 17
 - 4-in-1™ Receptacles 17
 - USB Receptacles..... 17
 - Surge Protective Devices 18

Choose from among the broadest offering of safe and reliable receptacle outlets in the industry, with devices to suit your every need or function.

SYMBOLS TO SIMPLIFY BROWSING



Tamper-Resistant



Isolated Ground



Power Indication



Weather-Resistant



Audible Alarm



Single Receptacle



Plug Load Control



Fast-Charging USB

Hospital Grade Receptacles

HOSPITAL GRADE

UL construction and performance requirements for Hospital Grade receptacles are more stringent than those for specification grade devices. Leviton Hospital Grade receptacles meet or exceed these requirements. These receptacles are Fed Spec W-C-596 rated.*



Extra Heavy-Duty



Heavy-Duty

HOSPITAL GRADE Extra Heavy-Duty

- Single-piece wraparound nickel-plated brass strap
- Integral ground contacts
- Extra heavy-duty high-performance brass electrical contacts



* See website for product specifications.

Standard Receptacles



HOSPITAL GRADE

Extra Heavy-Duty



2-Pole, 3-Wire • 125 Volt

Color





15 Amp


20 Amp

STANDARD	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Back and Side Wire 	White	8200-W	8300-W
		Ivory	8200-I	8300-I
		Lt Almond	8200-T	8300-T
		Brown	8200	8300
		Gray	8200-GY	8300-GY
		Black	—	8300-E
		Red	8200-R	8300-R
	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant Back and Side Wire 	White	8200-SGW	8300-SGW
		Ivory	8200-SGI	8300-SGI
		Lt Almond	—	8300-SGT
		Brown	8200-SG	8300-SG
		Gray	8200-SGG	8300-SGG
		Red	8200-SGR	8300-SGR
		<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Power Indication LED Back and Side Wire 	White	8200-PLW
	Ivory		8200-PLI	8300-PLI
Brown	—		8300-PL	
Gray	—		8300-PLG	
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face MRI Back and Side Wire 	White	MRI82-W	MRI83-W	
	Ivory	MRI82-I	MRI83-I	
	Lt Almond	MRI82-T	MRI83-T	
	Gray	MRI82-GY	MRI83-GY	
	Red	MRI82-R	MRI83-R	
DECORA PLUS™	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Back and Side Wire 	White	16262-HGW*	16362-HGW*
		Ivory	16262-HGI*	16362-HGI*
		Lt Almond	—	16362-HGT*
		Gray	16262-HGG*	16362-HGG*
		Red	16262-HGR*	16362-HGR*
	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Power Indication LED Back and Side Wire 	White	16262-PLW*	16362-PLW*
		Ivory	16262-PLI*	16362-PLI*
		Red	16262-PLR*	16362-PLR*
	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant Back and Side Wire 	White	16262-SGW*	16362-SGW*
		Ivory	16262-SGI*	16362-SGI*
		Lt Almond	16262-SGT*	16362-SGT*
		Brown	16262-SG*	—
		Gray	—	16362-SGG*
	Red	16262-SGR*	16362-SGR*	



* Not Fed Spec rated

HOSPITAL GRADE Extra Heavy-Duty		NEMA 6-15R 	NEMA 6-20R 	250 V	
2-Pole, 3-Wire • 250 Volt		15 Amp	20 Amp		
STANDARD	• Duplex Receptacle	White	—	8400-W	
	• Smooth Face	Ivory	8600-I	8400-I	
	• Back and Side Wire	Brown	8600	8400	
		Gray	—	8400-GY	
		Red	—	8400-R	
HOSPITAL GRADE Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 		
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp		
STANDARD	• Single Receptacle	White	8210-W	8310-W	
	• Smooth Face	Ivory	8210-I	8310-I	
	• Back and Side Wire	Brown	8210	8310	
		Gray	—	8310-GY	
		Red	8210-R	8310-R	
	• Duplex Receptacle	White	8200-HW	8300-HW	
	• Smooth Face	Ivory	8200-HI	8300-HI	
	• Back and Side Wire	Lt Almond	8200-HT	8300-HT	
		Brown	8200-H	8300-H	
		Gray	8200-HGY	8300-HGY	
		Red	8200-HR	8300-HR	
	Yellow	8200-HY	—		
	Blue	8200-HBU	8300-HBU		
• Duplex Receptacle	White	C8200-W	C8300-W		
• Indented Face	Ivory	C8200-I	C8300-I		
• Back and Side Wire	Lt Almond	C8200-T	C8300-T		
	Brown	C8200	C8300		
	Gray	C8200-GY	C8300-GY		
	Black	C8200-E	C8300-E		
	Red	C8200-R	C8300-R		
	Blue	C8200-BU	C8300-BU		
• Duplex Receptacle	White	T8200-W	T8300-W		
• Smooth Face	Ivory	T8200-I	T8300-I		
• Tamper-Resistant	Lt Almond	T8200-T	T8300-T		
• Back and Side Wire	Brown	T8200	T8300		
	Gray	T8200-GY	T8300-GY		
	Black	T8200-E	T8300-E		
	Red	T8200-R	T8300-R		
	Blue	T8200-BU	T8300-BU		
• Single Receptacle	Orange	8210-IG	8310-OIG		
• Smooth Face					
• Isolated Ground					
• Back and Side Wire					

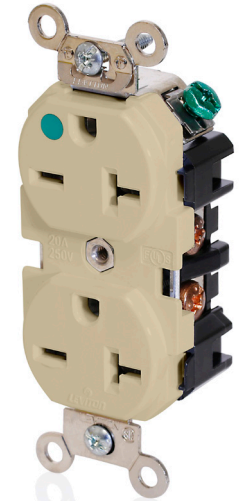

8400-I



C8200-W



T8200-I

Standard Receptacles

HOSPITAL GRADE

Heavy-Duty



2-Pole, 3-Wire • 125 Volt

Color


15 Amp

20 Amp

STANDARD


DECORA PLUS™

2-Pole, 3-Wire • 125 Volt	Color	15 Amp	20 Amp
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Isolated Ground Back and Side Wire 	White	8200-IGW	8300-IGW
	Ivory	8200-IGI	8300-IGI
	Brown	8200-IGB	8300-IGB
	Gray	8200-IGG	8300-IGG
	Red	8200-IGR	8300-IGR
	Orange	8200-IG	8300-OIG
	Orange	8200-LIG	8300-LIG
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Isolated Ground Back and Side Wire Pre-wired Ground Lead 	White	8200-HLW	8300-HLW
	Ivory	8200-HLI	8300-HLI
	Gray	—	8300-HLG
	Red	8200-HLR	8300-HLR
	White	T8200-IGW	T8300-IGW
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Isolated Ground Tamper-Resistant Back and Side Wire 	Ivory	T8200-IGI	T8300-IGI
	Gray	T8200-IGG	T8300-IGG
	Red	T8200-IGR	T8300-IGR
	Orange	T8200-IG	T8300-IG
	Blue	T8200-IGB	T8300-IGB
	White	D8200-IGW	D8300-IGW
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Isolated Ground Back and Side Wire 	Ivory	D8200-IGI	D8300-IGI
	Lt Almond	D8200-IGT	D8300-IGT
	Brown	D8200-IGB	D8300-IGB
	Gray	D8200-IGG	D8300-IGG
	Black	D8200-IGE	D8300-IGE
	Red	D8200-IGR	D8300-IGR
	Orange	D8200-IG	D8300-IG
	White	DT820-IGW	DT830-IGW
	Ivory	DT820-IGI	DT830-IGI
	Brown	DT820-IGB	DT830-IGB
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Isolated Ground Tamper-Resistant Back and Side Wire 	Gray	DT820-IGG	DT830-IGG
	Red	DT820-IGR	DT830-IGR
	Orange	DT820-IG	DT830-IG

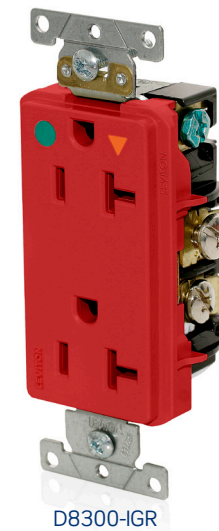

lev-lok® Modular Receptacles

The perfect productivity solution for electrical construction & maintenance applications.

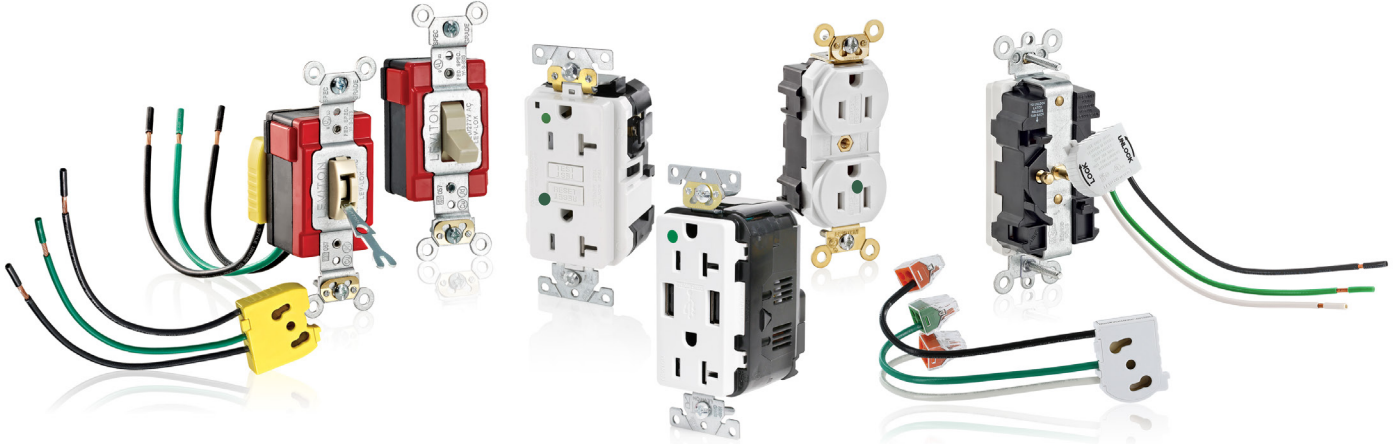

KEY FEATURES AND BENEFITS



Future Proof

It's 5x faster to replace devices in a facility to meet future needs, whether you're updating technology or meeting new requirements.



Compress Timelines

Accelerate installation and swap outs to complete projects faster than using traditional wiring.



Accurate & Secure Connection

Lev-Lok® lowers the risk of incorrect installation while providing a safe and secure connection.

CALCULATE YOUR SAVINGS ONLINE: www.leviton.com/levlokcalculator

Time Savings

lev-lok® Modular Wiring Devices: Receptacles

HOSPITAL GRADE Extra Heavy-Duty




2-Pole, 3-Wire • 125 Volt

	Color	15 Amp	20 Amp
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face 	White	M8200-W	M8300-W
	Ivory	M8200-I	M8300-I
	Lt Almond	M8200-T	M8300-T
	Brown	M8200	M8300
	Gray	M8200-GY	M8300-GY
	Black	M8200-E	M8300-E
	Red	M8200-R	M8300-R
	Blue	M8200-B	M8300-B
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant 	White	M8200-SGW	M8300-SGW
	Ivory	M8200-SGI	M8300-SGI
	Lt Almond	M8200-SGT	M8300-SGT
	Brown	M8200-SG	M8300-SG
	Gray	M8200-SGG	M8300-SGG
	Black	M8200-SGE	M8300-SGE
	Red	M8200-SGR	M8300-SGR
	Blue	M8200-SGB	M8300-SGB
STANDARD <ul style="list-style-type: none"> Duplex Receptacle Smooth Face MRI 	White	MRI15-W	MRI20-W
	Ivory	MRI15-I	MRI20-I
	Lt Almond	MRI15-T	MRI20-T
	Gray	MRI15-GY	MRI20-GY
	Red	MRI15-R	MRI20-R
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Power Indication LED 	White	M8200-PLW	M8300-PLW
	Ivory	M8200-PLI	M8300-PLI
	Lt Almond	M8200-PLT	M8300-PLT
	Gray	M8200-PLG	M8300-PLG
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Illuminated Blade Slot 	White	M8200-ILW	M8300-ILW
	Ivory	M8200-ILI	M8300-ILI
	Lt Almond	M8200-ILT	M8300-ILT
	Gray	M8200-ILG	M8300-ILG
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant Illuminated Blade Slot 	White	MT820-ILW	MT830-ILW
	Ivory	MT820-ILI	MT830-ILI
	Lt Almond	MT820-ILT	MT830-ILT
	Gray	MT820-ILG	MT830-ILG
	Red	MT820-ILR	MT830-ILR


lev-lok®

SIMPLE AND SECURE

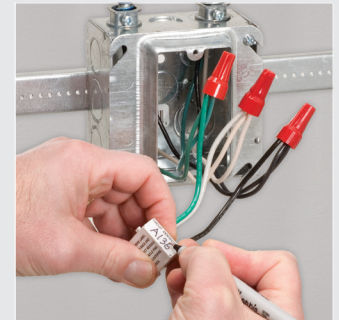

Install Wiring Module

All modules have a Circuit ID Label for ease of identification

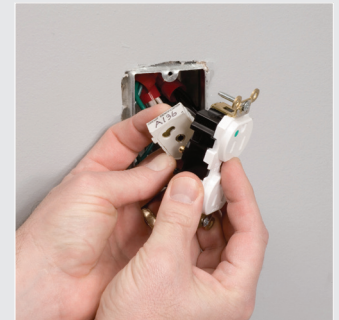

Connect Wiring Device

Simply push and twist to lock connection



Finish Installation

Install device into box and finish with wallplate

MSTWL series wiring modules (sold separately) must be used with Lev-Lok receptacles. See page 27 for options and ordering information.



FOR MORE INFORMATION ON THE FULL LINE: www.leviton.com/levlok

lev-lok® Modular Wiring Devices: Receptacles

HOSPITAL GRADE Extra Heavy-Duty



2-Pole, 3-Wire • 125 Volt		Color	15 Amp	20 Amp
DECORA PLUS™	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face 	White	M1626-HGW	M1636-HGW
		Ivory	M1626-HGI	M1636-HGI
		Lt Almond	M1626-HGT	M1636-HGT
		Gray	M1626-HGG	M1636-HGG
		Black	M1626-HGE	M1636-HGE
		Red	M1626-HGR	M1636-HGR
		Blue	M1626-HGB	M1636-HGB
	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant 	White	MT162-HGW	MT163-HGW
		Ivory	MT162-HGI	MT163-HGI
		Lt Almond	—	MT163-HGT
		Gray	MT162-HGG	MT163-HGG
		Red	MT162-HGR	MT163-HGR
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Power Indication LED 	White	M1626-PLW	M1636-PLW	
	Ivory	M1626-PLI	M1636-PLI	
	Lt Almond	M1626-PLT	M1636-PLT	
	Gray	M1626-PLG	M1636-PLG	
	Red	M1626-PLR	M1636-PLR	
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Illuminated Blade Slot 	White	M1626-ILW	M1636-ILW	
	Ivory	M1626-ILI	M1636-ILI	
	Lt Almond	M1626-ILT	M1636-ILT	
	Gray	M1626-ILG	M1636-ILG	
	Red	M1626-ILR	M1636-ILR	
<ul style="list-style-type: none"> Duplex Receptacle Smooth Face Tamper-Resistant Illuminated Blade Slot 	White	MT162-ILW	MT163-ILW	
	Ivory	MT162-ILI	MT163-ILI	
	Lt Almond	MT162-ILT	MT163-ILT	
	Gray	MT162-ILG	MT163-ILG	
	Red	MT162-ILR	MT163-ILR	



M8300-ILI




M1626-HGR

HOSPITAL GRADE Heavy-Duty



2-Pole, 3-Wire • 125 Volt		Color	15 Amp	20 Amp
STANDARD	<ul style="list-style-type: none"> Duplex Receptacle Smooth Face 	White	M8200-HW	M8300-HW
		Ivory	M8200-HI	M8300-HI
		Lt Almond	M8200-HT	M8300-HT
		Brown	M8200-H	M8300-H
		Gray	M8200-HGY	M8300-HGY
		Black	M8200-HE	M8300-HE
		Red	M8200-HR	M8300-HR
		Blue	M8200-HB	M8300-HB

Receptacles must be used with MSTWL series wiring modules (sold separately). See pg 27 for module details.

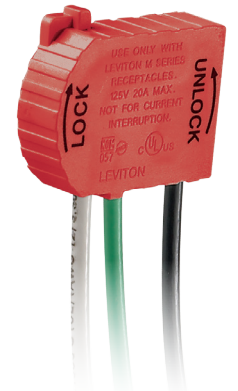

MSTWL-R

lev-lok® Modular Wiring Devices: Receptacles

HOSPITAL GRADE Heavy-Duty



2-Pole, 3-Wire • 125 Volt

Color

15 Amp

20 Amp

- Duplex Receptacle
- Smooth Face
- Tamper-Resistant

White	MT820-W	MT830-W
Ivory	MT820-I	MT830-I
Lt Almond	MT820-T	MT830-T
Brown	MT820	MT830
Gray	MT820-GY	MT830-GY
Black	MT820-E	MT830-E
Red	MT820-R	MT830-R
Blue	MT820-B	MT830-B



- Duplex Receptacle
- Smooth Face
- Isolated Ground

White	M8200-IGW	M8300-IGW
Ivory	M8200-IGI	M8300-IGI
Lt Almond	M8200-IGT	M8300-IGT
Gray	M8200-IGG	M8300-IGG
Black	M8200-IGE	M8300-IGE
Red	M8200-IGR	M8300-IGR
Orange	M8200-IG	M8300-IG



- Duplex Receptacle
- Smooth Face
- Tamper-Resistant
- Isolated Ground

White	MT820-IGW	MT830-IGW
Ivory	MT820-IGI	MT830-IGI
Lt Almond	MT820-IGT	MT830-IGT
Gray	MT820-IGG	MT830-IGG
Black	MT820-IGE	MT830-IGE
Red	MT820-IGR	MT830-IGR
Orange	MT820-IG	MT830-IG



- Duplex Receptacle
- Smooth Face
- Isolated Ground

White	MD820-IGW	MD830-IGW
Ivory	MD820-IGI	MD830-IGI
Lt Almond	MD820-IGT	MD830-IGT
Gray	MD820-IGG	MD830-IGG
Black	MD820-IGE	MD830-IGE
Red	MD820-IGR	MD830-IGR
Orange	MD820-IG	MD830-IG





- Duplex Receptacle
- Smooth Face
- Isolated Ground
- Tamper-Resistant

White	MDT82-IGW	MDT83-IGW
Ivory	MDT82-IGI	MDT83-IGI
Lt Almond	MDT82-IGT	MDT83-IGT
Gray	MDT82-IGG	MDT83-IGG
Black	MDT82-IGE	MDT83-IGE
Red	MDT82-IGR	MDT83-IGR
Orange	MDT82-IG	MDT83-IG





lev-lok® Modular Wiring Devices: GFCI Receptacles

HOSPITAL GRADE Extra Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 	
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp	
DECORA PLUS™	<ul style="list-style-type: none"> • SmartlockPro® Self-Test GFCI • Duplex Receptacle • Power Indication LED • Back and Side Wire • 20 Amp Feed-Through Terminals 	White	MGFN1-HGW	MGFN2-HGW
		Ivory	MGFN1-HGI	MGFN2-HGI
		Lt Almond	MGFN1-HGT	MGFN2-HGT
		Brown	MGFN1-HG	MGFN2-HG
		Gray	MGFN1-HGG	MGFN2-HGG
		Black	MGFN1-HGE	MGFN2-HGE
		Red	MGFN1-HGR	MGFN2-HGR
		White	MGFT1-HGW	MGFT2-HGW
		Ivory	MGFT1-HGI	MGFT2-HGI
		Lt Almond	MGFT1-HGT	MGFT2-HGT
	Brown	MGFT1-HG	MGFT2-HG	
	Gray	MGFT1-HGG	MGFT2-HGG	
	Black	MGFT1-HGE	MGFT2-HGE	
	Red	MGFT1-HGR	MGFT2-HGR	



lev-lok® Modular Wiring Devices: USB Receptacles

HOSPITAL GRADE Extra Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 	
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp	
DECORA PLUS™	<ul style="list-style-type: none"> • Duplex Receptacle • One Type A & One Type C USB Port • Smooth Face • Tamper-Resistant 	White	M56AC-HGW	M58AC-HGW
		Ivory	M56AC-HGI	M58AC-HGI
		Lt Almond	M56AC-HGT	M58AC-HGT
		Brown	M56AC-HG	M58AC-HG
		Gray	M56AC-HGG	M58AC-HGG
		Black	M56AC-HGE	M58AC-HGE
		Red	M56AC-HGR	M58AC-HGR

lev-lok® Modular Wiring Receptacle Modules

20 Amp, 125 Volt Max.	Module Color	Wire Type	Wire Colors	Catalog Number
Stranded Wire Leads	White	THHN	Black, White, Green	MSTWL-A
Stranded Wire Leads with 4-Port Push Wire Connectors	White	THHN	Black, White, Green	MSTWL-WST
Dual Module for 2-Gang Applications with Leads Pre-Installed in Push Wire Connectors	White	THHN	Black, White, Green	MSTWL-WTK
Stranded Wire Leads for Emergency Circuits	Red	THHN	Black, White, Green	MSTWL-R
Stranded Wire Leads for Isolated Ground Circuits	Orange	THHN	Black, White, Green	MSTWL-IG
Stranded Wire Leads with 4-Port Push Wire Connectors for Isolated Ground Circuits	Orange	THHN	Black, White, Green	MSTWL-WIG
Solid Wire Leads	White	THHN	Black, White, Green	MSTWL-SDA
Solid Wire Leads for Isolated Ground Circuits	Orange	THHN	Black, White, Green	MSTWL-SIG
Solid Wire Leads with 4-Port Push Wire Connectors	White	THHN	Black, White, Green	MSTWL-WSD
Stranded Wire Leads for Low Leakage Circuits	White	XHHW-2	Brown/Yellow, Orange/Blue, Green/Yellow	MSTWL-XI*
Stranded Wire Leads for Low Leakage Circuits	White	XHHW-2	Black, White, Green/Yellow	MSTWL-XN*

*Add suffix of 0 for 6", 1 for 18", 2 for 24" or 3 for 36" long leads; please allow 4 to 6 weeks for delivery

lev-lok® Circuit Analyzer

Connect the receptacle wiring module to the circuit analyzer to confirm that wiring is correct, or identify a wiring problem.
Catalog Number: LVLOK-TST



Receptacles with Pre-Wired Leads

KEY FEATURES & BENEFITS


- Eliminates the need to make pigtails
- Available in the most common configurations
- No terminal screws means faster wiring and no need to wrap device with electrical tape

HOSPITAL GRADE Heavy-Duty





2-Pole, 3-Wire • 125 Volt

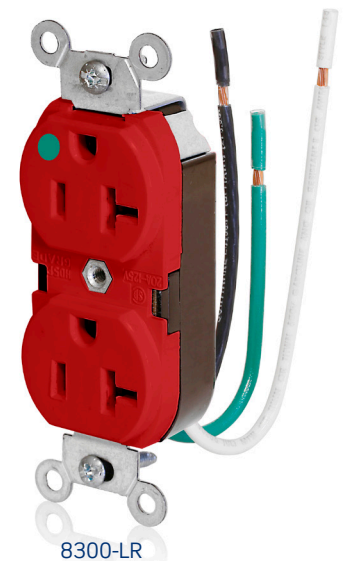STANDARD	Color	NEMA 5-15R		NEMA 5-20R	
		15 Amp	20 Amp	15 Amp	20 Amp
<ul style="list-style-type: none"> • Duplex Receptacle • Smooth Face • Pre-Wired Leads 	White	8200-LW	8300-LW		
	Ivory	8200-LI	8300-LI		
	Brown	8200-L	8300-L		
	Gray	8200-LGY	8300-LGY		
	Black	—		8300-LE	
	Red	8200-LR		8300-LR	
<ul style="list-style-type: none"> • Duplex Receptacle • Smooth Face • Pre-Wired Leads (hot and neutral only) 	White	8200-CW	8300-CW		
	Ivory	8200-CI	8300-CI		
	Gray	8200-CGY	8300-CGY		



smartlockpro® AFCI Receptacles

Outlet Branch Circuit (OBC) AFCI Devices offer advanced technology to help protect against electrical fires. These devices are designed to interrupt power in the event potentially hazardous arcing is detected, which could originate from a number of sources including damaged wires and cords. Meeting the latest UL requirements for OBC AFCI outlets, they provide protection against series and parallel arcs. SmartlockPro® OBC AFCI devices feature Leviton's patented reset lockout and tamper-resistant technology. AFCI's are now required by the National Electrical Code® (NEC) in many areas.

HOSPITAL GRADE Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 	
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp	
DECORA PLUS™ <ul style="list-style-type: none"> • Duplex Receptacle • Power Indication LED • Tamper-Resistant • Back and Side Wire • 20 Amp Feed-Through Terminals • Wallplate Included 		White	AFTR1-HGW	AFTR2-HGW
		Ivory	AFTR1-HGI	AFTR2-HGI
		Lt Almond	AFTR1-HGT	AFTR2-HGT
		Brown	AFTR1-HG	AFTR2-HG
		Gray	AFTR1-HGG	AFTR2-HGG
		Black	AFTR1-HGE	AFTR2-HGE
		Red	AFTR1-HGR	AFTR2-HGR



smartlockpro® GFCI Receptacles

The SmartlockPro® Self-Test GFCIs contain the latest innovation in ground fault protection by automatically conducting a periodic internal test to confirm that the GFCI is able to respond to a ground fault. Easy to install, they take up to 25% less space in the wallbox vs. typical GFCIs and can fit into any box, even shallow ones. These slim GFCIs provide all the lockout benefits of our standard SmartlockPro® offering, and are available in tamper-resistant and non tamper-resistant versions. Constructed of resilient thermoplastic and able to withstand high torque levels, self-test GFCIs come in styles for every need, including a combination guide light/receptacle and a blankface device.



GFWT2-HGW FRONT



GFWT2-HGW SIDE

Protection

smartlockpro® GFCI Receptacles

HOSPITAL GRADE

Extra Heavy-Duty














2-Pole, 3-Wire • 125 Volt

Color

15 Amp


20 Amp

	Color	15 Amp	20 Amp
<ul style="list-style-type: none"> Duplex Receptacle Power Indication LED Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included 	White	GFNT1-HGW	GFNT2-HGW
	Ivory	GFNT1-HGI	GFNT2-HGI
	Lt Almond	GFNT1-HGT	GFNT2-HGT
	Brown	GFNT1-HG	GFNT2-HG
	Gray	GFNT1-HGG	GFNT2-HGG
	Black	GFNT1-HGE	GFNT2-HGE
	Red	GFNT1-HGR	GFNT2-HGR
<ul style="list-style-type: none"> Duplex Receptacle Power Indication LED Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included NAFTA Compliant 	White	GFNT1-HFW	GFNT2-HFW
	Ivory	GFNT1-HFI	GFNT2-HFI
	Lt Almond	GFNT1-HFT	GFNT2-HFT
	Brown	GFNT1-HF	GFNT2-HF
	Gray	GFNT1-HFG	GFNT2-HFG
	Black	GFNT1-HFE	GFNT2-HFE
	Red	GFNT1-HFR	GFNT2-HFR
<ul style="list-style-type: none"> Duplex Receptacle Power Indication LED Tamper-Resistant Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included  	White	GFTR1-HGW	GFTR2-HGW
	Ivory	GFTR1-HGI	GFTR2-HGI
	Lt Almond	GFTR1-HGT	GFTR2-HGT
	Brown	GFTR1-HG	GFTR2-HG
	Gray	GFTR1-HGG	GFTR2-HGG
	Black	GFTR1-HGE	GFTR2-HGE
	Red	GFTR1-HGR	GFTR2-HGR
<ul style="list-style-type: none"> Duplex Receptacle Power Indication LED Tamper-Resistant Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included NAFTA Compliant  	White	GFTR1-HFW	GFTR2-HFW
	Ivory	GFTR1-HFI	GFTR2-HFI
	Lt Almond	GFTR1-HFT	GFTR2-HFT
	Brown	GFTR1-HF	GFTR2-HF
	Gray	GFTR1-HFG	GFTR2-HFG
	Black	GFTR1-HFE	GFTR2-HFE
	Red	GFTR1-HFR	GFTR2-HFR
<ul style="list-style-type: none"> Duplex Receptacle Power Indication LED Weather and Tamper-Resistant Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included   	White	GFWT1-HGW	GFWT2-HGW
	Ivory	GFWT1-HGI	GFWT2-HGI
	Lt Almond	GFWT1-HGT	GFWT2-HGT
	Brown	GFWT1-HG	GFWT2-HG
	Gray	GFWT1-HGG	GFWT2-HGG
	Black	GFWT1-HGE	GFWT2-HGE
	Red	GFWT1-HGR	GFWT2-HGR
<ul style="list-style-type: none"> Duplex Receptacle Tamper-Resistant WHITE Guidelight Power Indication LED Back and Side Wire 20 Amp Feed-Through Terminals Wallplate Included  	White	GFNL1-HGW	GFNL2-HGW
	Ivory	GFNL1-HGI	GFNL2-HGI
	Lt Almond	GFNL1-HGT	GFNL2-HGT
	Brown	GFNL1-HG	GFNL2-HG
	Gray	GFNL1-HGG	GFNL2-HGG
	Black	GFNL1-HGE	GFNL2-HGE
	Red	GFNL1-HGR	GFNL2-HGR

DECORA PLUS™


GFCI Status Indicator Light

Leviton GFCI devices feature an LED Status Indicator Light which provides a visual indication to the user of the status of GFCI protection. This is a convenient way to check the level of protection at-a-glance.

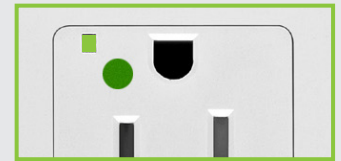

Green LED - Normal Operation.

- GFCI has passed self-test and is providing power

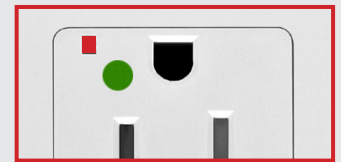

Red LED - Alert!

- Blinking - Initial self-test upon first power up
- Solid or blinking - Press TEST and RESET buttons to reset GFCI
- If GFCI will not reset OR solid or blinking red continues, replace device



No LED - No Power.

- GFCI in tripped state
- Press RESET button
- If GFCI will not reset, no power on the circuit

smartlockpro[®] GFCI Receptacles

HOSPITAL GRADE
Heavy-Duty

2-Pole, 3-Wire • 125 Volt

Color



15 Amp




20 Amp

DECORA PLUS[™]

- Duplex Receptacle
- Tamper-Resistant
- AMBER Guidelight
- Power Indication LED
- Back and Side Wire
- 20 Amp Feed-Through Terminals



Amber guidelight ideal for healthcare applications where disrupting circadian rhythms is a concern

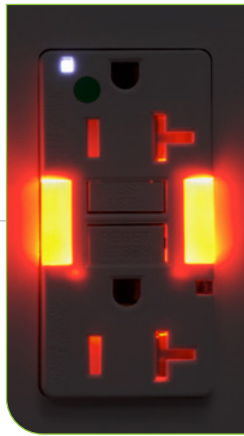

GFNL2-HWA

Protection

Dual Function AFCI/GFCI Status Indicator Light



Solid Green LED.

- Load Power ON.
- RESET button is in. Device is in normal working state.
- Load Power OFF.
- RESET button is out. Line & load wires are reversed.



Solid or Constant Flashing Red LED.

- Load Power ON.
- RESET button is in. Press TEST button & RESET button. If RED indication continues or will not RESET, replace device.
- Load Power OFF.
- RESET button is out. Device has tripped & self-test function detects a potential problem. If RED indication continues or will not RESET, replace device.

smartlockpro[®] Dual Function AFCI/GFCI Receptacles

The SmartlockPro AFCI/GFCI Receptacle offers an effective alternative to a Dual Function breaker and features the convenience of localized test and reset. It provides clear visual indication of status making it intuitive for users to assess various conditions such as power availability and GFCI self-test status. The device also distinguishes between a trip caused by a ground fault and a trip caused by an arc fault.

HOSPITAL GRADE
Heavy-Duty

2-Pole, 3-Wire • 125 Volt

Color



15 Amp



20 Amp

DECORA[®]

- Duplex Receptacle
- Power Indication LED
- Tamper-Resistant
- Back and Side Wire
- 20 Amp Feed-Through Terminals
- Wallplate NOT Included



Color	15 Amp	20 Amp
White	AGTR1-HGW	AGTR2-HGW
Ivory	AGTR1-HGI	AGTR2-HGI
Lt Almond	AGTR1-HGT	AGTR2-HGT
Brown	AGTR1-HG	AGTR2-HG
Gray	AGTR1-HGG	AGTR2-HGG
Black	AGTR1-HGE	AGTR2-HGE
Red	AGTR1-HGR	AGTR2-HGR

LED OFF & Flashes Red Twice Every 5 Seconds.

- Load Power OFF.
- RESET button is out. AFCI trip; press RESET, if device continues to trip, contact an electrician.



LED is OFF.

- Load Power OFF. RESET button is out. GFCI trip; press RESET, if device will not reset, there is no power on the circuit.

Surge Protective Receptacles





The value of these receptacles and ease of installation allow for placement anywhere you have a standard electrical outlet. With a small investment, you have the assurance that your equipment is well protected, from a heart monitor in the emergency room, to a computer in the office, or a big screen TV in the living room.

HOSPITAL GRADE Heavy-Duty		NEMA 5-15R	NEMA 5-20R
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp
<ul style="list-style-type: none"> • Duplex Receptacle • Indicator Light • Back and Side Wire • Wallplate Included 	White	8280-W	8380-W
	Ivory	8280-I	8380-I
	Lt Almond	8280-T	—
	Brown	8280	8380
	Gray	—	8380-GY
	Red	8280-R	8380-R
	Blue	8280-B	8380-B
<ul style="list-style-type: none"> • Single Receptacle • Indicator Light • Audible Alarm • Back and Side Wire • Wallplate Included  	Ivory	—	8381-I
DECORA PLUS™	White	T8280-W	T8380-W
	Ivory	T8280-I	T8380-I
	Lt Almond	T8280-T	—
	Gray	—	T8380-GY
	Red	T8280-R	T8380-R
	Blue	T8280-B	T8380-B
<ul style="list-style-type: none"> • Single Receptacle • Indicator Light • Audible Alarm • Isolated Ground • Back and Side Wire • Wallplate Included   	Ivory	—	8381-IGI
<ul style="list-style-type: none"> • Duplex Receptacle • Indicator Light • Audible Alarm • Isolated Ground • Back and Side Wire • Wallplate Included   	White	8280-IGW	8380-IGW
	Ivory	8280-IGI	8380-IGI
	Gray	—	8380-IGG
	Orange	8280-IGO	8380-IGO
	Blue	8280-IGB	8380-IGB
		 	




4-in-1™ Receptacles

Hospital Grade 4-in-1™ Receptacles provide a simple transition in retrofit applications to comply with new receptacle requirements in health care facilities. These devices allow you to increase the number of receptacles in your facility without having to pull new wires.

HOSPITAL GRADE Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp
<ul style="list-style-type: none"> • Quadruplex Receptacle • Side Wire Only 	White	1254-HW	21254-HW
	Ivory	1254-HI	21254-HI
	Brown	1254-H	21254-H
	Gray	—	21254-HGY
	Red	1254-HR	21254-HR
<ul style="list-style-type: none"> • Quadruplex Receptacle • Isolated Ground • Side Wire Only 	White	—	21254-IGW
	Ivory	—	21254-IGI
	Orange	1254-IG	21254-IG
<ul style="list-style-type: none"> • Quadruplex Receptacle • Surge Protective • Indicator Light • Side Wire Only 	White	8480-W	8490-W
	Ivory	8480-I	8490-I
	Red	8480-R	8490-R
<ul style="list-style-type: none"> • Quadruplex Receptacle • Surge Protective • Isolated Ground • Indicator Light • Side Wire Only 	White	8480-IGW	—
	Ivory	8480-IGI	8490-IGI
	Orange	—	8490-IG
	Blue	8480-IGB	8490-IGB





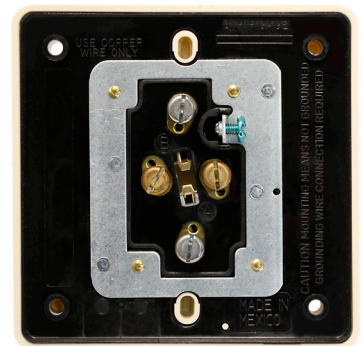

21254-HI (Front)



21254-HI (Back)

USB Receptacles

HOSPITAL GRADE Heavy-Duty		NEMA 5-15R 	NEMA 5-20R 
2-Pole, 3-Wire • 125 Volt		15 Amp	20 Amp
<ul style="list-style-type: none"> • Duplex Receptacle • One Type A & One Type C USB Port (5.1 Amp) • Smooth Face • Tamper-Resistant • Back and Side Wire  	White	T5633-HGW	T5833-HGW
	Ivory	T5633-HGI	T5833-HGI
	Lt Almond	T5633-HGT	T5833-HGT
	Brown	T5633-HG	T5833-HG
	Gray	T5633-HGG	T5833-HGG
	Black	T5633-HGE	T5833-HGE
	Red	T5633-HGR	T5833-HGR



Medical Grade Power Strips

- Conforms to UL 1363A, UL 60601-1, UL 60950-1, and UL 1449
- All outlets and plug are hospital grade, ensuring dependable performance
- Heavy duty steel construction withstands the rigors of demanding environments
- Built-in overload protection shuts off the strip in case of excess power draw, and can be returned to service with the simple push of a button
- Easily accommodates surface mounting; IV pole mounting with the use of mounting bracket (5300M-BKT)

Learn More



Stock Configurations	Current Rating	AC Power Cord Length	2 Outlet	4 Outlet	6 Outlet
Surge Protective Medical Grade Power Strips	15A (12 A max continuous load)	7 Feet	5302M-1S7	5304M-1S7	5306M-1S7
		15 Feet	5302M-1S5	5304M-1S5	5306M-1S5
	20A (16 A max continuous load)	7 Feet	5302M-2S7	5304M-2S7	5306M-2S7
		15 Feet	5302M-2S5	5304M-2S5	5306M-2S5

All strips available with flying leads - contact your Leviton sales representative for details.

Non-surge protective medical grade power strips are also available.
Please visit leviton.com/medstrips for more information.

Additional Accessories

Replacement Outlet Covers
Each will cover two outlets
5300M-CVR



Mounting Bracket
Includes top and bottom mounting mechanisms
5300M-BKT



Surge Protective Strips

- Feature metal housing, ON/OFF switch, and tamper-resistant outlets
- Includes audible alarm at protection loss
- 6 Foot Cord Length
- Multi-line protection (L-N, L-G, N-G)
- Onboard resettable circuit breaker



Industrial Grade

Ordering Guide: Surge Protective Strips

Catalog Number	Application	Maximum Input Current	Joules
5100-IPS	Industrial	15 Amp	1330
5100-IS2		20 Amp	900

Visit our Website at:
leviton.com/receptaclegrades

Leviton Canada
165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9
Telephone: 1-800-461-2002 • FAX: 1-800-563-1853
Tech Line: 1-800-405-5320