


Lever Edge™

THE FUTURE OF WIRING
IS AS EASY AS...

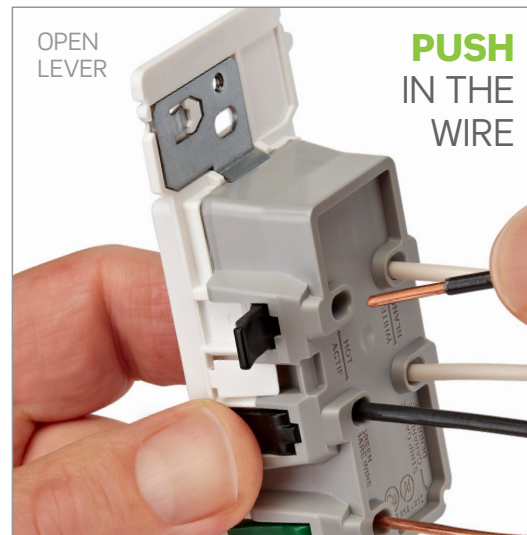

EXPERIENCE A NEW UL APPROVED TERMINATION METHOD FOR WIRING DEVICES

- EASY INSTALLATIONS
- TIME AND LABOR SAVINGS
- SAFE AND SECURE WIRING





**ACCEPTS MULTIPLE COPPER
WIRE SIZES AND TYPES**



INCREASED SAFETY
NO EXPOSED METAL PARTS

INDUSTRY-FIRST UL CERTIFIED
RAPID SCREWLESS GROUNDING
WIRE TERMINATION

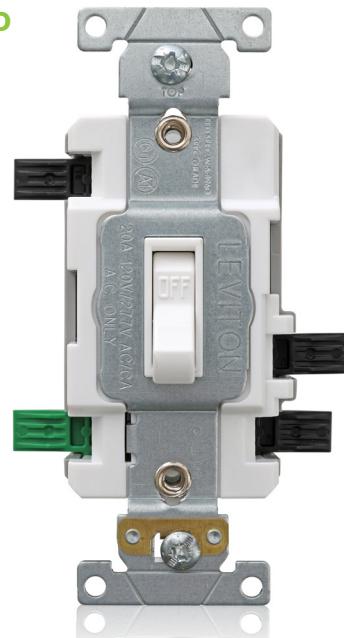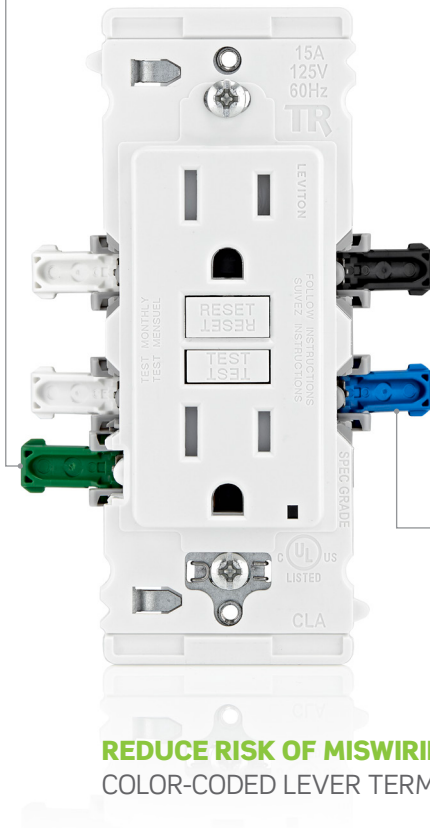

UNIQUE BLUE LEVER
QUICKLY IDENTIFIES THE LOAD
HOT CONNECTION TO MINIMIZE
LINE/LOAD REVERSAL
RISK ON GFCIS

REDUCE RISK OF MISWIRING
COLOR-CODED LEVER TERMINALS

ON THE JOB, TIME IS MONEY!

SAVE TIME AND LABOR WITH FAST AND EASY INSTALLS.

TONGUE AND GROOVE DESIGN
FOR EASIER ALIGNMENT IN
MULTI-GANG INSTALLATIONS*



LONGER AND WIDER STRAP
COMPATIBLE WITH MIDWAY WALLPLATES,
AND WITH STANDARD SIZED WALLPLATES
WHEN BREAKAWAY TAB IS REMOVED*

*On residential switches and receptacles



NEED TO RE-WIRE?
SIMPLY RE-OPEN THE LEVER
AND TAKE OUT THE WIRE.
NO STRUGGLE.


**WIRING THAT GETS
BETTER WITH TIME!**
AFTER SUBJECT TO VIBRATION,
WIRE RETENTION RESULTS
INCREASED BY ALMOST 40%**

**On commercial switches and receptacles using 10AWG


STRONG, SECURE WIRING CONNECTIONS

WE MEET UP TO **3.8X THE UL REQUIREMENTS**
FOR WIRE RETENTION PULL FORCE*


**DURABLE
NYLON HOUSING**
WITH HB OR BETTER
FLAMMABILITY
RATINGS

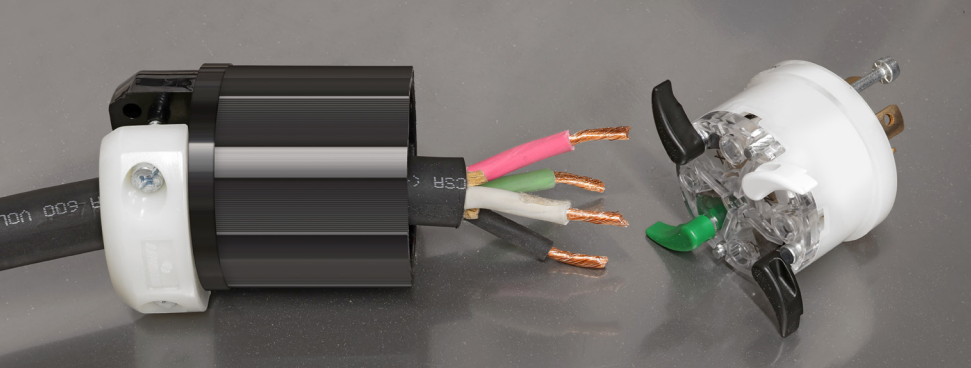

SECURE GRIP
WIDER RIBS ON HOUSING
STRENGTHENS GRIP WHILE
INSTALLING

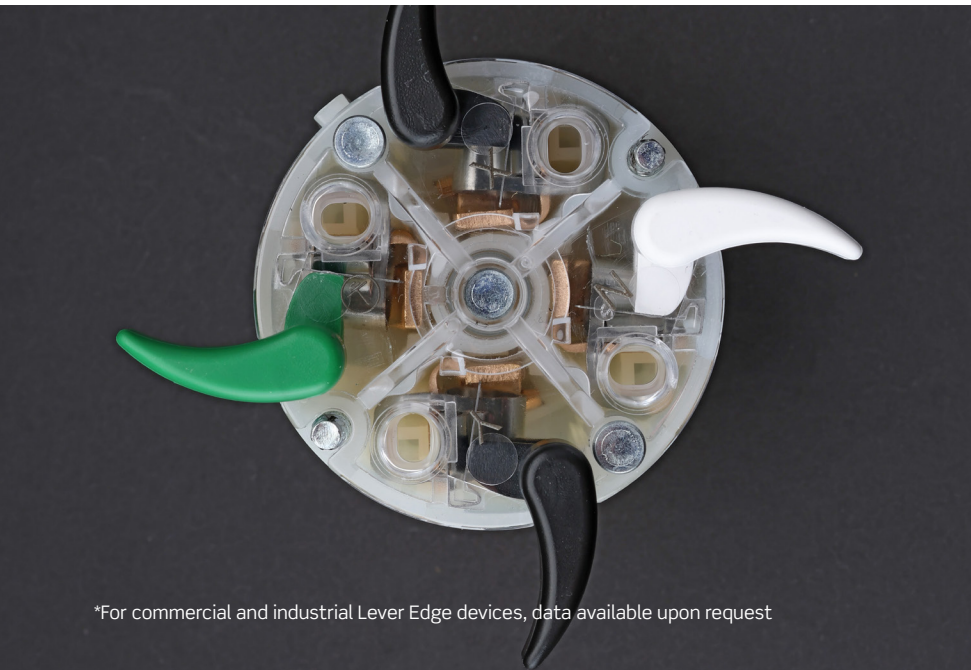

EASY TO VIEW STATUS
CLEAR BACK COVER TO EASILY
VIEW CONNECTION STATUS

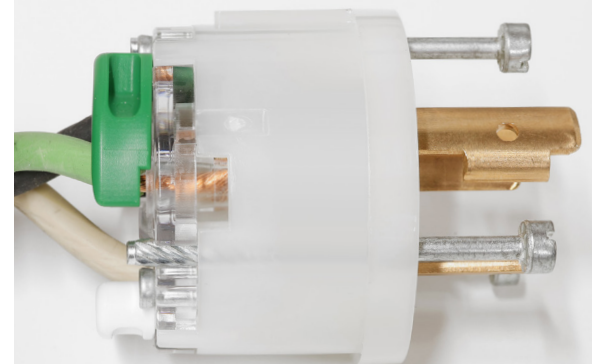

*For commercial and industrial Lever Edge devices, data available upon request

ORDERING INFORMATION

RESIDENTIAL GRADE DEVICES

RECEPTACLES

Cat. No.	Rating	Description
EGFT1-W	15 Amp / 20 Amp Feed-Through, 125 Volt	Tamper-Resistant GFCI, White
EGFW1-H0W	15 Amp / 20 Amp Feed-Through, 125 Volt	Weather- and Tamper-Resistant GFCI, White
E5325-W	15 Amp / 20 Amp Feed-Through, 125 Volt	Tamper-Resistant Decora Receptacle, White
E5825-W	15 Amp / 20 Amp Feed-Through, 125 Volt	Tamper-Resistant Decora Receptacle, White

SWITCHES

Cat. No.	Rating	Description
E5601-W	15 Amp 120/277 Volt	Single Pole Rocker Switch
E5603-W	15 Amp 120/277 Volt	3-Way Rocker Switch

DIMMER

Cat. No.	Rating	Description
ESL01-1LW	120 Volt 60 Hz 150 W LED/CFL/INC	Decora Slide Dimmer

COMMERCIAL GRADE DEVICES

RECEPTACLES

Cat. No.	Rating	Description
E5262-S*	15 Amp 125 Volt	Duplex Receptacle
E5362-S*	20 Amp 125 Volt	Duplex Receptacle
ET562-**	15 Amp 125 Volt	Tamper-Resistant Duplex Receptacle
ET563-**	20 Amp 125 Volt	Tamper-Resistant Duplex Receptacle

SWITCHES

Cat. No.	Rating	Description
E1221-S*	20 Amp 120/277 Volt	Single Pole Toggle Switch

*I=Ivory, W=White, E=Black, G(**GY)=Gray, R=Red

BLACK & WHITE

PLUGS

Cat. No.	NEMA Configuration
5266E	NEMA 5-15P
5366E	NEMA 5-20P
2311E	NEMA L5-20P
5466E	NEMA 6-20P
2321E	NEMA L6-20P
2621E	NEMA L6-30P
4770E	NEMA L7-15P
2411E	NEMA L14-20P
2711E	NEMA L14-30P

CONNECTORS

Cat. No.	NEMA Configuration
5269E	NEMA 5-15R
5369E	NEMA 5-20R



**THE FUTURE
OF WIRING
IS HERE.**



FOR PRODUCT DETAILS & ORDERING INFORMATION

Scan or Visit
leviton.com/leveredge

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2025 Leviton Manufacturing Co., Inc. All rights reserved.
NEC® is a registered trademark of the National Fire Protection Association, Quincy, MA 02169