



HOSPITAL GRADE • COMMERCIAL SPECIFICATION GRADE


USB Receptacles

Fast, powerful charging engineered for optimized performance



Fast Charging

LINE CARD

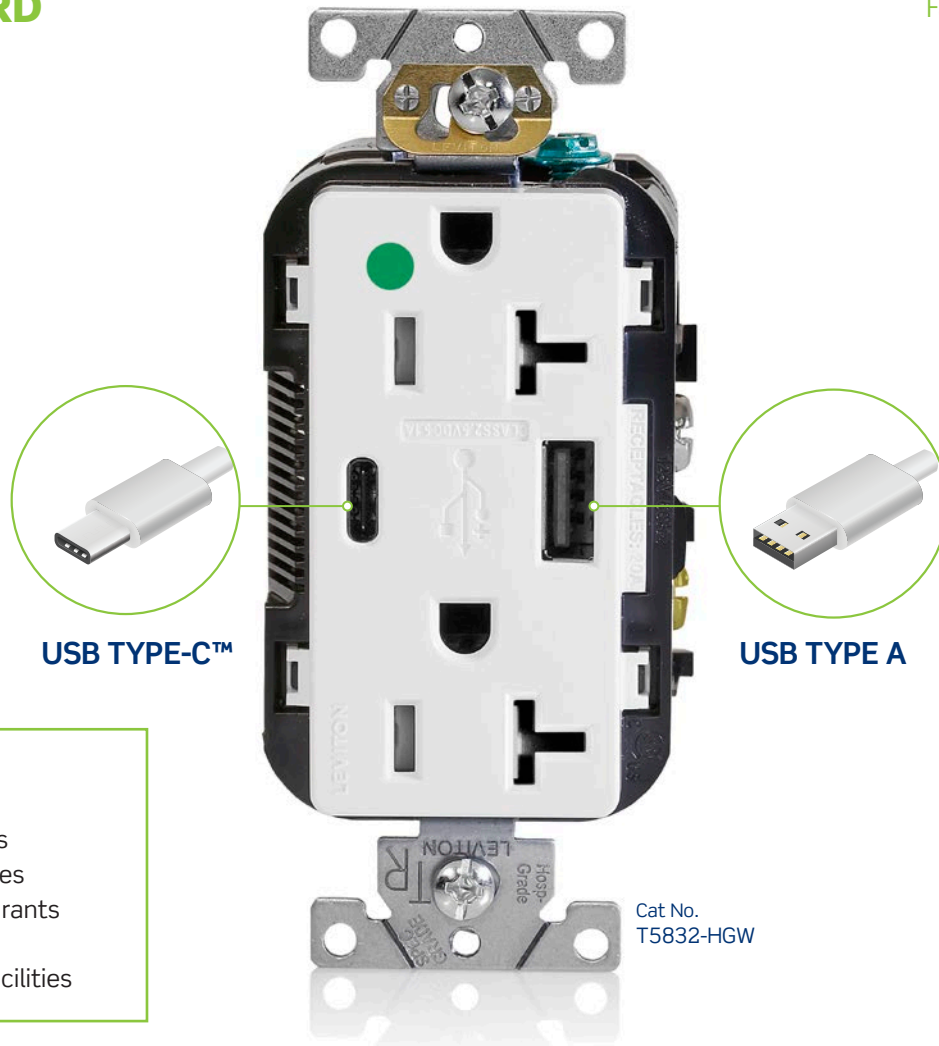

USB TYPE-C™

USB TYPE A

Cat No.
T5832-HGW

IDEAL FOR...

- Offices
- College Dorms
- Airport Lounges
- Cafes/Restaurants
- Hotels
- Healthcare Facilities

INNOVATIVE

- Smart chip technology recognizes the charging requirements of connected devices, efficiently managing power output to each
- Power Delivery (PD): Supplies a higher level of power to the latest Type-C PD-enabled devices for faster charging

SAFE

- Overcurrent protection on USB ports helps protect electronics from receiving too much power, which can damage devices
- Internal regulator on USB ports prevents electronics from overheating
- Tamper-resistant receptacles



COMMERCIAL SPECIFICATION GRADE USB RECEPTACLES



Fast Charging

SYMBOLS TO SIMPLIFY BROWSING



Tamper-Resistant



Power Indication



Weather-Resistant



Leaded



Lev-lok® Modular Wiring Devices

COMMERCIAL SPECIFICATION GRADE



2-Pole, 3-Wire • 125 Volt	Color	15 Amp	20 Amp
<ul style="list-style-type: none"> Two Type A USB Ports (3.6 Amp) Back and Side Wire 	White	T5632-W	—
	Ivory	T5632-I	T5832-I
	Lt Almond	T5632-T	T5832-T
	Brown	T5632	T5832
	Gray	T5632-GY	T5832-GY
	Black	T5632-E	T5832-E
<ul style="list-style-type: none"> One Type A & One Type C USB Port (5.1 Amp) Back and Side Wire 	White	T5633-W	T5833-W
	Ivory	T5633-I	T5833-I
	Lt Almond	T5633-T	T5833-T
	Brown	T5633	T5833
	Gray	T5633-GY	T5833-GY
	Black	T5633-E	T5833-E
<ul style="list-style-type: none"> One Type A & One Type C USB Port (5.1 Amp) 	White	W5633-W	W5833-W
	Black	T5635-E	T5835-E
<ul style="list-style-type: none"> Two Type C USB Ports (6 Amp, 30W) Back and Side Wire 	White	T5635-W	T5835-W
	Ivory	T5635-I	T5835-I
	Lt Almond	T5635-T	T5835-T
	Brown	—	T5835-B
	Gray	T5635-G	T5835-G



Cat. No. T5832-T

COMMERCIAL SPECIFICATION GRADE USBs WITH EXTRA PROTECTION

Solutions for peace of mind no matter the application!

WEATHER-RESISTANT



2-Pole, 3-Wire • 125 Volt
(White only)

- One Type A & One Type C USB Port (5.1 Amp)

ORDERING INFORMATION
15 Amp: W5633-W (Pictured)
20 Amp: W5833-W



USB/GFCI COMBINATION DEVICE



2-Pole, 3-Wire • 125 Volt
(White only)

- One Type A & One Type C USB Port (4.8 Amp)

ORDERING INFORMATION
15 Amp: GUAC1-W (Pictured)
20 Amp: GUAC2-W

- Two Type A USB Ports (4.8 Amp)

ORDERING INFORMATION
15 Amp: GUSB1-W
20 Amp: GUSB2-W






Fast Charging

HEAVY-DUTY HOSPITAL GRADE USB RECEPTACLES




Why choose a Hospital Grade USB Receptacle?

The extra-stringent testing requirements Hospital Grade devices must pass gives you the assurance that this receptacle can handle punishing environments and applications.

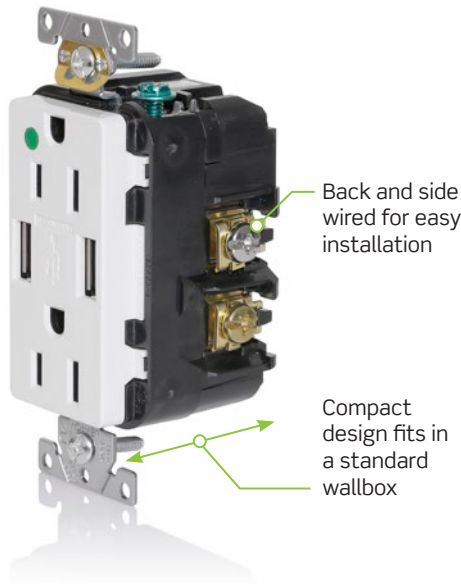

Back and side wired for easy installation

Compact design fits in a standard wallbox

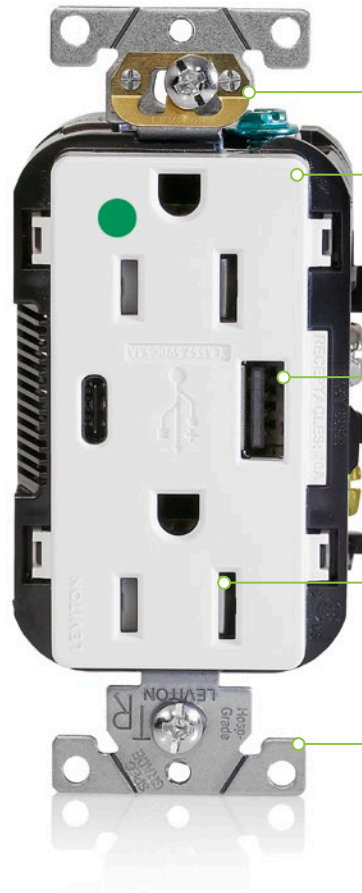

Brass Self-Grounding Clip

Impact and chemical resistant PBT face provides longer service life

USB ports optimally spaced for simultaneous use, easy maneuvering and reduced USB cable stress

Tamper-resistant shutters meet NEC Article 406.12 requirements



Improved strap design provides greater support, even with ears removed

HOSPITAL GRADE Heavy-Duty

2-Pole, 3-Wire • 125 Volt



15 Amp



20 Amp

- Two Type A USB Ports (3.6 Amp)
- Back and Side Wire



- One Type A & One Type C USB Port (5.1 Amp)
- Back and Side Wire



Color	15 Amp	20 Amp
White	T5632-HGW	T5832-HGW
Ivory	T5632-HGI	T5832-HGI
Lt Almond	T5632-HGT	T5832-HGT
Brown	T5632-HG	T5832-HG
Gray	T5632-HGG	T5832-HGG
Black	T5632-HGE	T5832-HGE
Red	T5632-HGR	T5832-HGR
White	T5633-HGW	T5833-HGW
Ivory	T5633-HGI	T5833-HGI
Lt Almond	T5633-HGT	T5833-HGT
Brown	T5633-HG	T5833-HG
Gray	T5633-HGG	T5833-HGG
Black	T5633-HGE	T5833-HGE
Red	T5633-HGR	T5833-HGR

DECORA PLUS™



Cat. No. T5833-HGG



Fast Charging

lev-lok® Modular Receptacles

A mating MSTWL Lev-lok wiring device module is required for use, sold separately

COMMERCIAL SPECIFICATION GRADE



2-Pole, 3-Wire • 125 Volt

Color

15 Amp

20 Amp

- Two Type A USB Ports

White	M56AA-W	M58AA-W
Ivory	M56AA-I	M58AA-I
Lt Almond	M56AA-T	M58AA-T
Brown	M56AA	M58AA
Gray	M56AA-GY	M58AA-GY
Black	M56AA-E	M58AA-E
Red	M56AA-R	M58AA-R
Orange	M56AA-O	M58AA-O
Green	M56AA-N	M58AA-N
Blue	M56AA-B	M58AA-B



- One Type A & One Type C USB Port

White	M56AC-W	M58AC-W
Ivory	M56AC-I	M58AC-I
Lt Almond	M56AC-T	M58AC-T
Brown	M56AC	M58AC
Gray	M56AC-GY	M58AC-GY
Black	M56AC-E	M58AC-E
Red	M56AC-R	M58AC-R
Orange	M56AC-O	M58AC-O
Green	M56AC-N	M58AC-N
Blue	M56AC-B	M58AC-B



DECORA PLUS™

HOSPITAL GRADE

Heavy-Duty



2-Pole, 3-Wire • 125 Volt

Color

15 Amp

20 Amp

- Two Type A USB Ports

White	M56AA-HGW	M58AA-HGW
Ivory	M56AA-HGI	M58AA-HGI
Lt Almond	M56AA-HGT	M58AA-HGT
Brown	M56AA-HG	M58AA-HG
Gray	M56AA-HGG	M58AA-HGG
Black	M56AA-HGE	M58AA-HGE
Red	M56AA-HGR	M58AA-HGR



- One Type A & One Type C USB Port

White	M56AC-HGW	M58AC-HGW
Ivory	M56AC-HGI	M58AC-HGI
Lt Almond	M56AC-HGT	M58AC-HGT
Brown	M56AC-HG	M58AC-HG
Gray	M56AC-HGG	M58AC-HGG
Black	M56AC-HGE	M58AC-HGE
Red	M56AC-HGR	M58AC-HGR



DECORA PLUS™



Lev-lok devices are the perfect productivity solution for electrical construction and maintenance applications. Designed for easy installation and swap-outs, they provide safe, secure connections and lower the risk of incorrect installation.



Cat. No. M56AA-W with MSTWL Wiring Module

Visit our Website at:
leviton.com/receptaclegrades
email: commercial@leviton.com

Leviton Manufacturing Co., Inc.
201 N Service Rd, Melville, NY 11747
Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)