



International
Dock Products

ORDER FORM

Flexmaster Dock Fenders: Unmounted & Mounted


DOCK PROTECTION:

- Protects boats and docks from impact - Flexmaster dock fenders provide reliable cushioning to help prevent scratches, dents, and hull damage when docking
- Durable, marine-ready PVC - constructed from strong yet flexible extruded PVC material designed to withstand harsh marine environments, heavy use, and UV exposure
- Flexible shape for absorption - the Flexmaster profile absorbs impact and distributes pressure to reduce wear on both dock and boat

WARRANTY:

- 2-Year Limited

Shown here
Mounted,
with Optional
Aluminum
Fender
Bracket

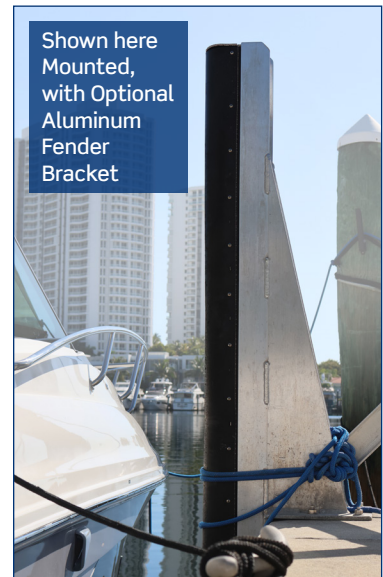

Unmounted
White

2" x 4"
Mounted
Gray

4" x 4"
Mounted
Black

DATE:

JOB NAME:

DISTRIBUTOR NAME & ACCOUNT NUMBER:

CITY:

STATE:

ZIP:

PO NUMBER:

CONTACT NAME:

EMAIL:

PHONE:

LEVITON SALES PERSON:



Visit our Website at:
www.leviton.com/powerpedestals
email: industrial@leviton.com

26-CI-0056

082826

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2026 Leviton Manufacturing Co., Inc. All rights reserved.

Unmounted Dock Fenders

Fenders can be installed vertically or horizontally



ORDERING NUMBER:

Ordering example: FMU-11FT-BK

FMU - -

1 2 3

1 MODEL OVERVIEW

FMU Flexmaster Unmounted Dock Fender – Made from extruded PVC.
Configurable length and color.

 
2 EXTRUSION LENGTH

2FT 2 Feet
3FT 3 Feet
4FT 4 Feet
5FT 5 Feet
6FT 6 Feet
7FT 7 Feet
8FT 8 Feet
9FT 9 Feet
10FT 10 Feet
11FT 11 Feet
12FT 12 Feet
13FT 13 Feet
14FT 14 Feet
15FT 15 Feet
16FT 16 Feet

3 EXTRUSION COLOR

BK Black
GY Gray
WT White

Example of Unmounted Dock Fender. (Does not include a mounting board beneath the PVC fender.)



← Dock Fender

COMPLETED NUMBER (APPEARS IN SPACE BELOW):

QUANTITY:

CUSTOMER
SIGNATURE

(Indicates build approval)



With this signature the customer acknowledges being advised that these Made-To-Order fenders are non-cancelable, non-refundable, and non-returnable.

Mounted Dock Fenders

Fenders can be installed vertically or horizontally



ORDERING NUMBER:

Ordering example: FMM-544-BK-CB-7FB-4U-3D

FMM - - - - -

1 2 3 4 5 6 7

1 MODEL OVERVIEW

FMM Flexmaster Mounted Dock Fender – Made from PVC and mounted to either a 2" x 4" or a 4" x 4" recycled plastic mounting board. Configurable length and extrusion color with matching optional plastic end caps. An optional aluminum Fender Bracket is available only when mounted to a 4" x 4" board, with configurable length and vertical (above/below dock) dimensions.

2 FENDER & MOUNTING BOARD SIZES

224	2 Feet – 2" x 4" Mounted
324	3 Feet – 2" x 4" Mounted
424	4 Feet – 2" x 4" Mounted
524	5 Feet – 2" x 4" Mounted
624	6 Feet – 2" x 4" Mounted
724	7 Feet – 2" x 4" Mounted
824	8 Feet – 2" x 4" Mounted
924	9 Feet – 2" x 4" Mounted
1024	10 Feet – 2" x 4" Mounted
1124	11 Feet – 2" x 4" Mounted
1224	12 Feet – 2" x 4" Mounted
1324	13 Feet – 2" x 4" Mounted
1424	14 Feet – 2" x 4" Mounted
1524	15 Feet – 2" x 4" Mounted
1624	16 Feet – 2" x 4" Mounted
244	2 Feet – 4" x 4" Mounted
344	3 Feet – 4" x 4" Mounted
444	4 Feet – 4" x 4" Mounted
544	5 Feet – 4" x 4" Mounted
644	6 Feet – 4" x 4" Mounted
744	7 Feet – 4" x 4" Mounted
844	8 Feet – 4" x 4" Mounted
944	9 Feet – 4" x 4" Mounted
1044	10 Feet – 4" x 4" Mounted
1144	11 Feet – 4" x 4" Mounted
1244	12 Feet – 4" x 4" Mounted
1344	13 Feet – 4" x 4" Mounted
1444	14 Feet – 4" x 4" Mounted
1544	15 Feet – 4" x 4" Mounted
1644	16 Feet – 4" x 4" Mounted

3 FENDER COLOR

BK	Black
GY	Gray
WT	White

4 FENDER BRACKET

NB	No Bracket
CB	Custom Bracket

5 FENDER BRACKET LENGTH

NA	N/A, No Bracket
2FB	2 Foot Bracket
3FB	3 Foot Bracket
4FB	4 Foot Bracket
5FB	5 Foot Bracket
6FB	6 Foot Bracket
7FB	7 Foot Bracket
8FB	8 Foot Bracket
9FB	9 Foot Bracket
10FB	10 Foot Bracket

6 BRACKET UPPER HEIGHT

NU	N/A, No Bracket
1U	1 Foot Above Dock
2U	2 Feet Above Dock
3U	3 Feet Above Dock
4U	4 Feet Above Dock
5U	5 Feet Above Dock
6U	6 Feet Above Dock
7U	7 Feet Above Dock
8U	8 Feet Above Dock

7 BRACKET LOWER HEIGHT

NL	N/A, No Bracket
1D	1 Foot Below Dock
2D	2 Feet Below Dock
3D	3 Feet Below Dock
4D	4 Feet Below Dock
5D	5 Feet Below Dock
6D	6 Feet Below Dock
7D	7 Feet Below Dock
8D	8 Feet Below Dock

NOTES: Optional fender brackets are available only with 4" x 4" mounted fenders.


If ordering a 2" x 4" mounted fender, or if a bracket is not required for a 4" x 4" mounted fender, the following default selections apply:

- FENDER BRACKET = NB (No Bracket)
- FENDER BRACKET LENGTH = NA (N/A, No Bracket)
- BRACKET UPPER HEIGHT = NU (N/A, No Bracket)
- BRACKET LOWER HEIGHT = NL (N/A, No Bracket)

Configurable length and extrusion color with matching plastic end cap

Screws (Included with Optional Bracket Assembly)

Example of 4" x 4" Mounted Fender with Optional Bracket Assembly

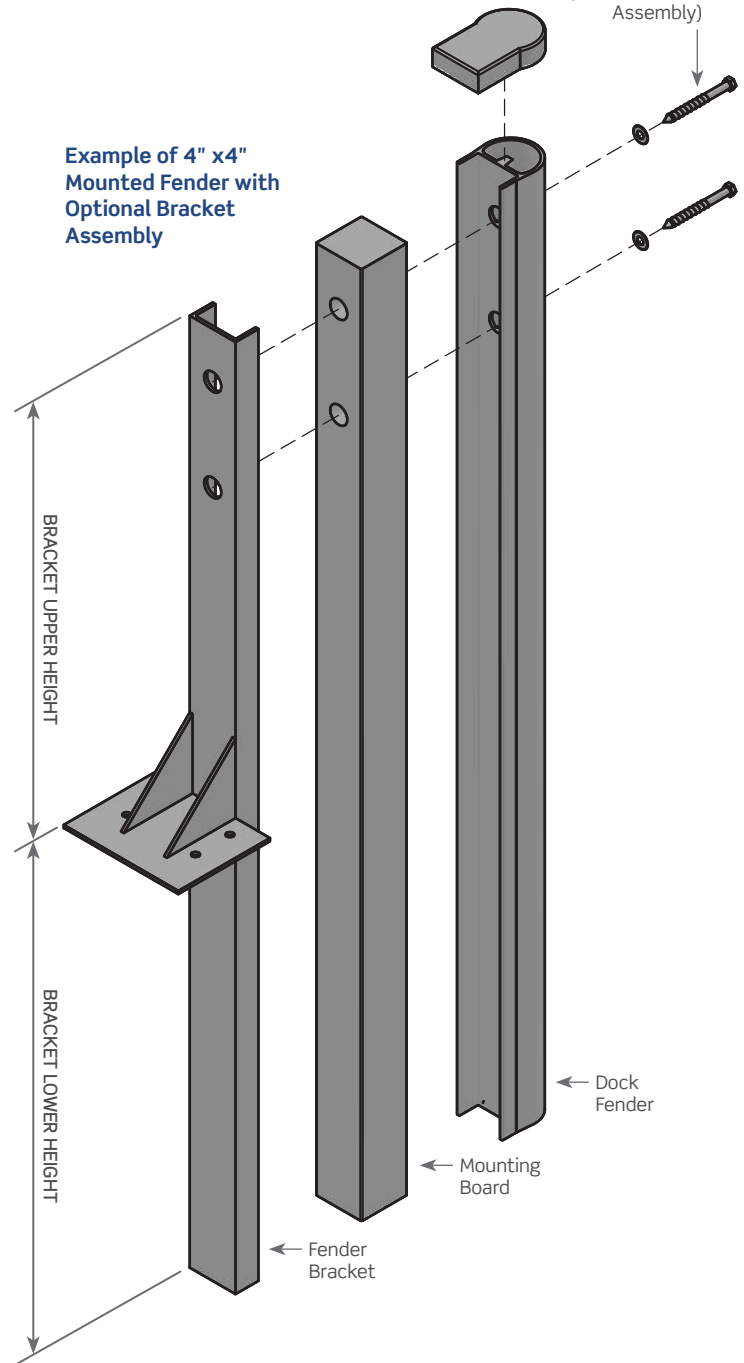

COMPLETED NUMBER (APPEARS IN SPACE BELOW):

QUANTITY:

CUSTOMER SIGNATURE

(Indicates build approval)



With this signature the customer acknowledges being advised that these Made-To-Order fenders are non-cancelable, non-refundable, and non-returnable.