



International
Dock Products

ORDER FORM

Custom 36-Inch Metallic Power Pedestal



POWER PEDESTALS FOR MARINE:


- Built from corrosion-resistant aluminum - withstands harsh waterfront environments
- Engineered for extreme marine conditions - designed to resist saltwater, UV exposure, and extreme outdoor conditions for dependable performance year-round
- Safe, high quality power distribution - provides reliable electrical connections

STANDARDS:

- NEMA 3R, UL 231, NFPA 303, NFPA 70

WARRANTY:

- Housing: 15 years
- Construction/Fabrication: 2 years
- Wiring Devices: 1 year

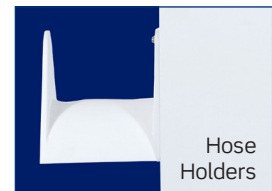

Hose
Holders



Hose
Hooks



Water
Faucets

DATE:

JOB NAME:

DISTRIBUTOR NAME & ACCOUNT NUMBER:

CITY:

STATE:

ZIP:

PO NUMBER:

CONTACT NAME:

EMAIL:

PHONE:

LEVITON SALES PERSON:



Visit our Website at:
www.leviton.com/powerpedestals
email: industrial@leviton.com

26-CI-0055

080526

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2026 Leviton Manufacturing Co., Inc. All rights reserved.

Ordering example: P36-50S2-50S2-20S-20S-LF-LW-PC-M0-RM0-W1-NH



P36	-	-	-	-	-	-	-	-	-	-	-	-	-	-
	1	2	3	4	5	6	7	8	9	10	11	12	13	14

1 PEDESTAL MODEL

P36 Metallic 36" Dock Mount Power Pedestal - Includes one-piece extruded aluminum housing with powder-coated finish, integrated lighting, pre-wired power distribution block, powder coated aluminum angled receptacle covers, and dock-mount base gasket.

2 RECEPTACLE Device Location A - Right		3 RECEPTACLE Device Location B - Right		4 RECEPTACLE Device Location C - Left		5 RECEPTACLE Device Location D - Left	
R0	No Receptacle	R0	No Receptacle	R0	No Receptacle	R0	No Receptacle
20S	20A GFI Recept. + Std. Brkr. + Cvr.	20S	20A GFI Recept. + Std. Brkr. + Cvr.	20S	20A GFI Recept. + Std. Brkr. + Cvr.	20S	20A GFI Recept. + Std. Brkr. + Cvr.
30S	30A (125V) Recept. + Std. Brkr. + Cvr.	30S	30A (125V) Recept. + Std. Brkr. + Cvr.	30S	30A (125V) Recept. + Std. Brkr. + Cvr.	30S	30A (125V) Recept. + Std. Brkr. + Cvr.
30E	30A (125V) Recept. + 30mA EPD Brkr. + Cvr.	30E	30A (125V) Recept. + 30mA EPD Brkr. + Cvr.	30E	30A (125V) Recept. + 30mA EPD Brkr. + Cvr.	30E	30A (125V) Recept. + 30mA EPD Brkr. + Cvr.
50S	50A (125V) Recept. + Std. Brkr. + Cvr.	50S	50A (125V) Recept. + Std. Brkr. + Cvr.	50S	50A (125V) Recept. + Std. Brkr. + Cvr.	50S	50A (125V) Recept. + Std. Brkr. + Cvr.
50E	50A (125V) Recept. + 30mA EPD Brkr. + Cvr.	50E	50A (125V) Recept. + 30mA EPD Brkr. + Cvr.	50E	50A (125V) Recept. + 30mA EPD Brkr. + Cvr.	50E	50A (125V) Recept. + 30mA EPD Brkr. + Cvr.
50S2	50A (125/250V) Recept. + Std. Brkr. + Cvr.	50S2	50A (125/250V) Recept. + Std. Brkr. + Cvr.	50S2	50A (125/250V) Recept. + Std. Brkr. + Cvr.	50S2	50A (125/250V) Recept. + Std. Brkr. + Cvr.
50E2	50A (125/250V) Recept. + 30mA EPD Brkr. + Cvr.	50E2	50A (125/250V) Recept. + 30mA EPD Brkr. + Cvr.	50E2	50A (125/250V) Recept. + 30mA EPD Brkr. + Cvr.	50E2	50A (125/250V) Recept. + 30mA EPD Brkr. + Cvr.
50EV	50A (125/250V) EV Recept. (14-50R) + Std. Brkr. + Cvr.	50EV	50A (125/250V) EV Recept. (14-50R) + Std. Brkr. + Cvr.	50EV	50A (125/250V) EV Recept. (14-50R) + Std. Brkr. + Cvr.	50EV	50A (125/250V) EV Recept. (14-50R) + Std. Brkr. + Cvr.
				HH	Hose Holder - Pwdr Coated Aluminum	HH	Hose Holder - Pwdr Coated Aluminum
6 DISTRIBUTION		8 LIGHTING CONTROL		11 WATER FAUCET		13 SPARE BREAKER OPTION 1	
DF	Direct Feed	PC	Photocell	W0	No Water Service	B0	No Spare Breaker
LF	Loop/Series Feed	MB	Manual/breaker	W1	3/4" Water Faucet, 1/4 Turn Ball Valve - QTY 1	B20	20A 1-Pole Spare Breaker
				W2	3/4" Water Faucet, 1/4 Turn Ball Valve - QTY 2	B2G	20A 1-Pole GFI Spare Breaker
7 LIGHTING		9 ELECTRICAL METER				B30	30A 1-Pole Spare Breaker
LW	White (Std. White Lens)	M0	No Electrical Meter	12 HOSE HOOKS		B3G	30A 1-Pole GFI Spare Breaker
LA	Amber (Amber Translucent Lens)	M1	Electrical Meter - QTY 1	NH	No Hooks	B3E	30A 1-Pole EPD Spare Breaker
LR	Red (Red Translucent Lens)	M2	Electrical Meter - QTY 2	AH	Aluminum Hose Hooks - QTY 2	B3D	30A 2-Pole EPD Spare Breaker
LB	Blue (White Lens w/Blue Internal Tubing)					B50	50A 2-Pole Spare Breaker
LG	Green (White Lens w/Green Internal Tubing)	10 REMOTE MONITORING					
LO	Orange (White Lens w/Orange Internal Tubing)	RM0	No Remote Monitoring			14 SPARE BREAKER OPTION 2	
FL	Fluorescent	RM1	Remote Monitoring Enabled			B00	No Spare Breaker
						B202	20A 1-Pole Spare Breaker
						B2G2	20A 1-Pole GFI Spare Breaker
						B302	30A 1-Pole Spare Breaker
						B3G2	30A 1-Pole GFI Spare Breaker

NOTES: Maximum 4 receptacles, but no 100A receptacles due to space constraints.
Spare breaker availability is subject to remaining breaker panel capacity after receptacles are selected.
High-amperage receptacle combinations may limit or prevent spare breaker selection.
Outlying configurations will be reviewed during quoting or engineering validation.

COMPLETED NUMBER (APPEARS IN SPACE BELOW):

QUANTITY:

**CUSTOMER
SIGNATURE**



With this signature the customer acknowledges being advised that these Made-To-Order pedestals are non-cancelable, non-refundable, and non-returnable.

