



ArcArrest[®] Switch-Rated Pin & Sleeve

Providing a local means of disconnect as required by NEC, rated for both branch and motor circuit disconnects.

Engineered for safety and compliance

- No exposure to live electrical components or arc flash, even when operating under load
- Lockout/tagout provisions in both plug and receptacle allow for fast compliance with OSHA
- Meet UL1682 and UL2682 requirements
- Meet NEC Requirements of Line-of-Sight Disconnects

One solution, endless flexibility


- Integrates both a wall-mounted disconnect and plug and connector, providing you more flexibility and portable applications
- Simplified ordering with just one part number

Withstand harsh industrial conditions

- Eliminates ingress of dust, water, and high-temperature, high-pressure washdowns with Type 4X and IP69K ratings
- Maintains a watertight seal whether connected or disconnected - when unmated, devices remain protected with receptacle lid or plug cap

Common Applications:

- Wastewater Treatment Facilities
- Food & Beverage Manufacturing
- Industrial Manufacturing
- Temporary Power Applications
- Data Centers
- Power Generation
- Oil & Gas

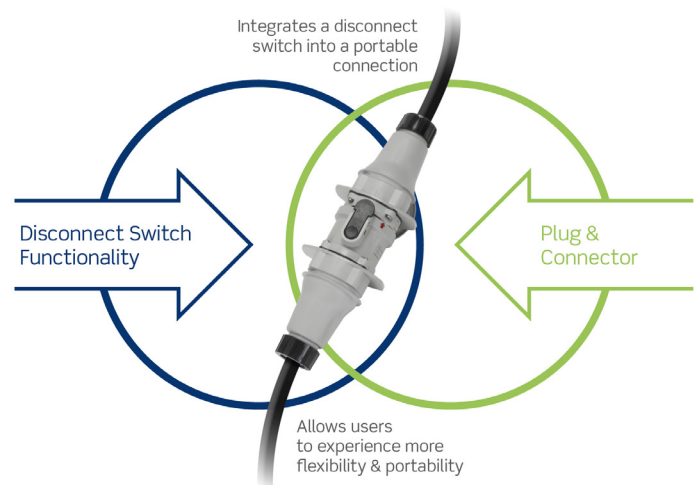

30 Amp Ordering Chart

Voltage	Polarity	Plug w/Handle and Drawplate	Plug w/ Handle	Connector w/Handle and Drawplate	Connector w/Handle	Receptacle	Receptacle w/70° Angle	Inlet	Inlet w/70° Angle
125	1P+N+G	ARC30PD075	ARC30P075	ARC30CD075	ARC30C075	ARC30R075	ARC30RA075	ARC30B075	ARC30BA075
250	2P+G	ARC30PD072	ARC30P072	ARC30CD072	ARC30C072	ARC30R072*	ARC30RA072	ARC30B072*	ARC30BA072
3Ø250	3P+G	ARC30PD073	ARC30P073	ARC30CD073	ARC30C073	ARC30R073*	ARC30RA073	ARC30B073*	ARC30BA073
125/250	2P+N+G	ARC30PD076	ARC30P076	ARC30CD076	ARC30C076	ARC30R076	ARC30RA076	ARC30B076	ARC30BA076
208	2P+G	ARC30PD162	ARC30P162	ARC30CD162	ARC30C162	ARC30R162*	ARC30RA162	ARC30B162*	ARC30BA162
3Ø208	3P+G	ARC30PD163	ARC30P163	ARC30CD163	ARC30C163	ARC30R163*	ARC30RA163	ARC30B163*	ARC30BA163
3ØY120/208	3P+N+G	ARC30PD167	ARC30P167	ARC30CD167	ARC30C167	ARC30R167	ARC30RA167	ARC30B167	ARC30BA167
277	1P+N+G	ARC30PD045	ARC30P045	ARC30CD045	ARC30C045	ARC30R045	ARC30RA045	ARC30B045	ARC30BA045
480	2P+G	ARC30PD042	ARC30P042	ARC30CD042	ARC30C042	ARC30R042*	ARC30RA042	ARC30B042*	ARC30BA042
3Ø480	3P+G	ARC30PD043	ARC30P043	ARC30CD043	ARC30C043	ARC30R043*	ARC30RA043	ARC30B043*	ARC30BA043
3ØY277/480	3P+N+G	ARC30PD047	ARC30P047	ARC30CD047	ARC30C047	ARC30R047	ARC30RA047	ARC30B047	ARC30BA047
600	2P+G	ARC30PD142	ARC30P142	ARC30CD142	ARC30C142	ARC30R142*	ARC30RA142	ARC30B142*	ARC30BA142
3Ø600	3P+G	ARC30PD143	ARC30P143	ARC30CD143	ARC30C143	ARC30R143*	ARC30RA143	ARC30B143*	ARC30BA143
3ØY347/600	3P+N+G	ARC30PD147	ARC30P147	ARC30CD147	ARC30C147	ARC30R147	ARC30RA147	ARC30B147	ARC30BA147

Accessories

Angled Adapter ARCANGLE30	Plug Cap ARPCPC30	Handle ARCH30	Handle w/Drawplate ARCHDP30
------------------------------	----------------------	------------------	--------------------------------

*Add "AC" to end of part number for auxiliary contact versions

60 Amp Ordering Chart

Voltage	Polarity	Plug w/Handle and Drawplate	Plug w/ Handle	Connector w/Handle and Drawplate	Connector w/Handle	Receptacle	Receptacle w/70° Angle	Inlet	Inlet w/70° Angle
125	1P+N+G	ARC60PD075	ARC60P075	ARC60CD075	ARC60C075	ARC60R075	ARC60RA075	ARC60B075	ARC60BA075
250	2P+G	ARC60PD072	ARC60P072	ARC60CD072	ARC60C072	ARC60R072	ARC60RA072	ARC60B072	ARC60BA072
3Ø250	3P+G	ARC60PD073	ARC60P073	ARC60CD073	ARC60C073	ARC60R073	ARC60RA073	ARC60B073	ARC60BA073
125/250	2P+N+G	ARC60PD076	ARC60P076	ARC60CD076	ARC60C076	ARC60R076	ARC60RA076	ARC60B076	ARC60BA076
208	2P+G	ARC60PD162	ARC60P162	ARC60CD162	ARC60C162	ARC60R162	ARC60RA162	ARC60B162	ARC60BA162
3Ø208	3P+G	ARC60PD163	ARC60P163	ARC60CD163	ARC60C163	ARC60R163	ARC60RA163	ARC60B163	ARC60BA163
3ØY120/208	3P+N+G	ARC60PD167	ARC60P167	ARC60CD167	ARC60C167	ARC60R167	ARC60RA167	ARC60B167	ARC60BA167
277	1P+N+G	ARC60PD045	ARC60P045	ARC60CD045	ARC60C045	ARC60R045	ARC60RA045	ARC60B045	ARC60BA045
480	2P+G	ARC60PD042	ARC60P042	ARC60CD042	ARC60C042	ARC60R042	ARC60RA042	ARC60B042	ARC60BA042
3Ø480	3P+G	ARC60PD043	ARC60P043	ARC60CD043	ARC60C043	ARC60R043	ARC60RA043	ARC60B043	ARC60BA043
3ØY277/480	3P+N+G	ARC60PD047	ARC60P047	ARC60CD047	ARC60C047	ARC60R047	ARC60RA047	ARC60B047	ARC60BA047
600	2P+G	ARC60PD142	ARC60P142	ARC60CD142	ARC60C142	ARC60R142	ARC60RA142	ARC60B142	ARC60BA142
3Ø600	3P+G	ARC60PD143	ARC60P143	ARC60CD143	ARC60C143	ARC60R143	ARC60RA143	ARC60B143	ARC60BA143
3ØY347/600	3P+N+G	ARC60PD147	ARC60P147	ARC60CD147	ARC60C147	ARC60R147	ARC60RA147	ARC60B147	ARC60BA147

Accessories

Angled Adapter ARCANGLE60	Plug Cap ARPCPC60	Handle ARCH60	Handle w/Drawplate ARCHDP60
------------------------------	----------------------	------------------	--------------------------------

For more information, visit
leviton.com/ArcArrest or scan:



Visit our Website at:
www.leviton.com/arcarrest
 email: industrial@leviton.com

Leviton Manufacturing Co., Inc.
 201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)
 © 2025 Leviton Manufacturing Co., Inc. All rights reserved.