


Decora Plus™ Universal Receptacles

Commercial Specification Grade

US 15 A, 125 V / Euro 16 A, 250 V

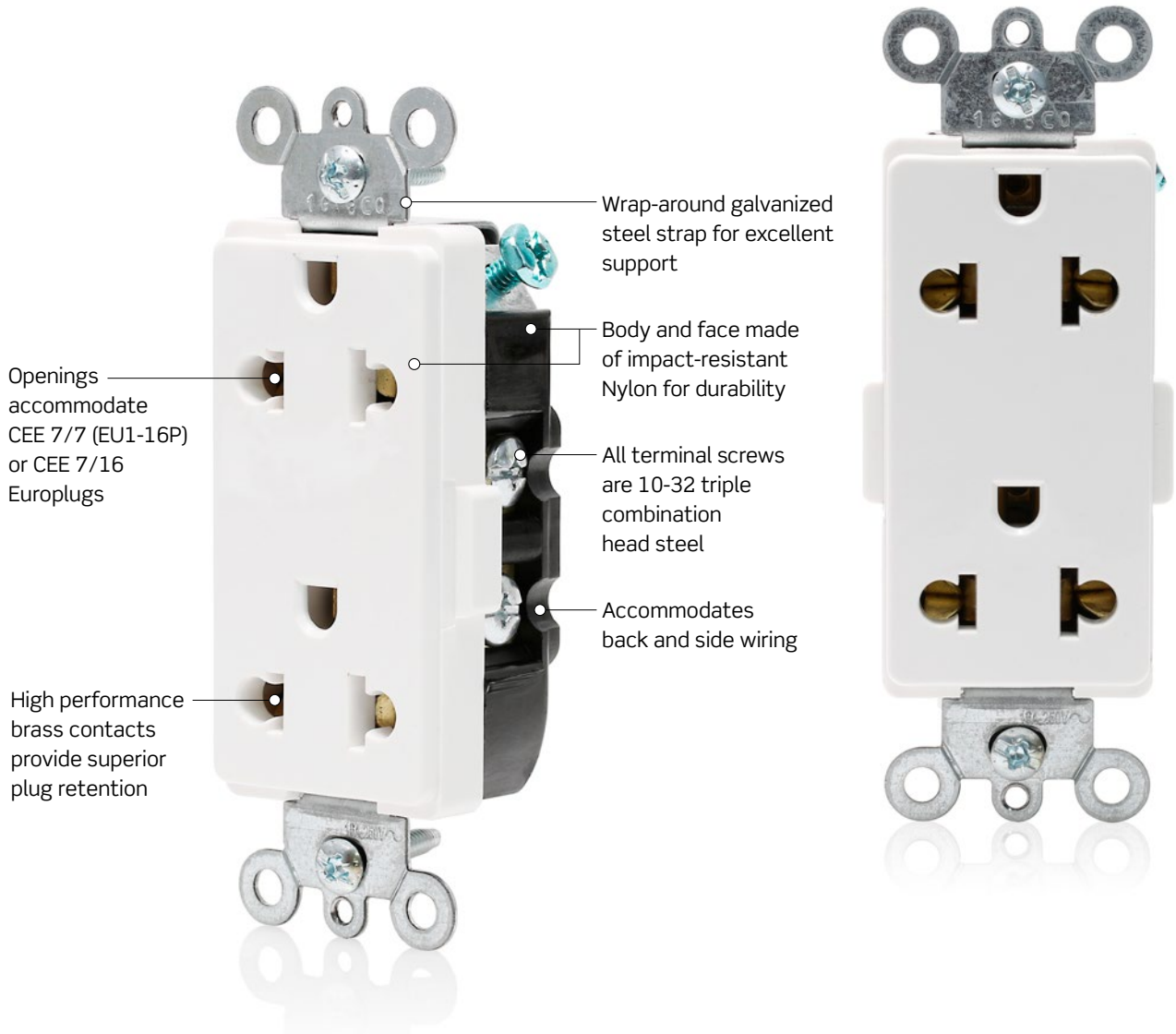

- Openings accommodate CEE 7/7 (EU1-16P) or CEE 7/16 Europlugs
- High performance brass contacts provide superior plug retention
- Wrap-around galvanized steel strap for excellent support
- Body and face made of impact-resistant Nylon for durability
- All terminal screws are 10-32 triple combination head steel
- Accommodates back and side wiring

Common Applications:

- Residential Dwellings
- Educational Facilities
- Office Environments
- Hospitals/Medical Buildings
- Hospitality
- Day Care Centers

Ordering Information

Color	Catalog Number
White	5835-W
Ivory	5835-I
Black	5835-E
Light Almond	5835-T

Specifications

Electrical Specifications		
	Euro-American Standard	
	NEMA 5-15R	EU1-16R
Horsepower Rating	½ hp	½ hp
Amperage	15 A	16 A
Voltage	125 V	250 V
Grounding	Grounding	Non-Grounding
Pole(s)	2	2
Wire(s)	3	2
Dielectric Voltage	1500	
Temperature Rise	Max 30°C	
Environmental Specifications		
Flammability Rating	V-2	
Operating Temperature	Maximum Continuous 60°C, Minimum -40°C (w/o impact)	
Material Specifications		
Face	Nylon	
Body	Nylon	
Mounting Strap	Galvanized Steel	
Line Contacts	Brass Triple Wipe 0.031"	
Grounding Screw	#8 Brass	
Ground Contacts	Brass	
Mounting Screws	#6 Plated Steel	
Terminal Clamps	Zinc-Plated Steel	
Terminal Screws	#10 Brass	

Mechanical Specifications	
Product ID	Ratings are marked on device
Wire Accomodation	#14-#10 AWG Stranded
Termination	Back and Side Wire
Strap Construction	Wraparound Strap
Product Features	
Feature(s)	Smooth Face
Device Type	Duplex Receptacle Outlet
Brand	Decora Plus
Grade	Commercial Specification Grade
NEMA Configuration	5-15R
Standards & Certifications	
Applicable Standards & Certifications	NOM, NAFTA Compliant
Warranty	
Warranty	10-Year Limited

Visit our Website at:
www.leviton.com/commercial
 email: commercial@leviton.com

Q-1155A

012919

Leviton Manufacturing Co., Inc.
 201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2019 Leviton Manufacturing Co., Inc. All rights reserved.

