


Duplex Receptacles

Heavy Duty Hospital Grade 15A & 20A, 125V

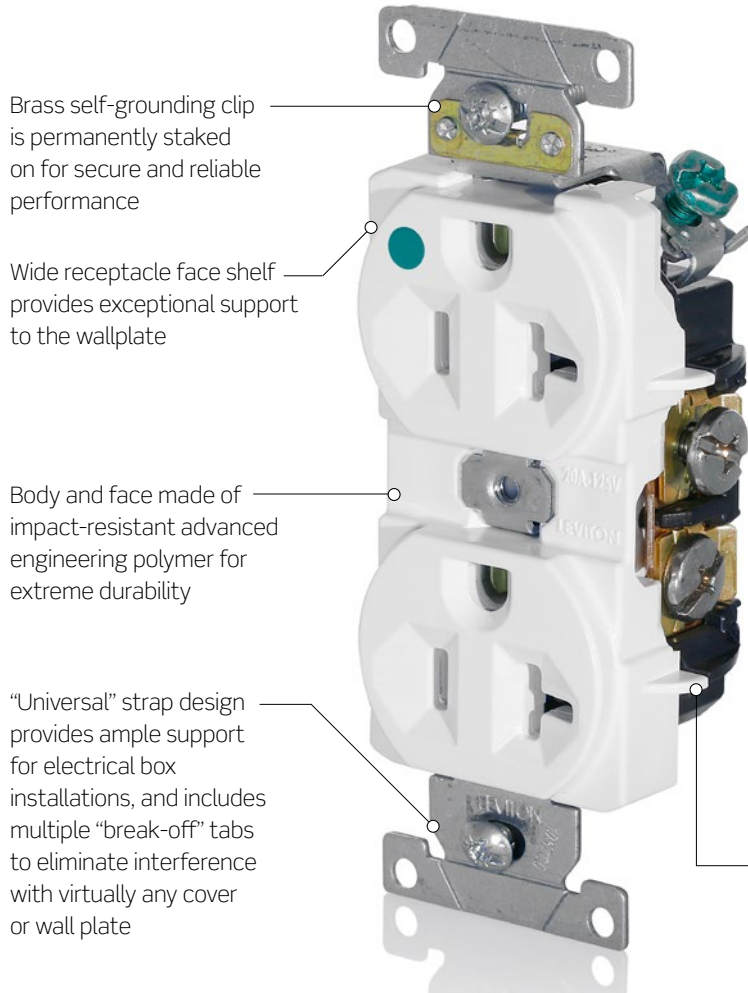


Brass self-grounding clip is permanently staked on for secure and reliable performance

Wide receptacle face shelf provides exceptional support to the wallplate

Body and face made of impact-resistant advanced engineering polymer for extreme durability

“Universal” strap design provides ample support for electrical box installations, and includes multiple “break-off” tabs to eliminate interference with virtually any cover or wall plate

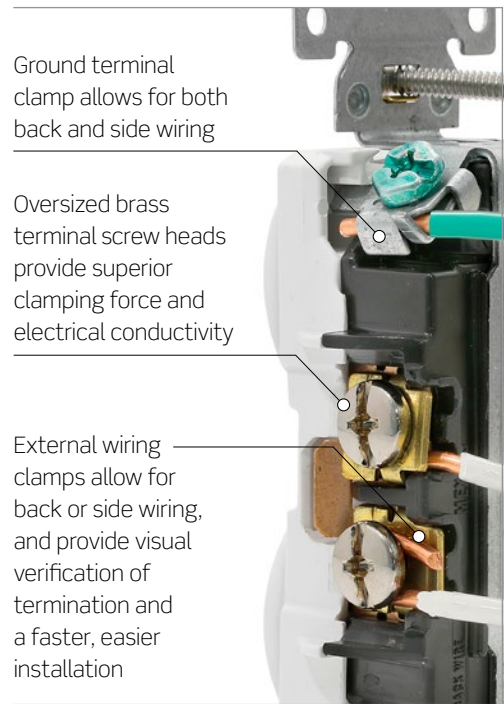

Ground terminal clamp allows for both back and side wiring

Oversized brass terminal screw heads provide superior clamping force and electrical conductivity

External wiring clamps allow for back or side wiring, and provide visual verification of termination and a faster, easier installation

Molded in ribs prevent terminal screws from making contact with wall box

Common Applications

- Healthcare Facilities
- Educational Facilities
- Institutional Buildings

Ordering Information

Rating		15 A / 125 V	20 A / 125 V
NEMA Config		5-15R	5-20R
Order ID	Brown	C8200	C8300
	Ivory	C8200-I	C8300-I
	White	C8200-W	C8300-W
	Gray	C8200-GY	C8300-GY
	Red	C8200-R	C8300-R
	Blue	C8200-BU	C8300-BU
	Black	C8200-E	C8300-E
	Light Almond	C8200-T	C8300-T


Specifications

Rating	C8200	C8300
AC Horsepower Rating		
At Rated Voltage	½ HP	1 HP
Electrical Specifications		
Amperage	15A	20A
NEMA	5-15R	5-20R
Voltage	125V	
Grounding	Self-Grounding*	
Pole	2	
Wire	3	
Dielectric Voltage	Withstands 3000V min	
Temperature Rise	Max 30°C after 250 cycles OL at 200% rated current	
Environmental Specifications		
Flammability	UL94 V0	
Operating Temperature	Maximum Continuous 75°C, minimum, -40°C (w/o impact)	
Material Specifications		
Face	PBT Polyester Blend	
Body	PBT Polyester Blend	
Strap	Steel (Galvanized G60)	
Ground Contact	0.030" Brass	
Mounting Screw	Triple-Drive Plated Steel	
Ground Screw	#8 hex head , Triple-Drive Brass	
Line Contacts	0.030" Phosphor Bronze	
Terminal Clamp	Brass	
Terminal Screws	#8 Triple-Drive Brass	
Ground Clip	Brass	
Mechanical Specifications		
Product ID.	Ratings are permanently marked on device	
Terminal ID	Brass - Hot, Green - Ground, Silver - Neutral	
Terminal Accommodation	#14- 10AWG	
Wire Types	Stranded or Solid	
Termination	Back and Side Wire	
Standards & Certifications		
NEMA	WD 1 & WD 6	
ANSI	C-73	
Certification/Listing	cULus, NOM-ANCE	
Applicable Standards	UL498, Fed Spec WC596, CSA C22.2 No.42	
RoHS	RoHS Compliant	
Warranty		
Product Warranty	10 Years	


*Self-Grounding when installed in a properly grounded metallic box

Dimensions

Front View

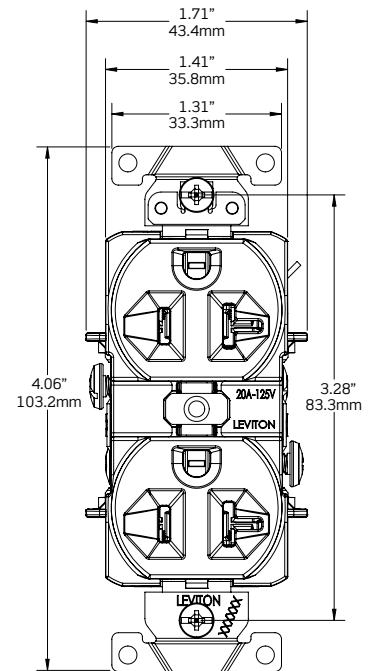

Side View

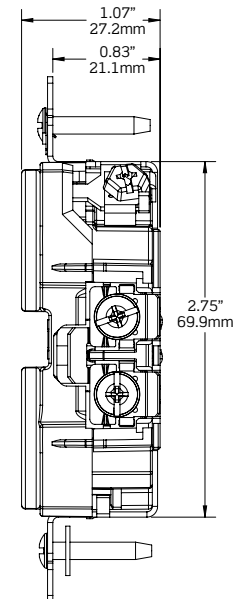

Visit our Website at:
www.leviton.com/commercial
 email: commercial@leviton.com

Q-1013

080717

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2017 Leviton Manufacturing Co., Inc. All rights reserved.

