

Duplex Receptacles

Heavy Duty Industrial Specification Grade


Tamper-Resistant

15A & 20A, 125V

- Brass self-grounding clip is permanently staked on for secure and reliable performance
- Wide receptacle face shelf provides exceptional support to the wallplate or box cover
- Patented tamper-resistant safety shutter mechanism prevents insertion of foreign objects
- Body and face made of impact-resistant advanced engineering polymer for extreme durability
- “Universal” strap design provides ample support for electrical box installations, and includes multiple “break-off” tabs to eliminate interference with virtually any cover or wall plate



Provides compliance with National Electrical Code Article 406 for tamper-resistant receptacles

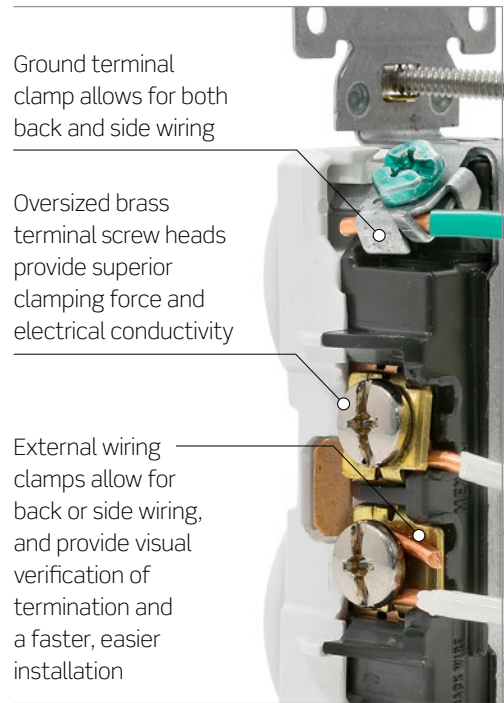

- Ground terminal clamp allows for both back and side wiring
- Oversized brass terminal screw heads provide superior clamping force and electrical conductivity
- External wiring clamps allow for back or side wiring, and provide visual verification of termination and a faster, easier installation
- Molded in ribs prevent terminal screws from making contact with wall box

Common Applications

- Commercial Buildings
- Transportation Facilities
- Municipal Buildings
- Education Facilities

Ordering Information

Ratings		15 A/ 125 V	20 A/ 125 V
NEMA Config		5-15R	5-20R
Order ID	Brown	T5262	T5362
	Ivory	T5262-I	T5362-I
	White	T5262-W	T5362-W
	Gray	T5262-GY	T5362-GY
	Red	T5262-R	T5362-R
	Blue	T5262-BU	T5362-BU
	Black	T5262-E	T5362-E
	Light Almond	T5262-T	T5362-T


Specifications

Rating	T5262	T5362
AC Horsepower Rating		
At Rated Voltage	½ HP	1 HP
Electrical Specification		
Amperage	15A	20A
NEMA	5-15R	5-20R
Voltage	125V	
Grounding	Self-Grounding*	
Pole	2	
Wire	3	
Dielectric Voltage	Withstands 3000V min	
Temperature Rise	Max 30°C after 250 Cycles Overload at 200% rated current	
Environmental Specifications		
Flammability	UL94 V0	
Operating Temperature	Maximum continuous 75°C, minimum -40°C (w/o impact)	
Material Specifications		
Face	PBT Polyester Blend	
Body	PBT Polyester Blend	
Strap	Steel (Galvanized G60)	
Ground Contact	0.030" Brass	
Mounting Screw	Triple-Drive Plated Steel	
Ground Screw	#8 Hex Head, Triple-Drive Brass	
Line Contacts	0.030" Phosphor Bronze	
Terminal Clamp	Brass	
Terminal Screws	#8 Triple-Drive Brass	
Ground Clip	Brass	
Shutter Mechanism	Acetal	
Mechanical Specifications		
Product ID.	Ratings are permanently marked on the device	
Terminal ID	Brass - Hot, Silver - Neutral, Green - Ground	
Terminal Accommodation	#14 - #10 AWG	
Wire Types	Solid or Stranded	
Termination	Back and Side Wire	
Standards & Certifications		
NEMA	WD 1 & WD 6	
ANSI	C-73	
Certification/Listing	cULus, NOM-ANCE	
Applicable Standards	UL 498, Fed Spec W-C 596, CSA C22.2 NO. 42	
RoHS	RoHS Compliant	
Warranty		
Product Warranty	10 Years	


*Self-grounding when installed in a properly grounded metallic box

Dimensions

Front View

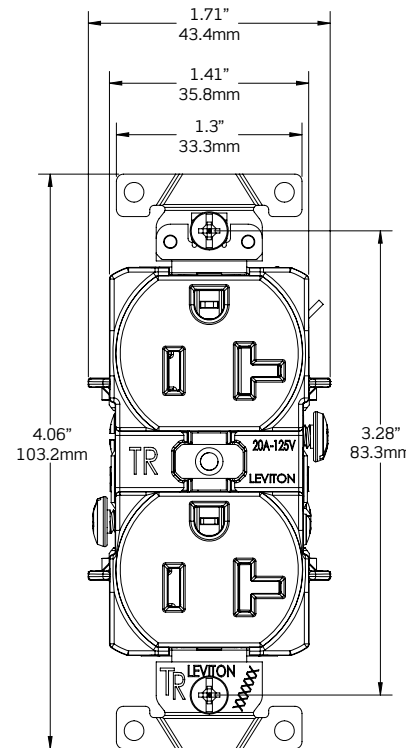

Side View

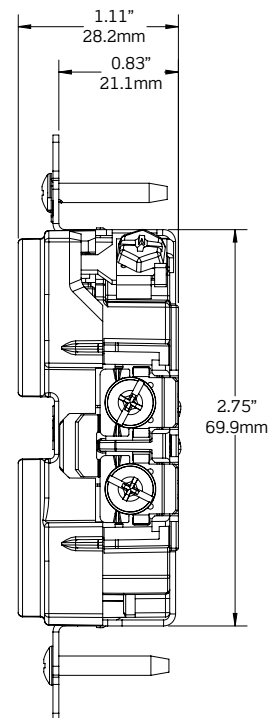

Visit our Website at:
www.leviton.com/commercial
 email: commercial@leviton.com

Q-1100

071917

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2017 Leviton Manufacturing Co., Inc. All rights reserved.

