


Tamper-Resistant Single Recessed Clock Hanger Receptacles

Ideal for flush-to-the-wall applications, such as behind flat screen televisions, clocks and video monitors in conference rooms and office areas

Quick installation: simply wire and mount to a standard single gang box

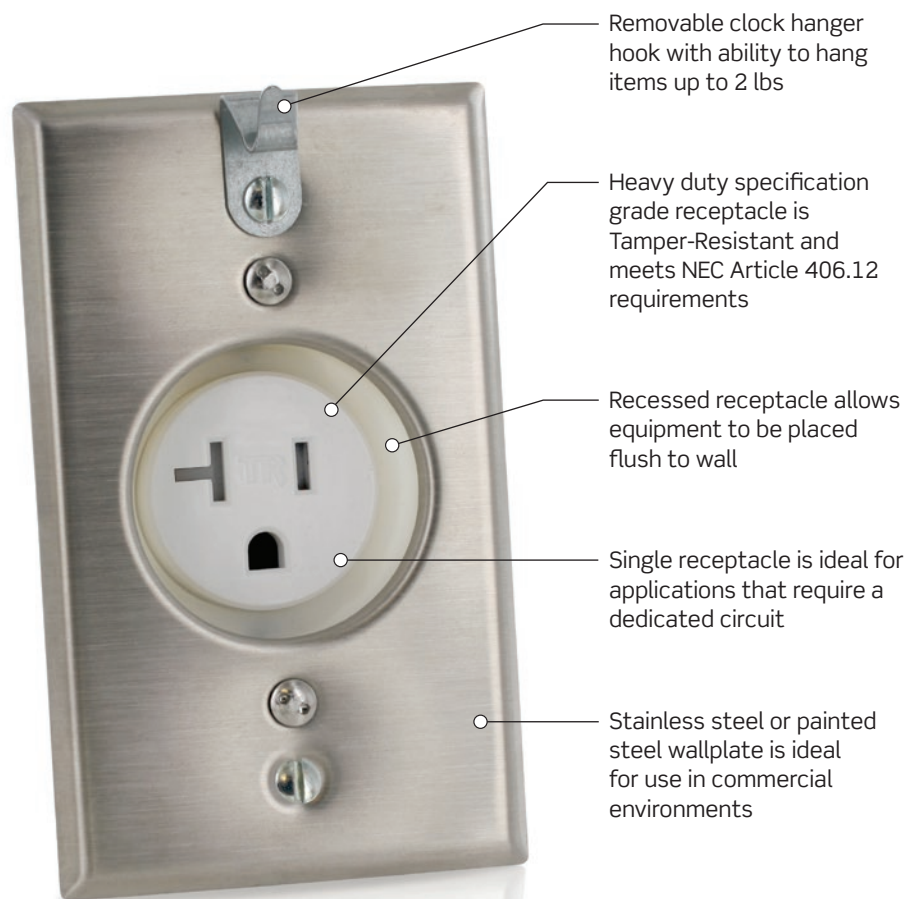

Ordering Information

Description	15A	20A
Stainless Steel	T5261-CH	T5361-CH
Ivory: Painted Steel	T5015-CHI	T5020-CHI
White: Painted Steel	T5015-CHW	T5020-CHW

Common Applications


- Educational Facilities
- Hospitality Venues
- Commercial Buildings
- Multiple Dwelling Units

Specifications


Description	T5261-CH	T5361-CH	T5015-CHx	T5020-CHx
AC Horsepower Rating				
At Rated Voltage	1/2 HP	1 HP	1/2 HP	1 HP
Electrical Specifications				
Amperage	15A	20A	15A	20A
Voltage	125V	125V	125V	125V
NEMA	5-15R	5-20R	5-15R	5-20R
Pole	2	2	2	2
Wire	3	3	3	3
Dielectric Voltage	Withstands 2000V per UL498		Withstands 2000V per UL498	
Temperature Rise	Max 30 °C after 100 cycles at 150 percent rated current		Max 30 °C after 100 cycles at 150 percent rated current	
Environmental Specifications				
Flammability	Rated V-2 per UL 94		Rated V-2 per UL 94	
Operating Temperature	-40 °C to +75 °C		-40 °C to +75 °C	
Material Specifications				
Receptacle Face	Nylon (Color: White)		Nylon (Colors: CHI-Ivory or CHW-White)	
Receptacle Body	Nylon			
Receptacle Line Contacts	Brass Triple-Wipe			
Receptacle Mounting Screws	Steel 10-32			
Receptacle Grounding Screw	Steel 8-32			
Receptacle Strap	Zinc-Plate Steel			
Wallplate	Stainless Steel			
Mechanical Specifications				
Terminal ID	Brass-Hot, Green-Ground, Silver Neutral			
Terminal Accom.	14-10 AWG			
Termination	Back and Side Wiring			
Standards & Certifications				
NEMA	WD-1 and WD-6			
ANSI	C-73			
Certification/Listing	cCSAus, NOM-ANCE			
Applicable Standards	UL 498, UL 514A, CSA C22.2, No. 42, CSA C22.2 No. 18.1-04			
Guarantees				
Product Warranty	10 Year Limited			

Dimensions




Front View

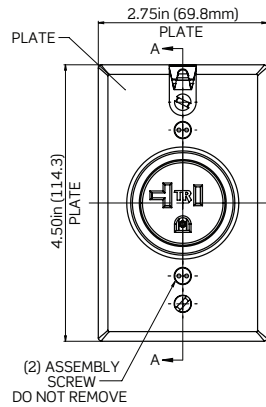

Back View

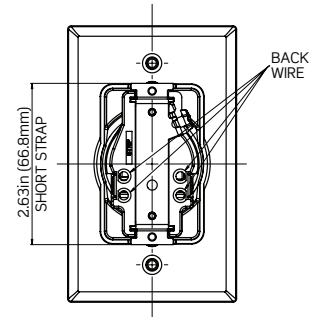

Top View

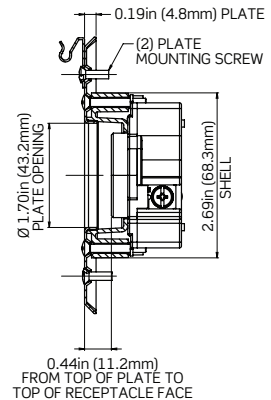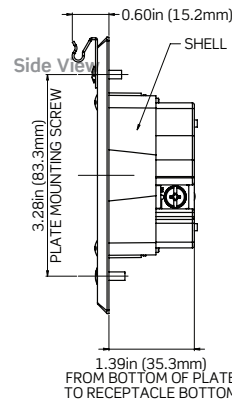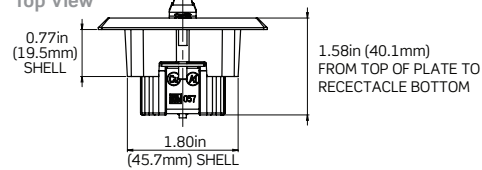

Visit our Website at:

www.leviton.com/industrial

email: industrial@leviton.com

Q-918

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2014 Leviton Manufacturing Co., Inc. All rights reserved.

121914

