

# The Latest Innovations for 2026

## Solutions for the Home

### 50A EV CHARGING OUTLET WITH OUTDOOR WEATHER-RESISTANT COVER, SURFACE MOUNT

The perfect option for homeowners who prefer a plug-in EV charging application to a hardwired application, and for future-focused new construction projects that want to present an EV-ready environment.

All-in-one, pre-assembled outlet and cover code compliant solution with pre-wired ground.

- Engineered to handle the extended charge times and frequent plug-ins that EVs demand while delivering consistent, reliable power.
- Crafted from galvanized steel with a welded flange and NEMA 3R rating for superior corrosion resistance that stands up to rain, snow, and other tough outdoor conditions.
- 50A, 125/250V NEMA 14-50R receptacle is specifically designed for plug-in EV chargers.



### CONVENIENT IN-WALL USB CHARGER RECEPTACLES


Declutter your space with charging power where you need it. Two charging ports deliver a combined total of 18 watts of power. Built-in smart chip recognizes the individual device's charging requirements to optimize the charge. Type A/A replacement is ideal for high-volume, price-sensitive projects.



## Lever Edge™

The future of wiring is as simple as push, click, done.

- No exposed parts for faster installation, color-coded levers to help prevent miswiring, easier alignment in multi-gang installations, and more!
- Solutions include outlets, switches, GFCIs, dimmers, plugs and connectors.

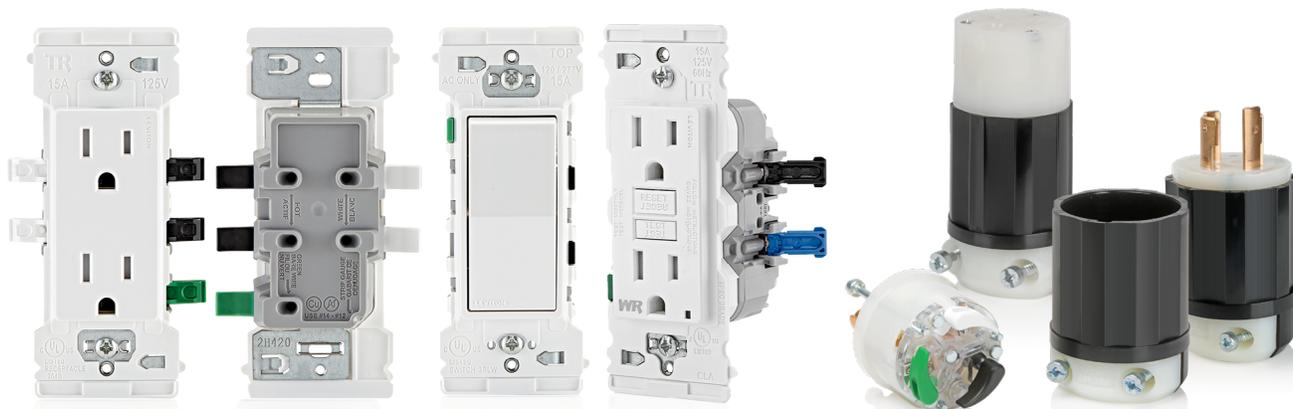


### SLIM GFCI OUTLETS

**\*Leviton's GFCIs have the slimmest in-box depth on the market!**

SmartlockPro® devices are also designed to improve immunity for reduced HF nuisance tripping.

- More room in the wall box for faster and easier installation
- Contractors save time and money on the job
- Provides continuous ground-fault protection and meets the latest UL requirements
- Status indicator light provides simple, intuitive feedback on protection status
- Patented Reset Lockout technology prevents reset if the GFCI is not wired or operating correctly

*\*Does not apply to Combination GFCI/USB and Smart GFCI*

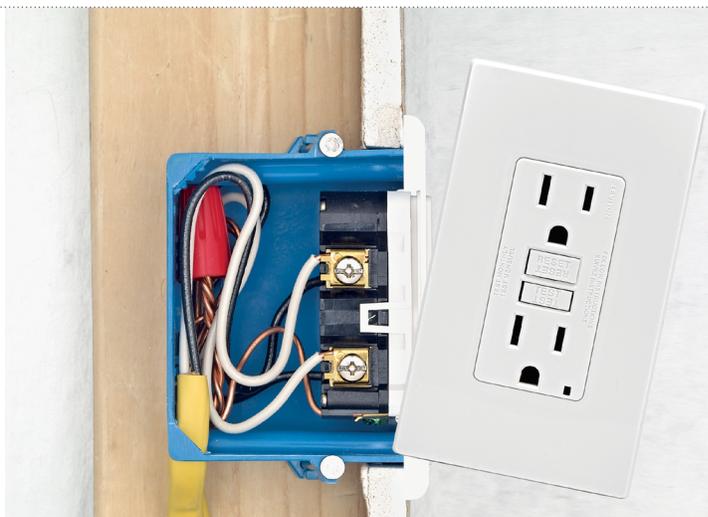

# The Latest Innovations for 2026

## Solutions for the Home

### SURFACE MOUNT DOWNLIGHTS

The SDR series is a sleek, low-profile design that offers high lumen output and adds a modern touch to any space. Its driver-on-board design allows for easy mounting over most industry standard junction boxes (including shallow pancake style ceiling boxes). Pair the SDR series with Leviton compatible dimmers for the desired light level needed for any space.

- Available in 5-, 7-, and 9-inch round apertures delivering up to 1500 lumens
- Field Selectable Color Temperature (CCT) 2700K-5000K
- Optional matte black trim ring accessories



Black Trim Ring sold separately

### Decora Smart® Wi-Fi® ELV/LED Phase Selectable Dimmer

Add smart control to 0-10V loads including Mark 7 Fluorescent Ballasts and LED fixtures/Electronic Ballasts; dual voltage 120V/277V; and no power pack required for On/Off switching with high inrush stability, 50mA sinking current



### 400A METER-COMBINATION LOAD CENTER

Developed for large-scale residential applications, fully electrified homes, and future-proofing installations, the new 400A and 300A Meter-Combination Load Centers meet the increasing demand for larger electrical service entrances. Each Meter-Combination Load Center comes with one (factory installed) main breaker and a secondary main breaker offering flexibility to tailor the total amperage to the needs of the installation.



# The Latest Innovations for 2026

## Commercial and Industrial Facility Solutions

### Lever Edge™

The future of wiring is as simple as push, click, done.

#### Lever Edge Commercial Receptacles

- A single wraparound galvanized steel strap on commercial grade receptacles
- Ribbed levers for easy, secure grip

#### Lever Edge Black & White® Industrial Plugs and Connectors

- Durable nylon housing with HB or better flammability ratings
- Wider ribs on housing strengthens grip while installing
- Clear back cover to easily view connection status



### ArcArrest® SWITCH-RATED PIN & SLEEVE DEVICES

ArcArrest® Switch-Rated Pin & Sleeve devices provide a local means of disconnect as required by NEC and are rated for both branch and motor circuit disconnects. By combining a wall-mounted disconnect with a plug and connector, they deliver greater flexibility and portability. Even under load, there's no exposure to live components or arc flash. Built with watertight ratings, they're engineered to perform reliably in harsh industrial environments.



### GREENCONNECT™ — WIRELESS DONE RIGHT!

GreenConnect™ makes wireless lighting control easy with a simple, scalable solution. With Push-to-Pair technology, GreenConnect™ does not require a room controller, hub, or app. Fully programmable by the contractor, setup is quick and effortless without any factory commissioning required. Add wireless control to virtually any switching or dimming device without new wiring, an ideal solution for retrofits and new construction.



### FLOOR BOXES

From wood frame construction to concrete pours, our floor boxes offer a full portfolio of products to satisfy the needs of commercial applications. Accommodating data, AV and power connectivity where it's needed most, we provide an all encompassing solution down to the devices inside the box. Our floor box systems are easy to install and built to last, making them a superior choice for commercial settings.



### THE COMPLETE SOLUTION FOR ELECTRIC VEHICLE CHARGING

Smart and reliable Electric Vehicle Charging for Residential, Commercial and Public Applications.



### VerifEye® SUBMETERING

From tenant billing to energy measurement & verification (M&V), VerifEye® submeters offer cost-effective scalability and integration to provide a complete utility submetering solution for every facility.



### MARINE GRADE PIN & SLEEVE

- Industry-exclusive — the only manufacturer of ABYC certified Pin & Sleeve devices in the market
- Marine grade — withstands harsh, corrosive marine environments
- Superior watertight ratings — including IP68 for long-term submersion
- Compatible with Leviton Marine Power Pedestals



## Commercial Lighting Control Solutions



### SMART SENSORS FOR INTUITIVE DIMMING OR SWITCHING CONTROL

Smart Sensors combine occupancy/vacancy sensing with 0-10V dimming or ON/OFF switching to provide a simple commercial grade solution for easy energy savings, local control and code compliance. Choose from simple standalone Smart Wallbox Sensors or for more advanced lighting control strategies, use Smart Ceiling Mount Sensors. For outdoor applications, use Smart Fixture Mount Sensors.

# Everyday Distributor Stocked Products

The core of any stocking order, these quality devices consist of the most commonly used items in every industry, day to day.

## RESIDENTIAL GRADE

### Dimmers

- IllumaTech®, SureSlide®,
- Toggle Slide, and
- Decora® Slide



### Switches: 15A, 20A

- Quiet, Toggle, Lighted,
- 3-Way, and Decora®

### Receptacles: 15A, 20A

- Tamper-Resistant,
- Weather-Resistant,
- Standard, and Decora®



### USB In-Wall Charger Receptacles

- **Good** — convenient power where you need it
- **Better** — step up to Power Delivery for 2x faster charging
- **Best** — provides 60W of power for high-need devices




### Combination Devices

- 2 Switches, 3 Switches,
- Switch/Receptacle,
- Switch/GFCI,
- GFCI/Guide Light


### AFCl, GFCI and Dual Function AF/GF: 15A, 20A

- Tamper-Resistant,
- Weather-Resistant,
- Audible Alarm

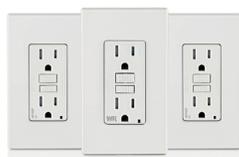

### Wallplates

- Standard, Decora®, Screwless, Combination, Midway and Oversized

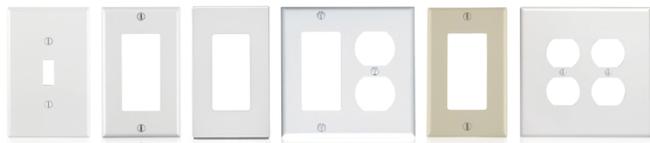

### Heavy Duty Weather-Resistant Covers

- For Outdoor Residential and Commercial Applications



## COMMERCIAL GRADE

### Wall Switch Sensors

- Occupancy/Vacancy, PIR Infrared, Multi-Technology



### Ceiling and Fixture Mount Sensors

- Occupancy/Vacancy, PIR Infrared, Multi-Technology



## COMMERCIAL/INDUSTRIAL GRADE

### Switches: 15A, 20A

- Extra Heavy-Duty, 3-Way, Lighted, Locking, and Decora Plus™



### Motor Starting Switches: 30A, 40A, 60A

- Component and Enclosed

### Receptacles: 15A, 20A

- Tamper-Resistant, Extra Heavy-Duty, Isolated Ground, Hospital Grade, and Decora Plus™



### Black & White Plugs and Connectors: 15A, 20A, 30A, 50A

- Straight Blade, Locking, Angled, Hospital Grade

### WetGuard® Watertight Devices: 15A, 20A, 30A, 50A

- Straight Blade, Locking, Plugs, Connectors, Inlets, Outlets, Boxes and Covers



### Medical Grade Power Strips

- With Load Monitoring Inform™ Technology



### Lev-Lok® Modular Wiring Devices

- Switches, Receptacles, Sensors, Wiring Modules



# Leviton 2024 Sustainability

## A Message from our President & CEO

“Our CN2030 program, with its ambitious goal of achieving company-wide Carbon Neutrality by 2030, is a testament to our unwavering commitment. With the full support of our Board of Directors, we are making strategic investments in our manufacturing facilities and warehouses worldwide, upgrading equipment for greater energy efficiency and transitioning to emissions free energy sources.”



**Daryoush Larizadeh**  
President and CEO

## Empowering a Path

We believe in a carbon-free future and our goal is carbon neutrality across our business operations by 2030. Our ambition is to be net zero by 2050.

(1) Carbon Neutral: reduce and balance Scope 1, 2, plus selected relevant scope 3 emissions; driving Regions, Business Units and Leviton to Carbon Neutral, 3rd party verified using PAS-2060 and ISO-14064 / GHG Protocols

(2) All business units mean all owned and leased assets inclusive of Factories, Offices, Warehouses, Sales Offices etc

(3) Net Zero: reduce >90% of all Scope 1,2, relevant scope 3 and balance 100% of emissions via SBTi (or equivalent) and aligning with the Paris Climate Agreement goals to limit global warming to 2°C, targeting 1.5°C by 2050

## LEVITON'S CN2030 SUSTAINABILITY PLAN

