


DDS Series Satellite Dimmer Packs



DESCRIPTION

DDS satellite dimmers are fully UL listed digital products providing reliable, responsive performance with smooth, accurate dimming curves. Extensive epoxy encased toroidal filtering reduces the potential of dimmer generated noise. Individual channels are user assignable as dimmers or on/off relays for non-dim applications. All DDS Dimmers have built-in chase effects for stand-alone operation, perfect for all display type applications.

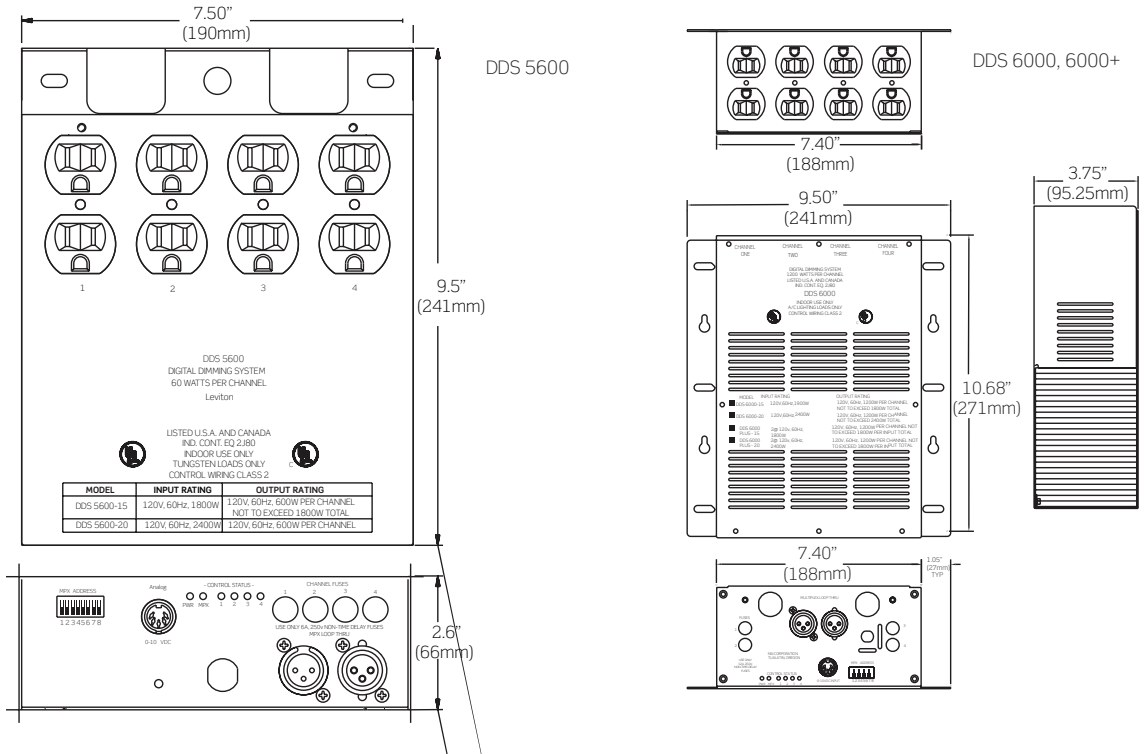

DIMENSIONAL DATA - IN. [CM] LBS. [KG]			
	5600	6000	6000+
Width	7.5 [9.1]	9.5 [24.1]	9.5 [24.1]
Depth	2.6 [6.6]	3.75 [9.5]	3.75 [9.5]
Height	9.5 [24.1]	10.9 [27.7]	10.9 [27.7]
Shipping Weight	10 [4.54]	14 [6.3]	15 [6.8]
Mounting Holes (OC)	8.25 [21]	8.25 [21]	

FEATURES

- 4 individual dimmer or relay channels
- Microprocessor digital phase control dimming or zero-crossing relay modes are user selectable (3600R is relay only)
- 512 channel address capable
- User select for soft start operation to increase lamp life
- User select for 8 auto sequence control programs
- Sequence rate adjustable from 1 to 60 seconds
- Toroidal noise
- Dual SCR circuit design ensures reliable operation
- Control status indicator LED
- Power on LED indicator
- Individual channel function LEDs
- External fusing for each individual channel
- NSI 128 channel Micro-Plex (3-pin XLR male and female)
- 0 to 10 volt analog input (5-pin DIN)
- Optional DMX512 digital control (5-pin XLR male and female)

PRODUCT DATA



DDS 5600

- 4 channels @ 600 watts
- 15 amp/1800 watt model with NEMA 5-15 household power cord connector or 20 amp/2400 watt model with NEMA 5-20 perpendicular blade power cord connector available
- 2400 watts maximum output
- 160 micro-second toroidal

- 2400 watts maximum output
- 400 micro-second toroidal
- UL listed knockout version available for hardwired permanent installation
- External circuit breaker for power cord protection

DDS 6000

- 4 channels @ 1200 watts
- 15 amp/1800 watt model with NEMA 5-15 household power cord connector or 20 amp/2400 watt model with NEMA 5-20 perpendicular blade power cord connector available

DDS 6000+ (DUAL POWER CORDS)

- 4 channels @ 1200 watts
- 15 amp/3600 watt model with NEMA 5-15 household power cord connector or 20 amp/4800 watt model with NEMA 5-20 perpendicular blade power cord connector available
- 4800 watts maximum output
- 400 micro-second toroidal filtering
- UL listed knockout version available for hardwired permanent installation

DDS Series Satellite Dimmer Packs

CAT. NO.	DESCRIPTION:
N5600-000	DDS 5600 4 Channel, 600 Watt / Channel Dimmer/Relay System, Micro-Plex And 0-10V Analog standard, 15 Amp Power Supply Cord, 120V, UL/C-UL Listed
N5600-D00	DDS 5600, 120V W/DMX - 4 Channel, 600 Watt / Channel Dimmer/Relay System, DMX installed, 15 Amp Power Supply Cord, 120V, UL/C-UL Listed
N5600-020	DDS 5600, 120V - 4 Channel, 600 Watt / Channel, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 20 Amp Power Supply Cord, 120V, UL/C-UL Listed
N5600-D20	DDS 5600, 120V W/DMX - 4 Channel, 600 Watt /Channel, Dimmer/Relay System, DMX installed, 20Amp Power Supply Cord, 120V, UL/C-UL Listed
N5600-009	DDS 5600 4 Channel, 600 Watt / Channel, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 15 Amp Power Supply Cord, 240V
N5600-D09	DDS 5600, 230V W/DMX - 4 Channel, 600 Watt /Channel, Dimmer/Relay System, DMX installed, 15 Amp Power Supply Cord, 240V
N6000-000	DDS 6000 4 Channel, 1200 Watt /Channel 1800 Watt Max, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 15 Amp Power Supply Cord, 120V, UL/C-UL Listed
N6000-D00	DDS 6000 W/DMX - 4 Channel, 1200 Watt /Channel 1800 Watt Max, Dimmer/Relay System, DMX installed, 15 Amp Power Supply Cord, 120V, UL/C-UL Listed
N6000-020	DDS 6000, 120V - 4 Channel, 1200 Watt /Channel 2400 Watt Max, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 20 Amp Power Supply Cord, 120V, UL/C-UL Listed
N6000-D20	DDS 6000 W/DMX - 4 Channel, 1200 Watt /Channel 2400 Watt Max, Dimmer/Relay System, DMX installed, 20 Amp Power Supply Cord, 120V, UL/C-UL Listed
N6000-009	DDS 6000 4 Channel, 1200 Watt /Channel 2400 Watt Max, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 15 Amp Power Supply Cord, 120V
N600P-D09	DDS 6000 W/DMX, 240V - 4 Channel, 1200 Watt / Channel 2400 Watt Max, Dimmer/Relay System, DMX installed, 15 Amp Power Supply Cord, 240V
N600P-000	DDS 6000 4 Channel, 1200 Watt / Channel 3600 Watt Max with Dual 15A Power Supply Cords, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 120V, UL/C-UL Listed
N600P-D00	DDS 6000+, 120V W/DMX - 4 Channel, 1200 Watt / Channel 3600 Watt Max with Dual 15A Power Supply Cords, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 120V, UL/C-UL Listed
N600P-020	DDS 6000+, 120V - 4 Channel, 1200 Watt / Channel 4800 Watt Max with Dual 20A Power Supply Cords, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 120V, UL/C-UL Listed
N600P-02K	DDS 6000+ KO - 4 Channel, 1200 Watt / Channel 4800 Watt Max, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, Knockout, 120V, UL/C-UL Listed
N600P-D20	DDS 6000+ W/DMX - 4 Channel, 1200 Watt / Channel 4800 Watt Max with Dual 20A power supply cords, Dimmer/Relay System, DMX installed, 120V, UL/C-UL Listed
N600P-D2K	DDS 6000+ KO w/DMX - 4 Channel, 1200 Watt / Channel 4800 Watt Max, Dimmer/Relay System, DMX installed, Knockout, 120V, UL/C-UL Listed
N600P-009	DDS 6000 4 Channel, 1200 Watt / Channel 3600 Watt Max with Dual 15A Power Supply Cords, Dimmer/Relay System, Micro-Plex and 0-10V Analog standard, 240V
N600P-0K9	DDS 6000+ KO, 240V - 4 Channel, 1200 Watt / Channel 4800 Watt Max . Dimmer/Relay System, Micro-Plex And 0-10V Analog Is Standard, Knockout, 240V
N600P-D09	DDS 6000+, 4 x 1200W, 2400W Max, 240V w/ DMX
N600P-DK9	DDS 6000+, 4 x 1200W, 2400W Max, 240V w/ DMX & Knockouts

Leviton Manufacturing Co., Inc. Lighting & Controls

10385 SW Avery St., Tualatin, OR 97062 tel 800-736-6682 fax 503-404-5594 tech line (6:00AM-4:00PM PT Mon-Fri) 800-959-6004

Leviton Manufacturing Co., Inc. Global Headquarters

201 North Service Road, Melville, NY 11747-3138 tel 800-323-8920 fax 800-832-9538 tech line (8:30AM-7:00PM ET Mon-Fri) 800-824-3005

Visit our Website at: www.leviton.com/architecturalcontrols

©2023 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

G-7946C/K23-am
REV NOV 2023