

Pro Color Cannon LED Fixture



DESCRIPTION

The Pro Color Cannon is a customizable lighting fixture that supports broad field angles with a variety of application-specific configurations which can be programmed as required. The fixture excels at both wash and accent lighting configurations.

- (36) 3W LEDs
- Four LED Packages
 - RGB - Red, Green, Blue
 - WWA - White, White, Amber
 - TRGB - Tri-Color Red, Green, Blue
 - TWWA - Tri-Color White, White, Amber
- Vary the concentration of light with the field angle* that meets your specifications:
 - 15° (RBG & WWA only)
 - 30°
 - 60°
- Control options
 - DMX512
 - Audio-Trigger built-in microphone
 - Internal program execution
- DMX Operating Modes
 - Mode A - 3 Channels; RGB
 - Mode P - 4 Channels; Dimmer/Strobe, RGB
 - Mode F - 6 Channels; RGB, Strobe, Macro, Dimmer

INTERNAL PROGRAMS

- Macros
 - Color Fade
 - Color Snap
 - Random
 - Yellow
 - Purple
 - Aqua
 - Orange
 - Pulse; Yellow, Purple, Aqua, Orange, Red, Green, Blue, White
 - White LED Full
- Flash - Strobes the LEDs on the whole unit in White color
- Fade Scroll - Fades the LEDs on the whole unit from one color to another
- Flash Scroll - Changes the LEDs on the whole unit from one color to another
- Chase Effect - Select different chase patterns on the whole unit
- Chase Speed - Selects the speed of the selected chase
- Sound Chase - Selects the chase pattern that is triggered via audio
- Sound Flash - Selects the flash pattern that is triggered via audio
- Sound Sensor - Selects the sensitivity of the audio sensor

* Field angles can vary +/- 5

PRODUCT DATA



APPLICATIONS

- Theater lighting
- Houses of worship
- Lecture halls
- Event venues

- Security eye bolt for locking or non-locking safety cables
- cETL US Listed
- US assembled

FEATURES

- Digital display
- Double mounting yoke for free-standing applications

ACCESSORIES


- Barn door
- Gel holder
- C-clamp
- Safety cable

SPECIFICATIONS

PHYSICAL	
Size	9.5" x 8.75" x 11.25" (24.13cm x 22.22cm x 28.58cm)
Weight	6 lbs (2.72 kg)
ELECTRICAL	
DMX Connectors	3-Pin & 5-Pin XLR
Voltage	110V-230V, 50/60Hz
Max Wattage	76 Watts/0.67 Amps
LED Lifetime	60,000-100,000 hours
ENVIRONMENTAL	
Ambient Temperature	0-40° C/104° F
Maximum Surface Temperature	60° C/140° F

NOTE: Included accessories: NEMA 5-15P, Parallel Blade & Ground Plug, 15A

PRO COLOR CANNON ORDERING KEY

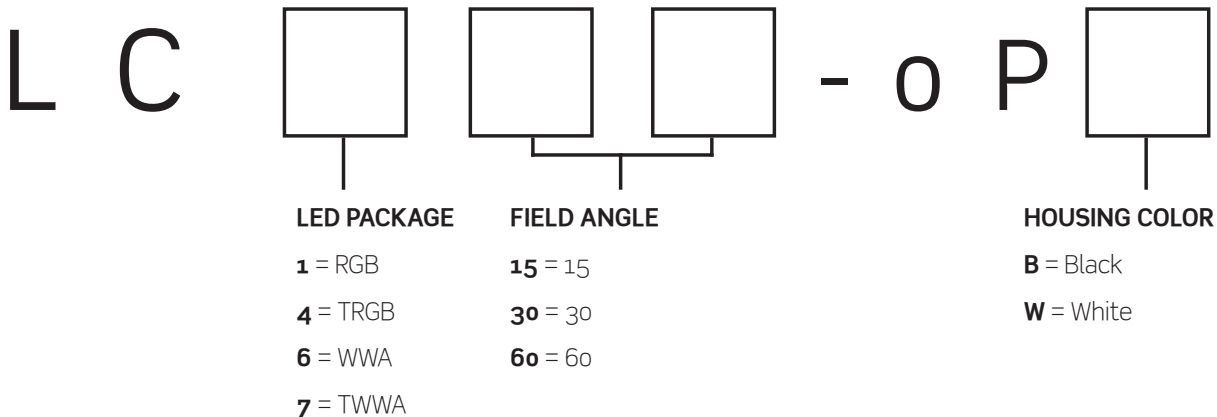

ORDERING INFORMATION

CAT. NO.	DESCRIPTION
LC4BD-00B	Pro Color Cannon Four Way Barn Door, Black
LC4BD-00W	Pro Color Cannon Four Way Barn Door, White
LCoGF-00B	Pro Color Cannon Gel Frame Holder, Black
LCoGF-00W	Pro Color Cannon Gel Frame Holder, White
TAoCC-000	C-Clamp
TAoSC-000	Safety Cable

LEVITON SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:
JOB NUMBER:	

Leviton Mfg. Co., Inc. Lighting & Energy Solutions

20497 SW Teton Avenue, Tualatin, OR 97062 1-800-736-6682 Tech Line: 1-800-959-6004 Fax: 503-404-5594 www.leviton.com/les
 © 2012 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

G-8651/A12-tb