

# Sector® Digital Switch

Decora® wall switches for basic, manual local control of lights as part of Leviton's Sector Intelligent Lighting Control System



SDS00-12W



SDS00-15W



SDSP4-05W  
+ SDS00-15W



SDSP4-G1W  
+ SDS00-15W



SDSP1-R5W  
+ SDS00-15W



SDSP1-M2W  
+ SDS00-15W



SDSP1-02W  
+ SDS00-12W



SDSP4-G2W  
+ SDS00-15W

## DESCRIPTION

The Sector® Digital Switch (SDS00) is a Decora device for manually controlling dimmable and non-dimmable lighting within a Sector lighting system zone or group. A scene control switch can be created by applying one of the scene control kits to a standard station. The Sector digital switch also serves as an IR receiver for the Sector handheld remote (SHH00-000) and can be used for basic adjusting of light level settings.


- The 5-button model has three lighting level selections for dimmable lighting (Max, Bright and Dim), as well as ON (Daylight harvesting ON) and OFF buttons.
- The 2-button model has two selections, ON and OFF which turns the lights on and off within a zone or group. Or either enters daylighting mode or simply turns on the lights depending on your system configuration. OFF always turns off the lights.

## FEATURES

- **No Interference:** 42KHz operation causes no interference with IR controls and occupancy sensors
- **All Digital Circuitry:** switch uses a minimum of components for maximum reliability at a low cost
- **Manual System Override:** switch allows you to manually override lighting settings in your immediate area
- **Easy Installation:** mounts easily into a single-gang wallbox
- **Topology-Free:** ballasts, occupancy sensors, and control stations connect on a single two conductor bus
- **Scene Control:** artwork kits available to field customize button stations, function configurable from software

# PRODUCT DATA

## WIRING DIAGRAM

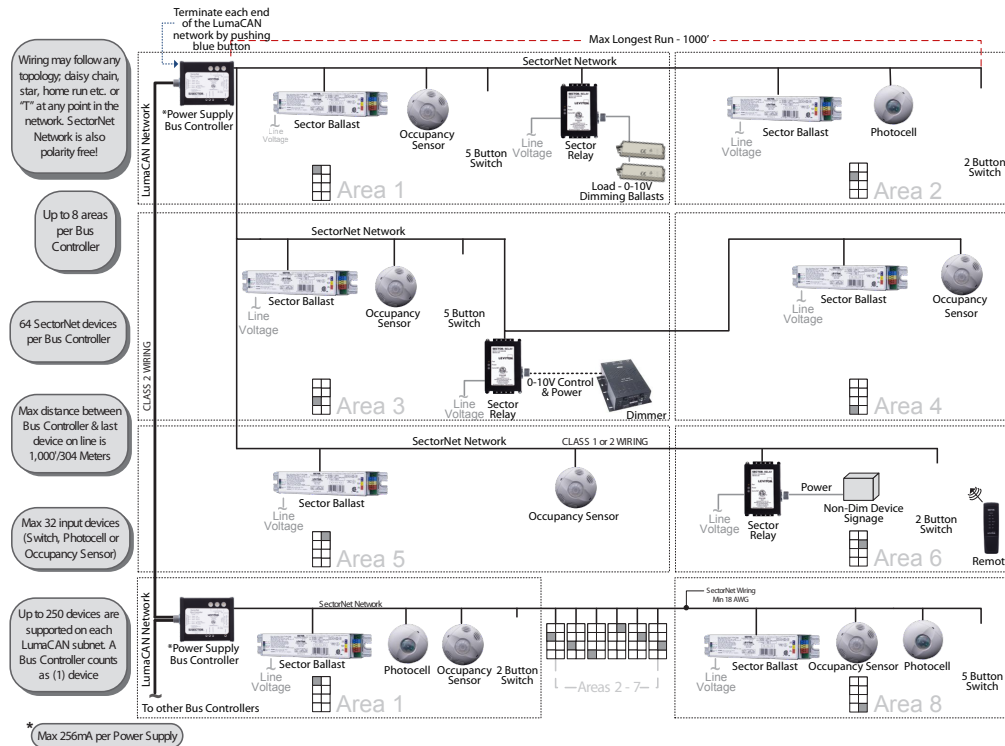

## SPECIFICATIONS

### Electrical

- Power source: Sector SBP00-00M Bus Controller/Power Supply
- Input Voltage: 34-42VDC, 277VAC tolerant
- Wire Designation (2): Brown; 18 AWG Min
- Class 1 or Class 2
- IEC61000-4-2

### Warranty

- Limited 5-year warranty

### Environmental

- Operating temperature: 0°C - 40°C (32°F - 104°F)
- Relative humidity: up to 90%, non-condensing
- Usage: indoors only

### Physical

- Size: 4.31" H x 1.625" W x 1.75" D (10.95 x 4.13 x 4.45cm)
- Mounting: In 2.25" deep wallbox
- Leads (2): Brown, 18 gauge

## ORDERING INFORMATION

CAT. NO.	DESCRIPTION
SDS00-15W	5-Button Digital Switch, White
SDS00-12W	2-Button Digital Switch, White
SDSP1-R5W	Artwork Kit, Scene 1, Raise, Lower, Max, OFF
SDSP1-M2W	Artwork Kit, Scene 1, Max, OFF
SDSP1-02W	Artwork Kit, Scene 1, OFF
SDSP4-05W	Artwork Kit, Scene 1, Scene 2, Scene 3, Scene 4, OFF
SDSP4-G1W	Artwork Kit, Zone 1 Toggle, Zone 2 Toggle, All OFF
SDSP4-G2W	Artwork Kit, High, Low, OFF

## Leviton Manufacturing Co., Inc. Lighting & Energy Solutions

20497 SW Teton Avenue, Tualatin, OR 97062 Telephone: 1-800-736-6682 • FAX: 503-404-5594  
Tech Line (6:00AM-4:00PM P.S.T. Monday-Friday): 1-800-959-6004

Visit our Website at: [www.leviton.com/les](http://www.leviton.com/les)

© 2014 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

G-8115D/K14-aa  
REV NOV 2014