



Permanent Install Power Supply

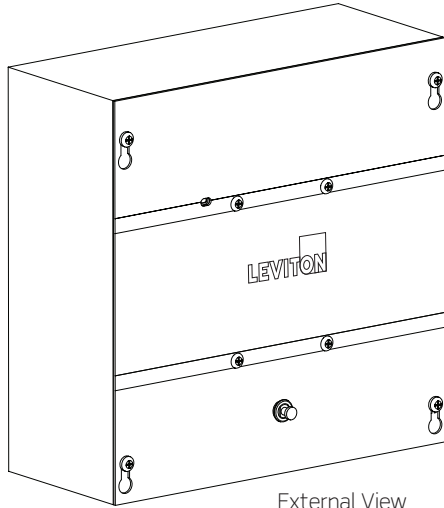

External View

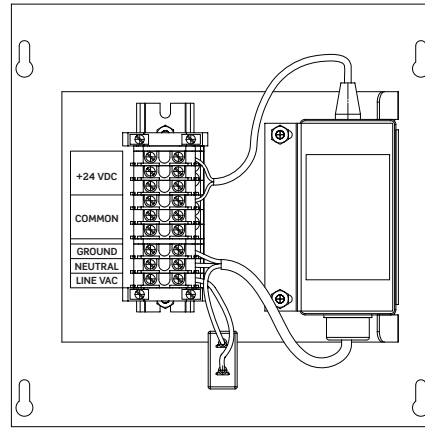

Internal View

DESCRIPTION


This power supply is designed for permanent installation and is used when additional power to peripheral devices is required.

APPLICATIONS

- D8000 auxiliary power supply
- D4000 auxiliary power supply
- Occupancy sensor auxiliary power supply

SPECIFICATIONS

- Output Voltage: +24V DC
- Maximum Output: 2.5A, 60W
- Input Voltage: +90-264V AC, 47-63Hz
- Input Current: <1.6Arms @ +90V AC
- Overcurrent Protection: voltage limiting, hiccup mode, auto recovery
- Short Circuit Protection: hiccup mode, auto recovery
- MTBF: 200,000 hours @ 40C
- Dimensions: 10" H x 10" W x 4" D (25.4cm x 24.4 cm x 10.16cm)
- Operating Temperature: 32 to 104°F (0 to 40°C)
- IP Rating: 45

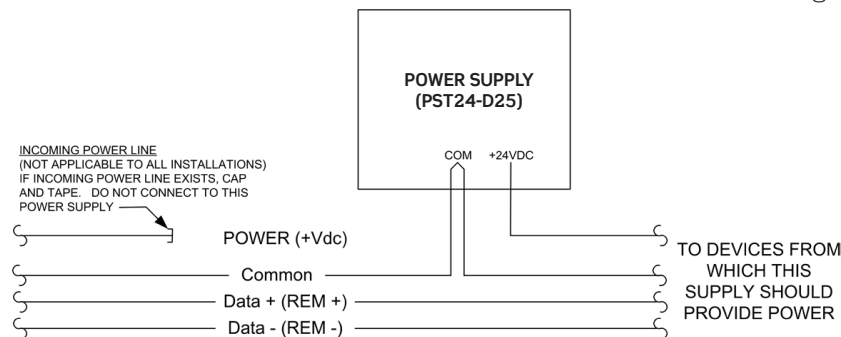

ORDERING INFORMATION

CAT. NO.	DESCRIPTION:
PST24-D25	Power Supply, Permanent Install w/Terminals, 24V, 2.5A

Leviton Manufacturing Co., Inc. Energy Management, Controls and Automation

20497 SW Teton Avenue, Tualatin, OR 97062 tel 800-736-6682 fax 503-404-5594 tech line (6:00AM-4:00PM PT Mon-Fri) 800-959-6004

Leviton Manufacturing Co., Inc. Global Headquarters

201 North Service Road, Melville, NY 11747-3138 tel 800-323-8920 fax 800-832-9538 tech line (8:30AM-7:00PM ET Mon-Fri) 800-824-3005

Visit our Website at: www.leviton.com/entertainmentlighting

©2018 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

G-8189A/G18-aa
REV JUL 2018