

Piccolo



12/48

The Leviton Piccolo line of lighting controllers offer features and functionality not commonly found in a console of this size. While it functions easily as a standard manual/memory board with traditional channel capacities and simple user interface components, Piccolo also offers features and capabilities previously unavailable in products in this category.

APPLICATIONS


- Schools, Theaters
- Churches, Studios
- Black Box Theaters
- Full Cue List Support
- Optional Monitor Output
- Channel, Submaster, or “Go” button playback

MODELS

DESCRIPTION	12/48	24/96	36/144	48/192
Channels	48	96	144	192
Sub masters	12	24	36	48
Handles	24	48	72	96
Sub master Pages	10			
Attributes	32			
DMX Channels	512			
Cues	10,000 (0.0-999.9)			
Effects	99			
Max Shows	Unlimited			
DMX Outputs	1			
DMX Inputs	1			
Dimensions - mm / Kg	490 x 400 x 50...100 mm / 3.5 Kg	720 x 400 x 50...100 mm / 5 Kg	950 x 400 x 50...100 mm / 6.25 Kg	1180 x 400 x 50...100 mm / 7.5 Kg
Dimensions - in / lbs.	19.3 x 15.7 x 2.0...3.9" / 7.7 lbs.	28.3 x 15.7 x 2.0...3.9" / 11 lbs.	37.4 x 15.7 x 2.0...3.9" / 13.8 lbs.	46.5 x 15.7 x 2.0...3.9" / 16.5 lbs.



12/48

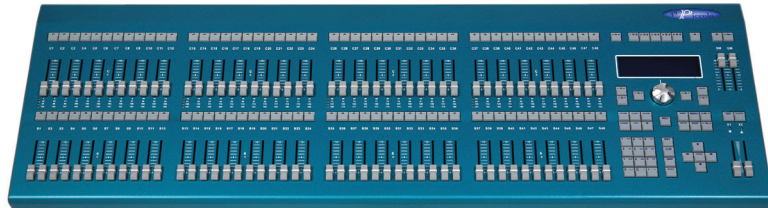

48/192

FEATURES

- **Operating Modes**
 - Two Scene – traditional two-scene mode, autofader becomes cross fader
 - Single Scene – all faders are channel faders, autofader becomes cue list
 - Submaster “Theater” Mode – ½ faders are channel faders, the other ½ are dedicated Submasters, autofader becomes cue list
- **32 Attribute channels for automated devices**
- **Full access to all channels via faders**
 - Match & Take Control with audible or visual indication of match
- **Proportional softpatch to all 512 DMX channels**
- **User Interface**
 - Channel Faders
 - Keypad
 - Display (240x64)
 - Attribute Encoder/Data Entry Wheel
 - Auto-fader with go, pause, back, and rate controls
 - Multi-Purpose Fader
 - Effect Master
 - DMX Input Master
 - Grand Master & Blackout Key
 - Channel Flash and Master Flash. Master Flash can be configured in different modes: GO, FLASH and SOLO
 - Arrow Keys
 - Soft Keys

- **Cues**
 - 10,000 cues numbered 0.0-999.9
 - Attributes
 - Fade Up
 - Fade Down
 - Delay Up
 - Delay Down
 - Wait
 - Follow
 - Jump
 - Loop
- **Effects (99)**
 - No practical limit on number of steps
 - Cues, Groups, Channels
 - Level
 - Speed
 - Ramp
 - Direction
 - Mode
 - Base Cue
- **Submasters**
 - 10 Pages of Submasters
 - Assigned to submaster/Group, cue, effect
- **LED Indicators**
 - (1) per channel to show channel level

- Console “Mode” Indication
- Accessible Channel ranges
- **I/O Ports**
 - DMX Output
 - DMX Input
 - Ethernet – 10/100-Base-T
 - USB Host (connect to PC)
 - USB Device (connect to USB Memory Stick or external hard drive)
 - Worklight
 - Midi In/Out
 - LT-Link
 - VGA Output (optional)
- **Software Features**
 - Hardware Test
 - Exam
 - Modify
 - Spreadsheet style list navigation
 - Cues
 - Groups
 - Effects
 - Text Labeling of any consoles item
 - (5) dimmers curves
 - Personalities
 - Multi-language
 - For use with or without external VGA
 - Print show data to text file
- **Off Line Editor**



Piccolo

CAT. NO.	DESCRIPTION
PPICO-012	Piccolo 12/48 with support for 48 channels and 32 attributes*
PPICO-V12	Piccolo 12/48 with support for 48 channels and 32 attributes, Includes VGA video option factory installed*
PPICO-024	Piccolo 12/48 with support for 48 channels and 32 attributes*
PPICO-V24	Piccolo 12/48 with support for 48channels and 32 attributes, Includes VGA video option factory installed*
PPICO-036	Piccolo 36/144 with support for 48 channels and 32 attributes*
PPICO-V36	Piccolo 36/144 with support for 48 channels and 32 attributes, Includes VGA video option factory installed*
PPICO-048	Piccolo 48/192 with support for 48 channels and 32 attributes*
PPICO-V48	Piccolo 48/192 with support for 48 channels and 32 attributes, Includes VGA video option factory installed*
ACCESSORIES	
PPICO-VID	Video option for installation by authorized dealers
CTP-7-5052	Work light
TAMON-F17	17" LCD monitor
TAMDC-F17	Dustcover for 17" LCD monitor
TAMDC-F19	Dustcover for 19" LCD monitor
TAMON-F19	LCD Flat Screen Monitor, Charcoal, 19"

* Power supply included

Leviton Manufacturing Co., Inc. Lighting & Energy Solutions

20497 SW Teton Avenue, Tualatin, OR 97062 • Telephone: 1-800-736-6682 • FAX: 503-404-5594
 Tech Line (6:00AM-4:00PM P.S.T. Monday-Friday): 1-800-959-6004

Leviton Manufacturing Co., Inc. Global Headquarters

201 N. Service Rd. Melville, NY 11747-3138 • Tech Line: 1-800-824-3005 • FAX: 1-800-832-9538

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 • Telephone: 1-800-469-7890 • FAX: 1-800-563-1853

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 • Tel. (+52) 55-5082-1040 • FAX: (+52) 5386-1797 • www.leviton.com.mx

Visit our Website at: www.leviton.com/les