


# Polymer Residential Water Meters

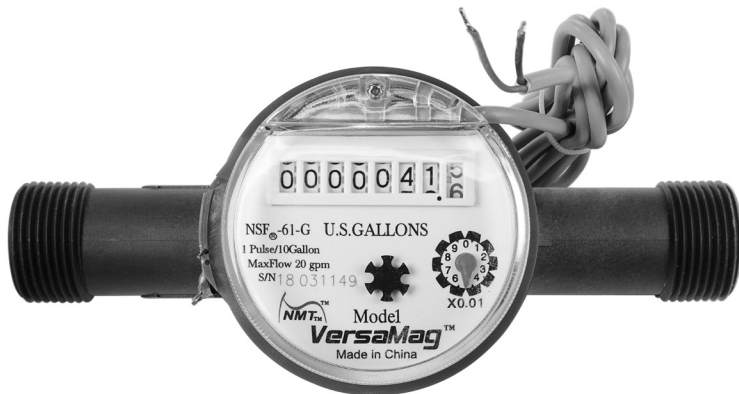

## DESCRIPTION

The Residential Polymer Water Meters, available in Hot and Cold varieties, are versatile for residential measurement and verification applications. Along with their compact design, the removable register allows for pressure tests and flush-outs without damaging the internal components. The meters can be installed in both horizontal and vertical positions while adhering to AWWA C708 accuracy standards\*. Available in both hot and cold versions to meet specific needs of the space.

\*Cannot be installed vertically in California or NTEP states.

## FEATURES

- Meets all AWWA standards
- California CTEP approved for both hot and cold applications
- National NTEP approved for both hot and cold applications
- NSF-61-G
- Pulse output
- Designed for water tenant billing applications
- Available wireless AMR solution


**PRODUCT DATA**



**SPECIFICATIONS**

SPECIFICATIONS	
Material	50% glass-reinforced nylon polymer
Max flow rate	20 gpm
Normal flow range (+/- 1.5%)	1-20 gpm
Nom flow rate	15 gpm
Minimum flow rate	1/4 gpm
Maximum work pressure	150 psi
Maximum work temperature	105° F (cold), 160° F (hot)
Nom pipe size	0.75 in (1.91 cm)
Pulse transmitter	10 gal per pulse

**DIMENSIONS**

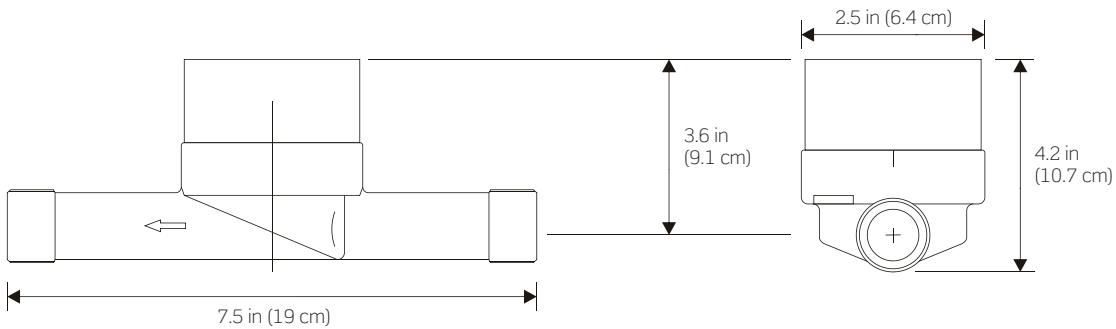

**ORDERING INFORMATION**

CAT. NO.	DESCRIPTION
WMC75-PC1	3/4 in Cold Water Meter - California certified, couplings sold separately
WMH75-PC1	3/4 in Hot Water Meter - California certified, couplings sold separately
WMX75-PZ1	3/4 in Meter Couplings, Polymer Set (2)
WMY75-PY1	3/4 in Spacer Tube, Polymer

**Leviton Manufacturing Co., Inc. Energy Management, Controls and Automation**

20497 SW Teton Avenue, Tualatin, OR 97062 tel 800-736-6682 fax 503-404-5594 tech line (6:00AM-4:00PM PT Mon-Fri) 800-959-6004

**Leviton Manufacturing Co., Inc. Global Headquarters**

201 North Service Road, Melville, NY 11747-3138 tel 800-323-8920 fax 800-832-9538 tech line (8:30AM-7:00PM ET Mon-Fri) 800-824-3005

Visit our Website at: [www.leviton.com/verifeye](http://www.leviton.com/verifeye)

©2019 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

G-10498/E19-tb