

Four Scene Preset Pre-Packaged Dimmer Quick Delivery

FEATURES

- Quick Delivery
- Easy to Install
- Four (4) Scene Preset
- Interfaces to A/V Systems
- 1920 to 5000 Watt Capacity
- Dims Incandescent & Quartz
- Dims Step-Down Transformers (Low Voltage Lighting)
- 100% Solid State Electronics
- SCR Power Device
- Heavy Duty Filter Chokes
- U.L. LISTED, cUL LISTED

Leviton Lighting Control Division's PDQ4 dimmers are Pre-Packaged commercial quality high capacity dimmers with four scene preset controls built in. They are available for quick delivery to meet the time demands of design-build projects.

Restaurants, Churches, Meeting Rooms, Multi Screen Theaters, etc., are projects that require top quality, high power capacity dimmers like Leviton Lighting Control Division's PDQ4. On many of these projects the user needs to have a preset system with timed fades (3 to 45 secs.) so that they can pre-program the lighting for simple one pushbutton operation. The PDQ4 cabinet comes with a high capacity dimmer with ratings from 1920 watts to 5000 watts for



incandescent and low voltage lighting loads. On the front of the dimmer cabinet is a fade rate controller (3 to 45 secs.) and a set of four intensity controllers to set four different lighting levels. Each preset level is recalled by a pushbutton located on the dimmer cabinet or from any number of remote preset select panels. The presets can also be recalled from an Audio/Visual system or a Motion Picture Projector. Several PDQ4 cabinets can be wired together to control more lights.

PDQ4

LEVITON SPECIFICATIONS SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Ordering Information

INCANDESCENT/LOW VOLTAGE DIMMERS

Model No.	PDQ4-1920/LV	PDQ4-2500/LV	PDQ4-3750/LV	PDQ4-5000/LV
Capacity	1920 watts	2500 watts	3750 watts	5000 watts
Input (by others)	20 amps	30 amps	40 amps	50 amps
Branch Breakers	None	2-20 amp	3-20 amp	4-20 amp
Max. Heat Loss	- All dimmers have a heat loss of 2% of connected load -			
Weight	23 lbs	23 lbs.	23 lbs.	23 lbs.
Cabinet Height	18" High	32" High	32" High	32" High
- All Cabinets are 8.375" Wide and 10" deep -				

CONTROL PANELS


Model No.	PRE-1	PRE-4	PRE-4M
No. Presets Selects	1	4	4 + MAX.
No. of LED indicators	1	4	5
Off Switch	Yes	Yes	Yes
Take/Control	- Last action takes precedence -		
Finish*	° Standard - Natural Color Grain Sanded Aluminum -		
No. of #18 wires	5	11	12

*Finish: If no finish is listed, the panel will be supplied with NATURAL COLOR GRAIN SANDED ANODIZED ALUMINUM. For Deluxe finish with screwless appearance, add color code to the end of the Control Panel Model Number.

AL Brushed Aluminum
PR Prime Coat Only

OW Oyster White
BK Brushed Black

PB Polished Brass
BB Brushed Medium Bronze

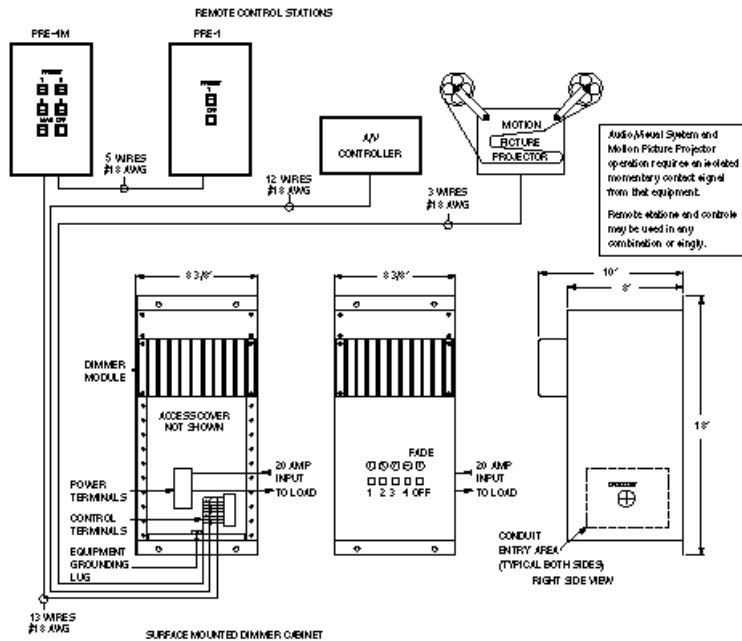

LEVITON SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:
JOB NUMBER:	