

Downlights

For Residential & Light Commercial Applications





Table of Contents

Smooth Slim Downlights	3
Round Baffle Slim Downlights	4
Square Baffle Slim Downlights	5
Adjustable Slim Downlights	6
2-Hour Fire-Rate Baffle Slim Downlights	7
Surface Mount Downlights	8
Motion Sensor Downlights	9
Accessories	10
Ordering Information	11



SMOOTH SLIM DOWNLIGHTS



WET RATED



TITLE 24



AIR-TIGHT



IC RATED

- Available in 4- and 6-inch diameter models
- Ultra slim design for low fixture depth
- Field selectable lumen output and color temperature (CCT)
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- Optional matte black trim ring accessories
- IC Rated, air-tight, and ENERGY STAR®
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(3)




CAT. NO.	DFR40-S1W	DFR60-S1W
SIZE	4-Inch Round	6-Inch Round
LUMEN OUTPUT ¹	650/820Lm	850/1100Lm
INPUT POWER	8/10W	10/13W
CRI	90+	
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K	

1. Values are nominal and vary based on CCT



Ultra Slim Profile

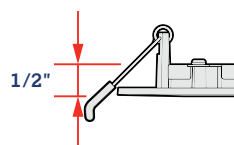

Black Trim Ring available
Sold Separately





ROUND BAFFLE SLIM DOWNLIGHTS



WET RATED



TITLE 24



AIR-TIGHT



IC RATED




- Available in 4-, 6- and 8-inch round apertures
- Field selectable color temperature (CCT)
- Regressed lens with Baffle for reduced glare
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- IC Rated die-cast aluminum housing in a matte white painted finish
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(3)

CAT. NO.	DBR40-S1W	DBR60-S1W	DBR80-S1W
SIZE	4-Inch Round	6-Inch Round	8-Inch Round
LUMEN OUTPUT ¹	820Lm	1100Lm	1500Lm
INPUT POWER	10W	13W	18W
CRI	90+		
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K		

1. Values are nominal and vary based on CCT



 Regressed Lens
Reduced Glare





SQUARE BAFFLE SLIM DOWNLIGHTS



WET RATED



TITLE 24



AIR-TIGHT



IC RATED

- Available in 4- and 6-inch square models
- Field selectable color temperature (CCT)
- Regressed lens with Baffle for reduced glare
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- IC Rated die-cast aluminum housing in a matte white painted finish
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(3)




CAT. NO.	DBS40-S1W	DBS60-S1W
SIZE	4-Inch Round	6-Inch Round
LUMEN OUTPUT ¹	820Lm	1100Lm
INPUT POWER	10W	13W
CRI	90+	
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K	

1. Values are nominal and vary based on CCT



 Regressed Lens
Reduced Glare





ADJUSTABLE SLIM DOWNLIGHTS



WET RATED



TITLE 24



AIR-TIGHT



IC RATED





- Available in 4- and 6-inch diameter models
- Fully adjustable floating gimbal design allows up to 80° of tilt and 350° of rotation
- Field selectable color temperature (CCT)
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- IC Rated die-cast aluminum housing in a matte white painted finish
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(3)

CAT. NO.	DAR40-S1W	DAR60-S1W
SIZE	4-Inch Round	6-Inch Round
LUMEN OUTPUT ¹	820Lm	1100Lm
INPUT POWER	10W	13W
CRI	90+	
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K	

1. Values are nominal and vary based on CCT



Fully Adjustable
80° tilt and 350° rotation

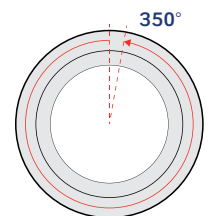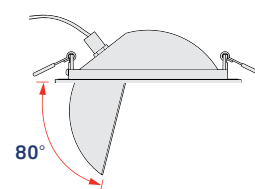




2-HOUR FIRE-RATED BAFFLE SLIM DOWNLIGHTS



FIRE RATED WET RATED TITLE 24 AIR-TIGHT IC RATED

- 2-Hour Fire-Rated, cETLus Listed in accordance with UL263, CAN/ULC S101 and ASTM E119
- Available in 4- and 6-inch round apertures
- Field selectable color temperature (CCT)
- Regressed lens with Baffle for reduced glare
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(3)

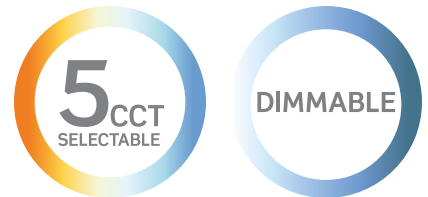


CAT. NO.	FBR40-S1W	FBR60-S1W
SIZE	4-Inch Round	6-Inch Round
LUMEN OUTPUT ¹	1000Lm	1350Lm
INPUT POWER	12W	15W
CRI	90+	
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K	

1. Values are nominal and vary based on CCT



 Regressed Lens
Reduced Glare





SURFACE MOUNT DOWNLIGHTS



WET RATED



TITLE 24

- Available in 5-, 7- and 9-inch round apertures
- Field selectable color temperature (CCT)
- Mounting bracket included to mount easily over most standard junction boxes
- Closed cell gasket included for use in wet location environments
- 120V Forward or Reverse Phase Dimming down to 10%
- Optional matte black trim ring accessories
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(1)



CAT. NO.	SDR50-S1W	SDR70-S1W	SDR90-S1W
SIZE	5-Inch Round	7-Inch Round	9-Inch Round
LUMEN OUTPUT ¹	900Lm	1100Lm	1500Lm
INPUT POWER	10W	13W	18W
CRI	90+		
COLOR TEMPERATURE	2700K / 3000K / 3500K / 4000K / 5000K		

1. Values are nominal and vary based on CCT



Black Trim Ring available
Sold Separately





MOTION SENSOR DOWNLIGHTS




DAMP RATED

- Available in 8-inch round apertures
- Low profile design for easy installation
- Integrated Passive Infrared Sensor (PIR) with 30/180 seconds timeout
- Field selectable color temperature (CCT)
- Mounting bracket included to fit 3-1/2 or 4-1/2 standard junction boxes
- Suitable for use in clothes closets when installed in accordance with NFPA® 70, NEC® Section 410.16 (A)(1) (C)(1)



CAT. NO.	9866-B0W
SIZE	8-Inch Round
LUMEN OUTPUT ¹	1440Lm
INPUT POWER	18W
CRI	80
COLOR TEMPERATURE	3000K / 4000K / 5000K


1. Values are nominal and vary based on CCT

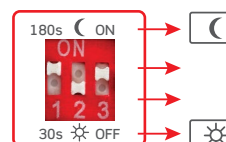

- Switch 1: 30/180 seconds auto time-off options
 Switch 2: Sensor Modes
 • Daytime - Turns on lamp regardless of ambient light.
 • Nighttime - Only turns lamp on when sensor detects motion and there is no ambient light.
 Switch 3: Sensor ON/OFF
 • Turns off sensor so lamp can be used with a single pole switch.

MOUNTING PLATES


DBRCX-H00

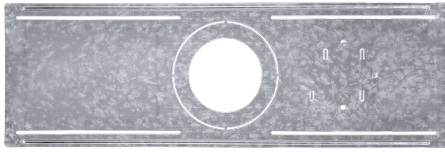

Compatible with:

DFR40-S1W, DFR60-S1W, FBR40-S1W,
FBR60-S1W, DAR40-S1W, DAR60-S1W,
DBR40-S1W, DBR60-S1W

DBSUX-H00

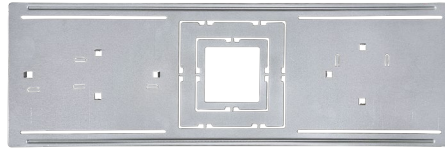

Compatible with:

DBS40-S1W, DBS60-S1W

DBRUX-H00




Compatible with:

DFR40-S1W, DFR60-S1W, FBR40-S1W,
FBR60-S1W, DAR40-S1W, DAR60-S1W,
DBR40-S1W, DBR60-S1W, DBR80-S1W

TRIM RINGS


SDR5X-T0E, SDR7X-T0E, SDR9X-T0E

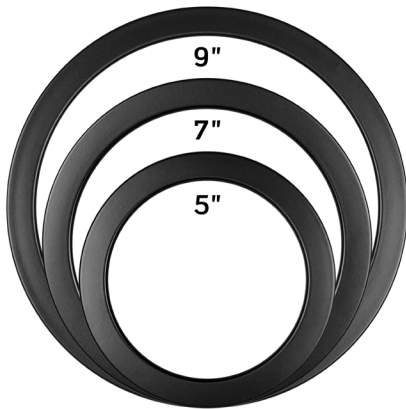

Compatible with:

SDR50-S1W, SDR70-S1W, SDR90-S1W

DFR4X-T0E, DFR6X-T0E

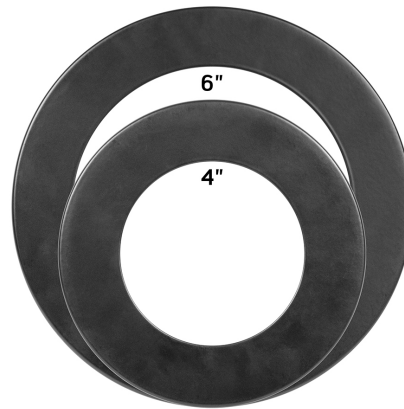

Compatible with:

DFR40-S1W, DFR60-S1W

CABLES

FB00X-ETW



Compatible with:

FBR40-S1W, FBR60-S1W

ORDERING INFORMATION

Smooth Slim Downlights

CAT. NO.	Description	UPC Number	Std. Pack
DFR40-S1W	4" Round Smooth Slim Downlight	07847701456 1	12
DFR60-S1W	6" Round Smooth Slim Downlight	07847703734 8	12
DFR4X-T0E	Trim Ring, 4-In Round Smooth DL, Black	07847703735 5	25
DFR6X-T0E	Trim Ring, 6-In Round Smooth DL, Black	07847703736 2	25
DBRCX-H00	4"/6" New Construction Mounting Plate	07847702352 5	15
DBRUX-H00	4"/6"/8" New Construction Mounting Plate	07847702024 1	15

Round Baffle Slim Downlights

CAT. NO.	Description	UPC Number	Std. Pack
DBR40-S1W	4" Round Baffle Slim Downlight	07847701456 1	12
DBR60-S1W	6" Round Baffle Slim Downlight	07847701460 8	12
DBR80-S1W	8" Round Baffle Slim Downlight	07847701461 5	12
DBRCX-H00	4"/6" New Construction Mounting Plate	07847702352 5	15
DBRUX-H00	4"/6"/8" New Construction Mounting Plate	07847702024 1	15

Square Baffle Slim Downlights

CAT. NO.	Description	UPC Number	Std. Pack
DBS40-S1W	4" Square Baffle Slim Downlight	07847701462 2	12
DBS60-S1W	6" Square Baffle Slim Downlight	07847701463 9	12
DBSUX-H00	4"/6" Square Mounting Plate	07847702028 9	15

Adjustable Slim Downlights

CAT. NO.	Description	UPC Number	Std. Pack
DAR40-S1W	4" Round Adjustable Slim Downlight	07847702366 2	12
DAR60-S1W	6" Round Adjustable Slim Downlight	07847702367 9	12
DBRCX-H00	4"/6" New Construction Mounting Plate	07847702352 5	15
DBRUX-H00	4"/6"/8" New Construction Mounting Plate	07847702024 1	15

2-Hour Fire-Rate Baffle Slim Downlights

CAT. NO.	Description	UPC Number	Std. Pack
FBR40-S1W	4" Fire-Rated Baffle Slim Downlight	07847702803 2	12
FBR60-S1W	6" Fire-Rated Baffle Slim Downlight	07847702804 9	12
FB00X-ETW	20' Extension Cable	07847702805 6	50
DBRCX-H00	4" / 6" NC Mounting Plate	07847702352 5	15

Surface Mount Downlights

CAT. NO.	Description	UPC Number	Std. Pack
SDR50-S1W	5" Round Surface Mount Downlight	07847702806 3	24
SDR70-S1W	7" Round Surface Mount Downlight	07847702807 0	24
SDR90-S1W	9" Round Surface Mount Downlight	07847702808 7	18
SDR5X-T0E	Trim Ring, 5" Round Surface MT, Black	07847702809 4	24
SDR7X-T0E	Trim Ring, 7" Round Surface MT, Black	07847702810 0	24
SDR9X-T0E	Trim Ring, 9" Round Surface MT, Black	07847702811 7	18

Motion Sensor Downlights

CAT. NO.	Description	UPC Number	Std. Pack
9866-B0W	8" Round Motion Sensor Downlight	07847787745 6	20



LED Compatibility Tool

Find compatible fixtures for your Leviton Dimmer

Use the LED Compatibility Tool to find the right Leviton dimmer and LED fixture combination for a seamless dimming experience.

Learn more at [Leviton.com/LED](https://leviton.com/LED), or scan the QR Code:



Decora Smart Wi-Fi Dimmer Switch (D36HD) with My Leviton App



Decora Slide Dimmer (DSL01)



Toggle Slide Dimmer (TSL01)

Better Together.

Easy to use, flexible applications, high-end performance.

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • Tech Line: 1-800-824-3005 (M-F 8AM-10PM EST, Sat 9AM-7PM EST)

Leviton Manufacturing Co., Inc. Lighting & Controls

10385 SW Avery Street, Tualatin, OR 97062

Telephone: 1-800-736-6682 • Tech Line: 1-800-959-6004 (M-F 6AM-4PM PST)

Visit our Website at: leviton.com/downlights

© 2026 Leviton Manufacturing Co., Inc. All rights reserved. Specifications subject to change without notice.

SCAN TO EXPLORE ALL
LIGHTING PRODUCT
DETAILS & VIDEOS

