

## Dimmer Compatibility

Ensure your customers have an exceptional lighting experience.



Designed and Tested for  
Compatibility and Performance

### DIMMERS:

**SureSlide:** 6672, 6674N, 6674

**IllumaTech:** IPL06

**Decora Slide with Lever Edge:** ESL01

**Decora Slide:** DSL06, DSE06

**Decora Digital:** DDM06

**Decora Smart Wi-Fi:** D2ELV

**Toggle Slide:** TSL06

**Trimatron Rotary:** RDL06, RNL06



## Certifications



cETLus  
Listed



Wet  
Location



ENERGY  
STAR®



T24  
Part 6 JA8

- cETLus listed in accordance with UL 1598 and CSA C22.2 No. 250.0
- Suitable for Wet Locations, covered ceilings
- ENERGY STAR® Certified
- Complies with Title 24 Part 6 JA8 High Efficacy LED Light Source Requirements
- Suitable for use in clothes closets when installed in accordance with NFPA® 70 Section NEC® 410.16 (A)(1) (C)(1) spacing requirements



Scan to learn more  
Downlights and Dimmers

Visit us at [www.leviton.com](http://www.leviton.com)



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am – 5pm EST  
For 24/7 product support visit [www.leviton.com/support](http://www.leviton.com/support)

© 2025 Leviton Manufacturing Co., Inc. All rights reserved.



CS-120125



## Surface Mount Fixtures

Easy to use, flexible applications,  
premium performance



THE FUTURE IS ON®



## FEATURES

### Ease of Use

- New and Remodel Construction
- Driver on board design allows for easy mounting to most industry standard junction boxes (including shallow pancake style ceiling boxes)

### Performance

- The color rendering of the room surfaces and materials is enhanced by 90+ CRI LEDs
- Long-life LEDs are rated for 70% of the original light level after 50,000 hours of use
- Consistent dimming performance with Leviton compatible dimmers down to 10%
- 5-Year warranty after date of purchase




### Flexibility

- With an overall 0.73" height, it provides a low-profile solution that blends into the environment
- Select from five (5) different Color Temperatures with a slide switch on the back of the fixture
- Designed for a wide range of applications: Residential, Multi-Family, Hospitality, and Light Commercial spaces

### Trim Ring Accessories

- Optional matte black trim rings are available for a bolder appearance
- Designed for easy installation and available in three different sizes

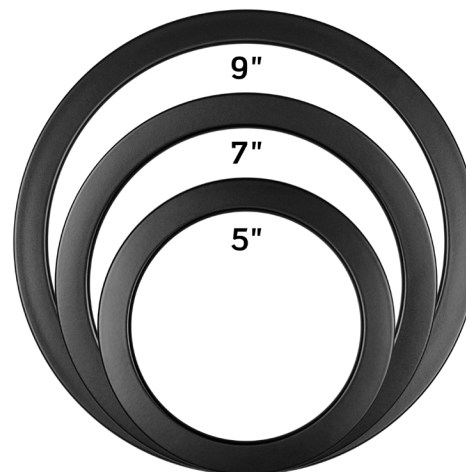

## Performance

### 5-INCH SURFACE MOUNT

CAT NO.	SDR50-S1W
LUMEN OUTPUT	900Lm
INPUT POWER	12W



### 7-INCH SURFACE MOUNT

CAT NO.	SDR70-S1W
LUMEN OUTPUT	1100Lm
INPUT POWER	15W



### 9-INCH SURFACE MOUNT

CAT NO.	SDR90-S1W
LUMEN OUTPUT	1500Lm
INPUT POWER	18W

