

## OneReach™ Remote PoE Port

Remote, 2-port, 10/100/1000BASE-T, 1000BASE-SX, PoE++, 2 x LC duplex, MMF, RJ-45, 56 VDC in M8 Power Input

### APPLICATION

The 2-port Remote PoE Port is part of the OneReach system, designed to support PoE at distances far in excess of the 100-meter limit of copper cabling alone. The device mounts in NEMA-rated enclosures and connects to active devices using category-rated cables terminated with standard RJ-45 connectors.



### DESCRIPTION

The 2-port Remote PoE Port performs two functions:

1. Converts 1000BASE-SX fiber Ethernet to 10/100/1000BASE-T copper Ethernet.
2. Provides IEEE 802.3 compliant Power over Ethernet (up to Type 4, Class 8) to up to two network powered device, up to 100 meters (328 ft) away.

### BENEFITS

- No need to install costly remote power outlets
- No need to install remote industrial switches
- Easily attach pre-terminated LC connectors for data transmission
- Standard M8 connector screws into place to complete DC power circuit
- Uses standard RJ-45 connectivity to patch to the security camera, wireless access point, or any other IP-based device
- Allows common pathway for fiber backbone and Class 2 power supply
- Supports two PoE or PoE+ devices; one PoE++ (60 W) and one PoE or PoE+ device; or one PoE++ (100 W) and one data device

### STANDARDS & REGULATIONS

- EN 50173
- ISO/IEC 11801
- IEC 61000 4-5 Surge Immunity - Level 4
- IEEE 802.3 10/100/1000BASE-T, 1000BASE-X
- Telcordia GR-468-CORE
- c(UL)us Listed
- IEC/UL 60950-1
- FCC Part 15 Subpart B EMC

### MECHANICAL SPECIFICATIONS

Weight:	Approximate net weight 2 lb (0.9 kg)
Materials:	ABS Polymer and plated steel
Dimensions:	1.74 in (44.2 mm) x 1.70 in (43.2 mm) x 8.25 in (210 mm)


Temp. (Storage):	-40 °C to +85 °C (-40 °F to +185 °F)
Temp. (Operating):	-40 °C to +70 °C (-40 °F to +158 °F)
Altitude (Operating):	-300 ft to 10,000 ft (-91.4 m to 3,048 m)
Humidity (Max.):	90% relative humidity, non-condensing

### WARRANTY INFORMATION

For Leviton product warranties, go to [leviton.com/ns/warranty](http://leviton.com/ns/warranty)

**PRODUCT SPECIFICATIONS**  
**81001534**

81001534

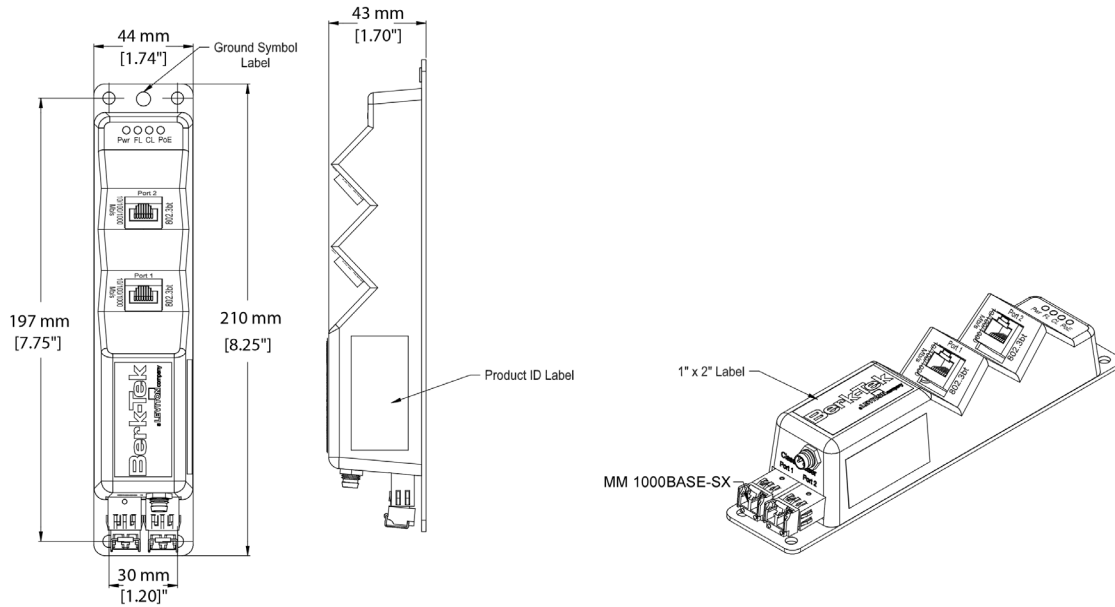

**CHARACTERISTICS**

**Construction**

Color	Black
Connector type	LC Duplex & M8
Fiber optic type	Multimode
Number of ports	2

**Mechanical**

Speed*	10/100/1000 Mbps for copper port 100 Mbps for fiber port
--------	---

\*Support for 10/100/1000BASE-T copper structured cabling communications and 1000BASE-SX multimode fiber cabling communication

**ONEREACH™ REMOTE POE PORT**

Description	Part No.
2-port Remote, MMF	81001534

For further support information, visit [leviton.com/ns/support](http://leviton.com/ns/support)