

Hook & Loop Wraps - Bulk Rolls

APPLICATION

Hook and loop bulk rolls are used for low-voltage multimedia and cord management. While other methods of cable support have the potential to kink or crimp, hook and loop bulk rolls offer a great way to safely organize and manage cables.



SPECIFICATION

Rolls shall be offered in 15-, 75-, and 600-foot lengths, and will all standardize on a 0.5-inch width. Maroon color shall be offered as a plenum-rated product. Shear strength for plenum-rated product shall be 29 PSI; non-plenum-rated product shear strength shall be 23 PSI.

FEATURES & BENEFITS

- Reusable solution for moves, adds, and changes
- Available in 15-, 75-, and 600-foot bulk rolls
- UL listed for use in plenum or air-handling spaces per NEC, Section 300-22 - maroon products only
- Offers flexible and orderly cable/cord routing

DESIGN CONSIDERATIONS

- Hook and loop fasteners provide a dependable way to secure cable run
- Cut to desired length

MECHANICAL SPECIFICATIONS

Dimensions: See page 2

Colors: See page 2

Temp. (Storage): -17 °C to + 105 °C (0 °F to + 222 °F)

Temp. (Installation): Refer to cable installation temperature

Temp. (Operating): -17 °C to + 105 °C (0 °F to + 222 °F)

COUNTRY OF ORIGIN

USA

WARRANTY INFORMATION


For Leviton product warranties, go to Leviton.com/ns/warranty

43115-xxx

PRODUCT SPECIFICATIONS

43115-xxx

43115-XXX

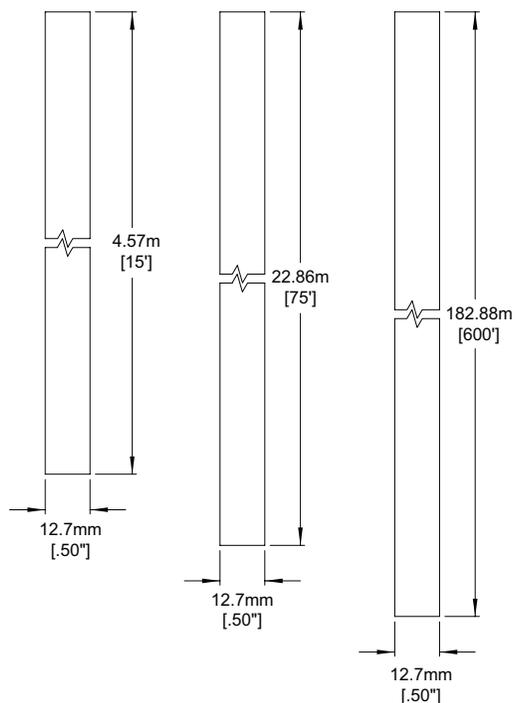

PART NUMBERS	
Description	Part No.
15' Bulk Roll	43115-15x
75' Bulk Roll	43115-75x
15' Bulk Roll, Black	43115-015
75' Bulk Roll, Black	43115-075
600' Bulk Roll, Black	43115-600

x = Color: Blue (L), Yellow (Y), Orange (O), Maroon (P)

For further support information, visit Leviton.com/ns/support