

PRODUCT SPECIFICATIONS

49256-WxM, 49256-WxL

Angled UTP White QUICKPORT™ Patch Panels

APPLICATION

Angled UTP White QUICKPORT Patch Panels feature a customizable design for fiber and copper applications, accepting all QUICKPORT snap-in jacks for optimum rack density on industry-standard racks. The panels feature an angled design to easily route cables into vertical cable managers, eliminating the need for horizontal front cable management bars. Panels fit all industry-standard 19-inch racks and cabinets. They are available with either black silkscreen blocks or magnifying lens label holders.



24-port panel, 1RU,
w/ magnifying lens



48-port panel, 2RU

SPECIFICATION

Angled patch panels shall be made of 16-gauge steel, and shall have a white powder coat finish with numbers for each port. Panels shall be available with black silkscreen blocks for labeling or magnifying lens label holders. The panels shall be offered in 24- and 48-port configurations. The panel shall have the ability to allow for single port replacement of inoperative ports.

FEATURES & BENEFITS

- White finish with black silkscreen blocks
- Optional magnifying lens label holders available
- Cords route directly into vertical managers from angled panel, saving rack space by eliminating horizontal management
- Models with magnifying lens ensure visibility of port labels
- Panel comes with silver mounting screws
- Black silkscreened blocks are provided for perfect alignment of machine printed labels

DESIGN CONSIDERATIONS

- Mounts on 19-inch equipment racks
- Accepts all QUICKPORT and QUICKPORT-compatible connectors
- Versions available with magnifying lens label holder
- Rear cable manager not included, sold separately (49006-AMB)

STANDARDS & REGULATIONS

- ANSI/TIA-568
- c(UL)us Listed

MECHANICAL SPECIFICATIONS

Dimensions:	See page 2
Materials:	16-gauge steel, white powder coating; magnifying lenses are high-impact, fire-retardant plastic
Mounting:	19-inch rack mount
Temp.(Storage):	-40 °C to +70 °C (-40 °F to +158 °F)
Temp. (Installation):	Refer to cable installation temperature
Temp. (Operating):	-10 °C to +60 °C (+14 °F to +140 °F)

COUNTRY OF ORIGIN

49256-W4L: China
49256-W4M: Please contact Customer Service
49256-W8x: Taiwan





WARRANTY INFORMATION

For Leviton product warranties, go to leviton.com/ns/warranty

49256-WxM, 49256-WxL

PRODUCT SPECIFICATIONS

49256-WxM, 49256-WxL

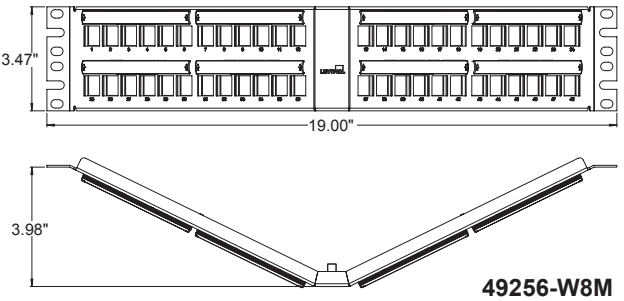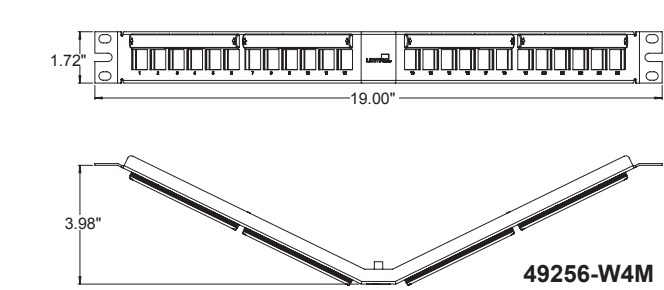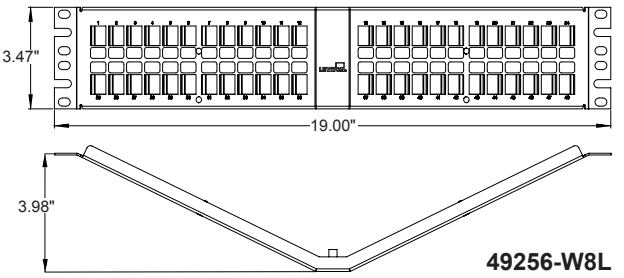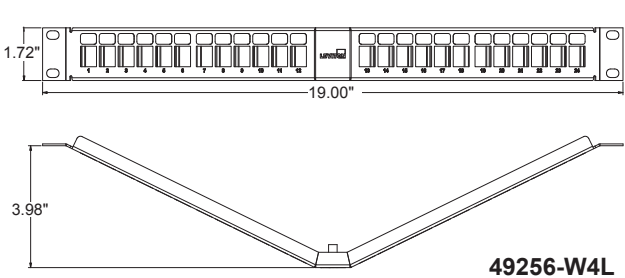

49256-WxM, 49256-WxL

PART NUMBERS	
Description	Part No.
Angled UTP White QUICKPORT™ Patch Panel, 24-port, 1RU	49256-W4L
Angled UTP White QUICKPORT Panel, 48-port, 2RU	49256-W8L
Angled UTP White QUICKPORT Panel, 24-port, 1RU, with magnifying lens	49256-W4M
Angled UTP White QUICKPORT Panel, 48-port, 2RU, with magnifying lens	49256-W8M

For further support information, visit leviton.com/ns/support