

Midsize Single-Gang QuickPort® Wallplates

APPLICATION

Midsize Single-Gang QuickPort Wallplates accept QuickPort snap-in modules to support multimedia applications with 1, 2, 3, 4, or 6 ports. Midsize wallplates are 3/8-inch taller and wider than standard wallplates. These wallplates are designed for applications where a one-piece, single-gang, economical flush-mount housing is desired to help cover irregular or oversized wall openings. The wallplates are made of a durable, smooth-finish nylon material and come in four color choices (white, light almond, ivory, and brown) with color-matched screws.



SPECIFICATION

The wallplate shall be a one-piece, single-gang flush-mount style that fits standard NEMA openings or four-square boxes with reducer. Wallplate shall be 3/8-inch taller and wider than standard wallplates. It shall provide 1, 2, 3, 4, or 6 port capacity for Leviton QuickPort connector modules. It shall be made of high-impact, fire-retardant nylon plastic rated UL 94V-2 and shall be cULus Listed and compliant with ANSI/TIA-568-C.0 specifications. The wallplate shall accommodate low-voltage box eliminators for a flush mount.

FEATURES

- 3/8-inch taller and wider than standard wallplates
- Durable smooth finish nylon material
- Color-matched wallplate screws
- Compatible with all individual QuickPort modules
- Individual port configurability allows specification flexibility
- Narrow module width allows high port density in a small area
- Accommodates low-voltage box eliminators for a flush mount

DESIGN CONSIDERATIONS

- Fits single-gang back boxes, or four-square boxes with appropriate user-provided reducer
- Install blanks in unused ports for future expansion (41084-B*B)
- To identify ports, use different colored connectors for each application, or use Leviton pre-printed Port Designation Labels (41080-LEB)

STANDARDS COMPLIANCE

- cULus Listed (UL 1863 & CAN/CSA-C22.2 No. 182.4)
- ANSI/TIA-568-C.0

PHYSICAL SPECIFICATIONS

- Dimensions: See page two
Materials: High-impact, durable, fire-retardant nylon plastic rated UL 94V-2
Capacity: 1, 2, 3, 4, and 6 QuickPort connector modules
Mounting: Color matched screws

COUNTRY OF ORIGIN


USA

WARRANTY INFORMATION

For a copy of Leviton product warranties, visit www.leviton.com/warranty.

ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

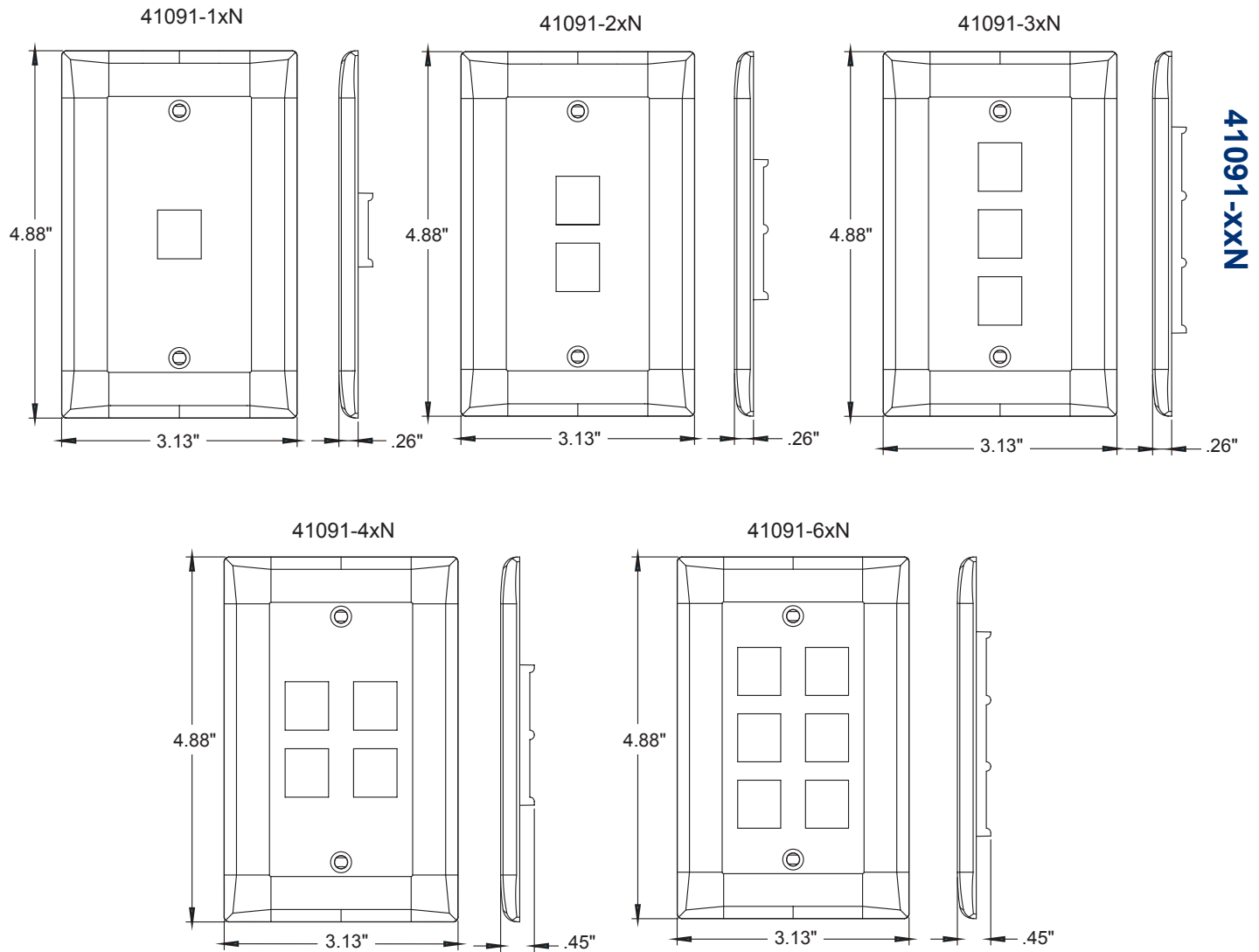

PART NUMBERS

Description	WHITE	LT. ALMOND	IVORY	BROWN
Midsize Single-Gang QuickPort® Wallplate, 1 Port	41091-1WN	41091-1TN	41091-1IN	41091-1BN
Midsize Single-Gang QuickPort Wallplate, 2 Ports	41091-2WN	41091-2TN	41091-2IN	41091-2BN
Midsize Single-Gang QuickPort Wallplate, 3 Ports	41091-3WN	41091-3TN	41091-3IN	41091-3BN
Midsize Single-Gang QuickPort Wallplate, 4 Ports	41091-4WN	41091-4TN	41091-4IN	41091-4BN
Midsize Single-Gang QuickPort Wallplate, 6 Ports	41091-6WN	41091-6TN	41091-6IN	41091-6BN

Leviton Network Solutions
2222 - 222nd St. SE
Bothell, WA 98021-4416

Asia / Pacific
T +1.631.812.6228
E infoasean@leviton.com

Canada
T +1.514.954.1840
E pcservice@leviton.com

Caribbean
T +1.954.593.1896
E infocaribbean@leviton.com

China
T +852.2774.9876
E infochina@leviton.com

Colombia
T +57.1.743.6045
E infocolombia@leviton.com

tel 1-800-824-3005
tel +1-425-486-2222
appeng@leviton.com
www.leviton.com

Europe
T +33.6.8869.1380
E infoeurope@leviton.com

India / SAARC
T +971.4.886.4722
E infoindia@leviton.com

Mexico
T +52.55.5082.1040
E lsamarketing@leviton.com

Middle East & Africa
T +971.4.886.4722
E lmeinfo@leviton.com

South Korea
T +82.2.3273.9963
E infokorea@leviton.com