

QUICKPORT™ Round Floor Jack Inserts & Assemblies

APPLICATION

Rugged and fully field-configurable, this device provides point-of-use connectivity for a broad range of applications where convenience or building requirements dictate the use of a floor-mounted communications outlet. Each floor plate is made of .06" thick solid brass to hold up under heavy furniture or foot traffic. When not in use, a flush-fitting brass screw cap keeps internal components free from dirt and dust. The two individual ports are configured easily with any combination of QUICKPORT Snap-in Modules. QUICKPORT floor jacks will fit standard metal boxes 3" x 2", 3" x 2 1/8", and larger.



SPECIFICATION

The floor jack assembly shall include a field configurable NEMA-style ivory insert, a satin brass cover plate, and a threaded satin brass cap. The assembly shall mount flush to standard single-gang NEMA boxes. The assembly shall provide 2 ports which are available in pre-configured or field configurable options and shall be compatible with a variety of UTP, shielded, and Audio/Video QUICKPORT Snap-in connectors. Plastic components shall be constructed of high-impact, fire-retardant plastic rated UL 94V-0, and be cULus listed and compliant to ANSI/TIA 568 series. Snap-in 6P6C connectors shall be FCC Part 68 compliant.

FEATURES

- Satin finish on brass floor plate & screw cap
- Flush-fitting brass screw cap keeps internal components free from dirt and dust when not in use
- Accepts a variety of UTP, Shielded, and A/V QUICKPORT Snap-in Connectors

DESIGN CONSIDERATIONS

- Use where a floor-mounted communications outlet is required
- Floor jack assemblies will fit standard metal boxes 3" x 2", 3" x 2 1/8", and larger
- Durable brass floor plate withstands heavy furniture or foot traffic
- Available in single gang only
- Put blanks (PN# 41084-0B*) in unused ports for future expansion

STANDARDS & REGULATIONS

- cULus Listed
- Complies with NEC® Article 800
- ANSI/TIA 568 Series

MECHANICAL SPECIFICATIONS


Dimensions:	2.75" W x 4.5" H x 1.66" D (loaded)
Materials:	Brass Plate and Cap: 70/30 Brass alloy with satin finish Insert: High impact, fire retardant polymer rated UL 94V-0
Capacity:	Available in 1- and 2-port versions

WARRANTY INFORMATION

For Leviton product warranties, go to leviton.com/ns/warranty

41650-00x, 41652-0xx

PRODUCT SPECIFICATIONS
41650-00x, 41652-0xx

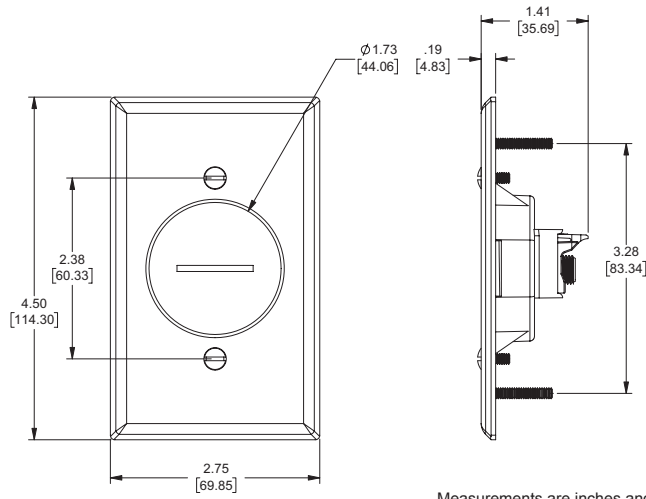

Measurements are inches and millimeters

PART NUMBERS

Description	Part No.
Floor plate assembly with one F-connector, one blank module	41650-00F
Floor plate assembly with one 6P6C connector, one blank module	41650-006
Floor plate assembly with one blank module	41652-000
Floor plate assembly with two 6P6C connector	41652-006
Floor plate assembly with one 6P6C connector, one F-connector	41652-06F
Replacement Floor Plate Cap	5249-CAP

For further support information, visit leviton.com/ns/support