

## Single-Gang and Dual-Gang QUICKPORT™ Wallplates with ID Windows

### APPLICATION

Leviton single-gang and dual-gang wallplates accept QUICKPORT snap-in modules to support multimedia station applications with 1, 2, 3, 4, 6, 8, and 12 ports. Use where port designation windows in a single-gang or dual-gang economical flush-mount housing is desired. Available in five colors: white, light almond, grey, ivory, and black.



### SPECIFICATION

The wallplate shall be a one-piece, single- or dual-gang flush-mount style that fits standard NEMA openings and accommodates low-voltage box eliminators for a flush installation. The wallplate shall be available with 1, 2, 3, 4, 6, 8, or 12 ports. The wallplate shall accept all Leviton QUICKPORT connectors. The wallplate shall feature clear port ID windows and include white label stock. The wallplate shall be molded from high-impact, fire-retardant plastic rated UL 94V-0, and be cULus Listed and compliant with ANSI/TIA 568 Series. The included wallplate mounting screws shall match wallplate color.

### FEATURES

- Includes ID designation windows for each wallplate
- Color-matched wallplate screws
- Fits standard NEMA box mount dimensions and accommodates low-voltage box eliminators for a flush installation
- Compatible with all individual QUICKPORT modules
- Individual port configurability allows specification flexibility
- Narrow module width allows high port density in a small area

### DESIGN CONSIDERATIONS

- Single-gang fits standard NEMA single-gang back boxes; dual-gang fits dual-gang standard NEMA back boxes; fits 4-square and 5-square boxes with appropriate reducer
- Put blanks (41084-0Bx) in unused ports for future expansion
- Differentiate ports with designation labels and up to 13 different color options for connectors
- 4, 6, 8, and 12 port plates may be used for MUTOA (multi-user telecommunications outlet assembly) applications

### STANDARDS & REGULATIONS

- cULus Listed (UL 1863 & CAN/CSA-C22.2 No. 182.4)
- ANSI/TIA 568 Series

### PHYSICAL SPECIFICATIONS

Dimensions:	See page two
Materials:	High-impact, fire-retardant plastic rated UL 94V-0
Capacity:	Single-gang: Available in 1, 2, 3, 4, or 6 ports Dual-gang: Available in 1, 2, 3, 4, 6, 8, or 12 ports

### COUNTRY OF ORIGIN


Please Contact Customer Service

### WARRANTY INFORMATION


For Leviton product warranties, go to [leviton.com/ns/warranty](http://leviton.com/ns/warranty)

42080-xxS, 42080-xxP, 42080-12x

Single-Gang

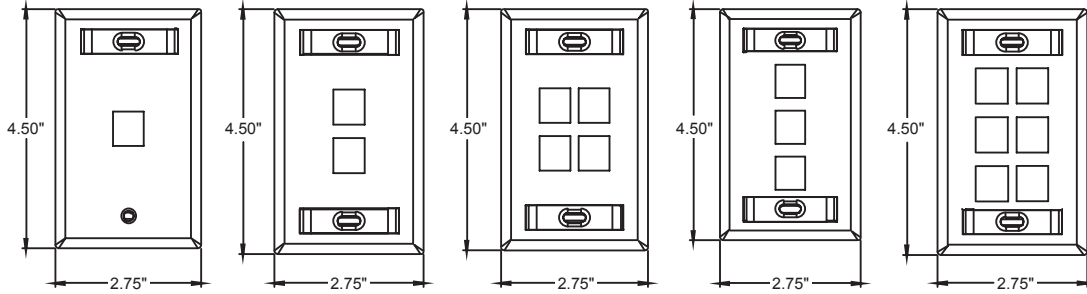

Dual-Gang

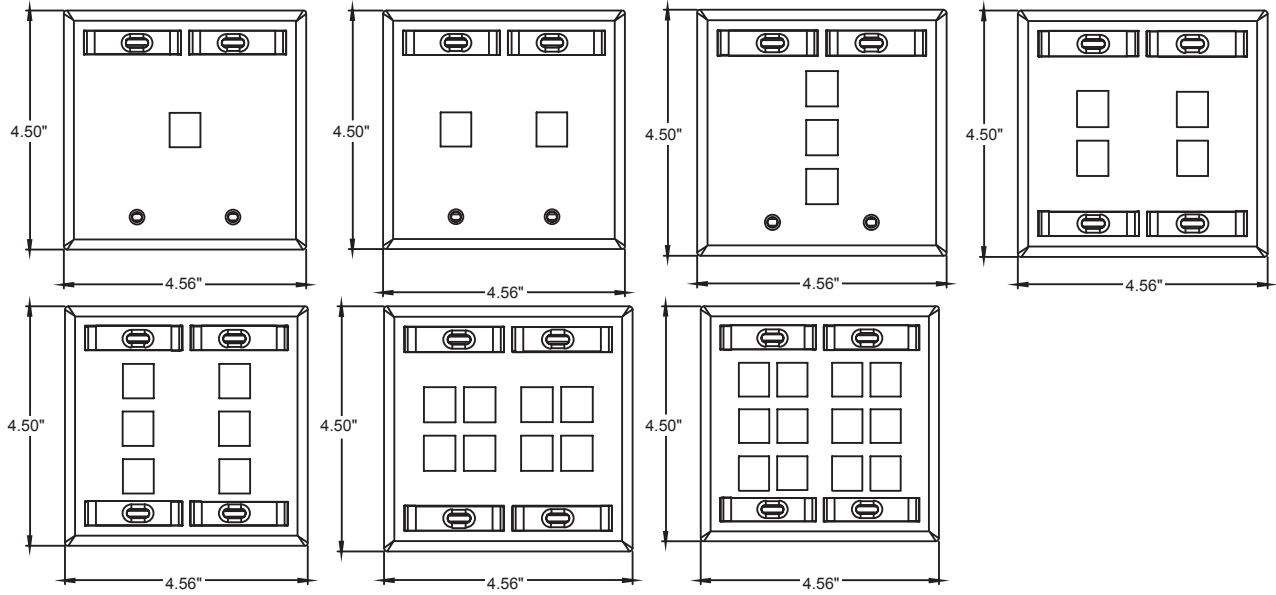

42080-xxS, 42080-xxP, 42080-12x

**PRODUCT SPECIFICATIONS**  
**42080-xxS, 42080-xxP, 42080-12x**



42080-xxS, 42080-xxP, 42080-12x

SINGLE-GANG QUICKPORT™ WALLPLATES WITH ID WINDOWS					
Description	White	Lt. Almond	Ivory	Gray	Black
6-Port Wallplate	42080-6WS	42080-6TS	42080-6IS	42080-6GS	42080-6ES
4-Port Wallplate	42080-4WS	42080-4TS	42080-4IS	42080-4GS	42080-4ES
3-Port Wallplate	42080-3WS	42080-3TS	42080-3IS	42080-3GS	42080-3ES
2-Port Wallplate	42080-2WS	42080-2TS	42080-2IS	42080-2GS	42080-2ES
1-Port Wallplate*	42080-1WS	42080-1TS	42080-1IS	42080-1GS	42080-1ES

DUAL-GANG QUICKPORT WALLPLATES WITH ID WINDOWS					
Description	White	Lt. Almond	Ivory	Gray	Black
12-Port Wallplate	42080-12W	42080-12T	42080-12I	42080-12G	42080-12E
8-Port Wallplate	42080-8WP	42080-8TP	42080-8IP	42080-8GP	42080-8EP
6-Port Wallplate	42080-6WP	42080-6TP	42080-6IP	42080-6GP	42080-6EP
4-Port Wallplate	42080-4WP	42080-4TP	42080-4IP	42080-4GP	42080-4EP
3-Port Wallplate	42080-3WP	42080-3TP	42080-3IP	42080-3GP	42080-3EP
2-Port Wallplate†	42080-2WP	42080-2TP	42080-2IP	42080-2GP	42080-2EP
1-Port Wallplate†	42080-1WP	42080-1TP	42080-1IP	42080-1GP	42080-1EP

Wallplates are sold empty

\* = Single-gang 1-port wallplates only have one ID window on top

† = Dual-gang 1- and 2-port wallplates only have two ID windows on top

For further support information, visit [leviton.com/ns/support](http://leviton.com/ns/support)

Page 3 of 3

**USA**  
 Network Solutions Headquarters  
 +1 (800) 722 2082  
[infoUSA@leviton.com](mailto:infoUSA@leviton.com)

Leviton Berk-Tek Cable: +1 (800) 237 5835  
[berktek.info@leviton.com](mailto:berktek.info@leviton.com)

**Asia Pacific**  
 +852 3620 2602  
[infoAPAC@leviton.com](mailto:infoAPAC@leviton.com)

**Canada**  
 +1 (800) 461 2002  
[infoCanada@leviton.com](mailto:infoCanada@leviton.com)

**Europe**  
 +44 (0) 1592 772124  
[infoEurope@leviton.com](mailto:infoEurope@leviton.com)

**Latin America**  
 MX: +52 (55) 2128 6286  
 LATAM: +52 (55) 2333 5963  
[infoLATAM@leviton.com](mailto:infoLATAM@leviton.com)

**Middle East & Africa**  
 +971 (4) 247 9800  
[infoMEA@leviton.com](mailto:infoMEA@leviton.com)

NETWORK SOLUTIONS PRODUCTS ARE AVAILABLE WORLDWIDE IN OVER 100 COUNTRIES. VISIT US ONLINE AT [LEVITON.COM/NS](http://LEVITON.COM/NS) TO LEARN MORE.