

Stainless-Steel QuickPort® Wallplates with ID Windows

APPLICATION

Leviton single-gang and dual-gang Stainless-Steel Wallplates with ID Windows offer field-configurable flexibility, and accept QuickPort snap-in connectors and adapters to support a variety of commercial and residential applications. Available in several port configurations; the single-gang wallplate comes in 1, 2, 3, 4, or 6 ports, and the dual-gang version comes in 4 or 8 ports.



SPECIFICATION

Single-gang and dual-gang stainless-steel wallplates shall be field configurable, and accept QuickPort snap-in connectors and adapters to support commercial and residential applications. The single-gang wallplate shall provide 1, 2, 3, 4, or 6 ports, and the dual-gang wallplate shall provide 4 or 8 ports. Wallplate mounting screw holes shall be slotted to permit leveling (+/- 4 degrees for single gang and +/- 2 degrees for double gang) in out of level wall boxes, and shall be hidden behind labeling identification windows at the top and bottom of each wallplate opening. Each wallplate shall have a brushed stainless-steel finish, fit standard NEMA electrical boxes, be cULus Listed, and compliant with ANSI/TIA-568-C.0 specifications.

FEATURES

- Compatible with all individual QuickPort connectors and adapters
- Fits standard NEMA electrical boxes and accommodates low-voltage box eliminators for a flush mount
- Includes ID windows for each wallplate
- Individual port configurability allows specification flexibility
- Brushed stainless-steel finish
- Slotted mounting holes allow installers to level the plate if the backbox is crooked

DESIGN CONSIDERATIONS

- Fits standard NEMA single- and dual-gang back boxes
- For future expansion, install blanks (41084-0Bx) in unused ports
- To identify ports, use different colored connectors for each application, or Leviton pre-printed Port Designation Labels (41080-LEB)

STANDARDS COMPLIANCE

- ANSI/TIA-568-C.0
- cULus Listed (UL 1863 & CAN/CSA-C22.2 No. 182.4)

PHYSICAL SPECIFICATIONS

Dimensions: See page two
Materials: Type 304 stainless steel, ABS plastic carrier
Capacity: Single-gang: 1-, 2-, 3-, 4- or 6-port versions
Dual-gang: 4- or 8-port versions

COUNTRY OF ORIGIN


Taiwan

WARRANTY INFORMATION

For a copy of Leviton product warranties, visit www.leviton.com/warranty.

ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

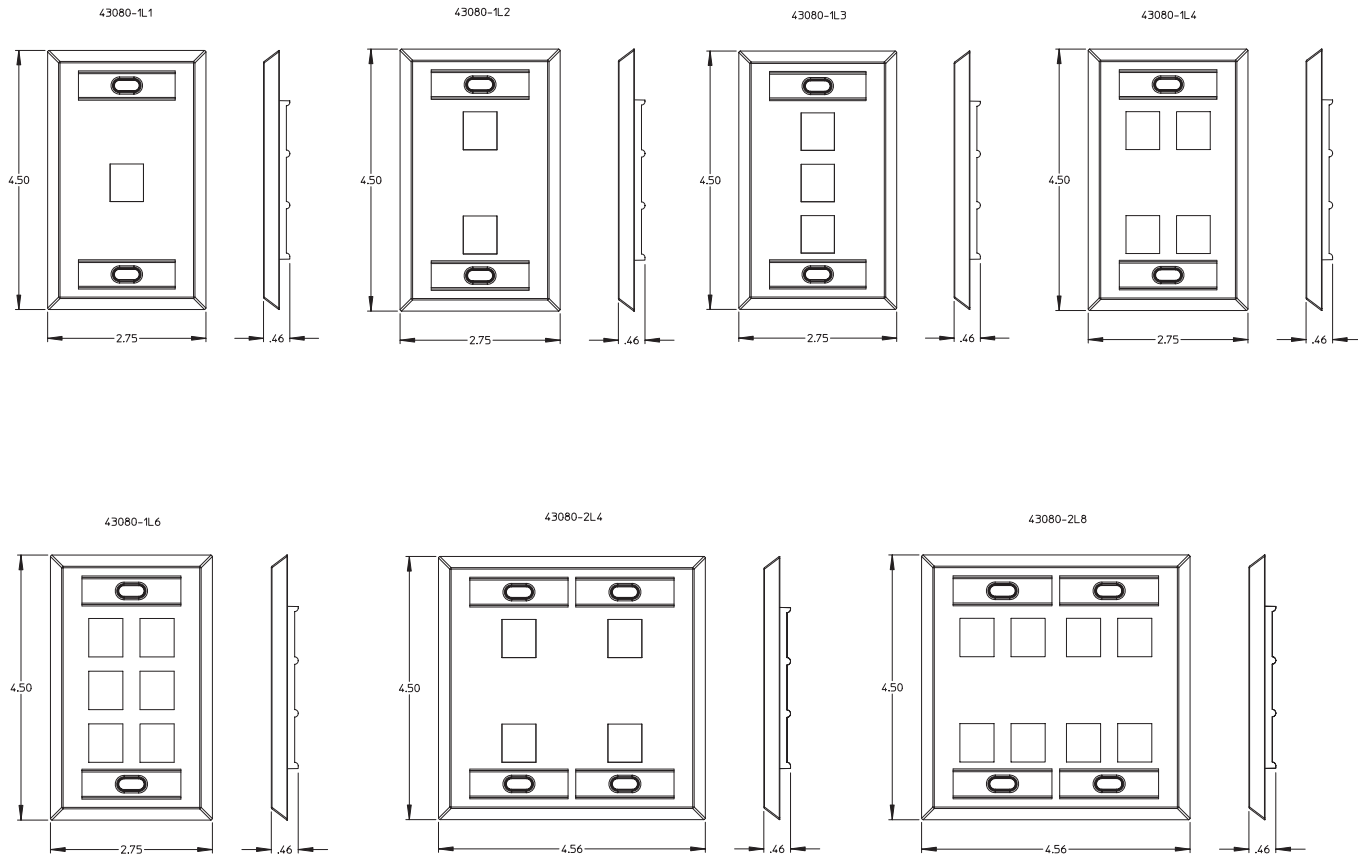

43080-1Lx, 43080-2Lx

PART NUMBERS

| Description | Part No. |
|--|-----------|
| Stainless-Steel QuickPort® Wallplate with ID Window, Single Gang | 43080-1Lx |
| Stainless-Steel QuickPort Wallplate with ID Window, Dual Gang | 43080-2Lx |

x = Single-Gang available in One (1), Two (2), Three (3), Four (4), or Six (6) ports
 x = Dual-Gang available in Four (4) or Eight (8) ports

Leviton Network Solutions
 2222 - 222nd St. SE
 Bothell, WA 98021-4416

Asia / Pacific
 T +1.631.812.6228
 E infoasean@leviton.com

Canada
 T +1.514.954.1840
 E pcservice@leviton.com

Caribbean
 T +1.954.593.1896
 E infocaribbean@leviton.com

China
 T +852.2774.9876
 E infochina@leviton.com

Colombia
 T +57.1.743.6045
 E infocolombia@leviton.com

tel 1-800-824-3005
 tel +1-425-486-2222
appeng@leviton.com
www.leviton.com

Europe
 T +44.0.1592.772124
 E customerservice@brand-rex.com

India / SAARC
 T +971.4.886.4722
 E infoindia@leviton.com

Mexico
 T +52.55.5082.1040
 E lsamarketing@leviton.com

Middle East & Africa
 T +971.4.886.4722
 E lmeinfo@leviton.com

South Korea
 T +82.2.3273.9963
 E infokorea@leviton.com