

45 x 45 mm Fiber Faceplate Modules

APPLICATION

Leviton Fiber Faceplate Modules have been designed around the existing Euro-style (45 x 45 mm) faceplate. The product has been designed for use in installation poles, wall trunking, and back boxes. Suitable for Euro-style faceplates and when used in conjunction with adapter (MMCADCUNI4517) compatible with UK-style (50 x 50 mm) faceplates.



FEATURES & BENEFITS

- Available in LC, SC, single-mode, and multimode
- Identification label with clear protective cover
- Ergonomic, rigid, and robust design
- Shuttered fiber adapters
- Snap-in color icons for ease of identification
- Fully recyclable plastics used

MECHANICAL SPECIFICATIONS

Dimensions:	See page 2
Materials:	Flame Retardant ABS Clear polycarbonate Flame retardant PBT Packaging: fully recyclable card
Temp. (Operating):	-10 °C to +60 °C (-0 °F to +0 °F)
Temp. (Storage):	+40 °C to +70 °C (+40 °F to +158 °F)
Humidity (Max.):	93% relative humidity, non-condensing

WARRANTY INFORMATION


For Leviton product warranties, go to Leviton.com/ns/warranty

FPCANGxxM3

PRODUCT SPECIFICATIONS

FPCANGxxM3

FPCANGxxM3

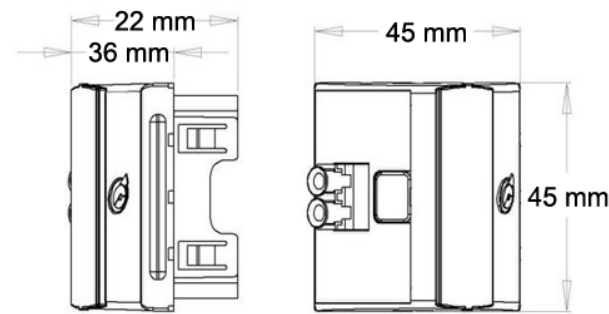

PORT IDENTIFICATION LABELS	
Color	RAL No.
Signal Blue	RAL5005
Traffic Green	RAL6024
Traffic Yellow	RAL1023
Traffic Red	RAL3020

PART NUMBER		
Description	Nominal Weight per Item	Part No.
45 x 45 mm Fiber Faceplate Module, LC quad multimode, white, 10 per pack	20g	FPCANGL4MM3
45 x 45 mm Fiber Faceplate Module, LC duplex multimode, white, 10 per pack	20g	FPCANGLCMM3
45 x 45 mm Fiber Faceplate Module, LC quad single-mode, white, 10 per pack	20g	FPCANGL4SM3
45 x 45 mm Fiber Faceplate Module, LC duplex single-mode, white, 10 per pack	20g	FPCANGLCSM3
45 x 45 mm Fiber Faceplate Module, SC duplex multimode, white, 10 per pack	20g	FPCANGDCMM3
45 x 45 mm Fiber Faceplate Module, SC duplex single-mode, white, 10 per pack	20g	FPCANGDCSM3

For further support information, visit [Leviton.com/ns/support](https://leviton.com/ns/support)