
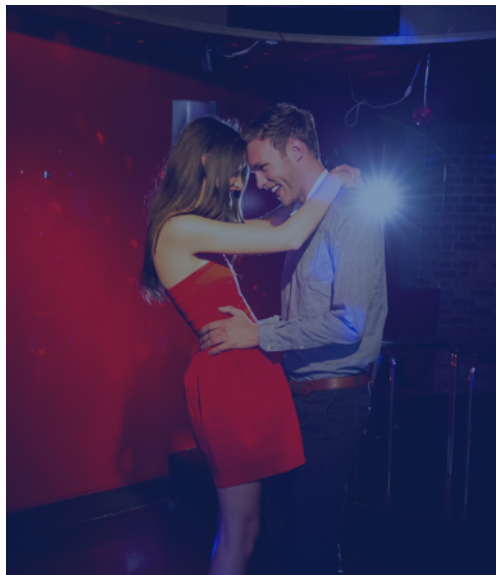


# LEVITON

AFFORDABLE  
ENTERTAINMENT  
SOLUTIONS FOR  
HOME AND BUSINESS

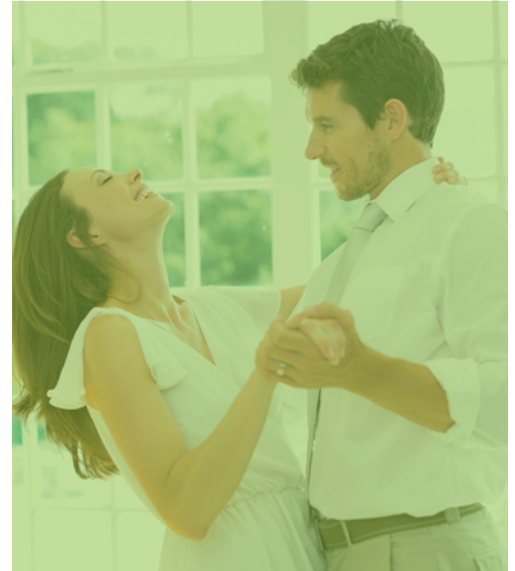

REVOLUTIONARY  
BUILT-IN DISTRIBUTED  
AUDIO SYSTEMS

[www.leviton.com/automation](http://www.leviton.com/automation)



# HI-FI 2 DISTRIBUTED AUDIO SYSTEM SOLUTIONS

The powerful yet compact Hi-Fi 2 plays music from devices you already own (or those you wish to purchase). Installation is simplified with a built-in amplification unit mounted in a structured wiring enclosure.

The Hi-Fi 2 accepts local and remote inputs (in addition to optional Bluetooth), and each room can be controlled with either an in-wall Volume Source Control or a smartphone/tablet for control of power, audio source, volume, bass, treble, balance and more settings. Wiring remains simplified with Remote Input Modules and Volume Source Controls using Cat6 wire.

When installed in conjunction with a Leviton Omni or BitWise automation system, you can have music automated based on time or event. Turn all zones off at a certain time each night, press one button to enact a "party mode" and more.

## THE HI-FI 2 FOUR SOURCE, FOUR ZONE

The Hi-Fi 2 Four Source, Four Zone unit is a compact version of the revolutionary Hi-Fi 2 distributed audio system, ideal for controlling, sharing and listening to audio systems in townhomes, luxury hotel suites, condominiums and small office buildings.



Hi-Fi 2 Four Source, Four Zone (95A00-3)

## FEATURES

Free iOS and Android apps	Super efficient, cool running digital amplification	Two versions (4 rooms; 8 rooms expandable to 16 rooms)
Integrate with Leviton Omni and BitWise Automation Systems	Easy Installation	Optional Bluetooth inputs

This is the most compact 4 zone, 160W system on the market today. Power output is 20W per channel at 8 ohms. It mounts directly into a Leviton Structured Media Center wiring enclosure at half-width. A kit is available with main amplifier, four Volume Source Controls, two Remote Input Modules, a remote control, and a stand-alone free app. Also available in an amplifier-only version. Operating Frequency: 2.402 MHz to 2.480 MHz. Maximum Output Power: +4.54 dBm.

## HI-FI 2 EIGHT SOURCE, EIGHT ZONE

The Hi-Fi 2 Eight Source, Eight Zone kit (expandable to 16 zones total), is the preferred distributed audio system for large residences and small businesses. Power output is 400W system, 25W per channel at 8 ohms, and the main amplifier mounts full-width into a Leviton Structured Media Center wiring enclosure.



Hi-Fi 2 Eight Source, Eight Zone (95A00-2)

A kit is available with main amplifier, eight Volume Source Controls, four Remote Input Modules, a remote control, and a stand-alone free app. The Hi-Fi 2 Eight Zone, Eight Source system is also available in an amplifier-only version, with optional components attached as desired. Operating Frequency: 2.402 MHz to 2.480 MHz. Maximum Output Power: +4.54 dBm.

## MOUNTING INSTALLATION

Hi-Fi 2's main amplification units can be mounted within any Leviton Structured Media Center®. The Hi-Fi 2 Four Source, Four Zone unit mounts half-width in a Leviton SMC and the Hi-Fi 2 Eight Source, Eight Zone unit mounts full-width.



## iOS AND ANDROID APPS

Using a free app, maintain total control over your audio experience by selecting a music source to play in a single room or throughout the entire property. Adjust volume levels throughout, change tracks, power on/off, and more.



Bluetooth Remote Input Module (95A04-2)



## LEVITON ARCHITECTURAL EDITION SPEAKERS

Incorporates the most advanced audio materials, technologies, and precision engineering available. Whatever the application, when the specs call for In-Wall, In-Ceiling, Outdoor, or Home Theater speakers, Leviton Architectural Edition performance is guaranteed to deliver high sound quality and aesthetics.





### LEVITON HI-FI 2 DISTRIBUTED AUDIO SYSTEMS

Description	Part No.
Hi-Fi 2 8 Zone, 8 Source Kit with Enclosure	95A00-1
Hi-Fi 2 8 Zone, 8 Source Kit for Structured Wiring Enclosures	95A00-2
Hi-Fi 2 4 Zone, 4 Source Kit for Structured Wiring Enclosures	95A00-3

### LEVITON HI-FI 2 AMP ONLY

Description	Part No.
Hi-Fi 2 8 Zone, 8 Source Amp Only	95A01-1
Hi-Fi 2 4 Zone, 4 Source Amp Only	95A02-3

### LEVITON HI-FI 2 OPTIONAL COMPONENTS

Bluetooth Remote Input Module 95A04-2	95A04-2
Remote Input Module 95A04-1	95A04-1
Volume Source Control 95A03-1	95A03-1
RIM Color Change Kits (Case of 12)	95A10-X
VSC Color Change Kits (Case of 12)	95A11-X
Hi-Fi 2 8 Zone Expansion Amplifier Kit with Enclosure	95A12-1
Hi-Fi 2 8 Zone Expansion Amplifier Kit for Structured Wiring Enclosures	95A12-2
BRIM Color Change Kit (Sold Individually)	94A15-X
Hi-Fi 2 Expansion Amplifier Assembly w/Power Supply	95A18-1

### LEVITON ARCHITECTURAL EDITION IN-WALL AND IN-CEILING SPEAKERS

Description	Part No.
Dual 5 1/4" Two-Way In-Wall Center Channel Loudspeaker	LAE5I-000
6.5" In-Ceiling Two-Channel Stereo Speaker, 80 Watts, 8 Ohms	LAE6D-000
6.5" In-Ceiling Speaker, 80 Watts, 8 Ohms	LAE6C-000
Pre-Construction Bracket for LAE6C and LAE6D	PCC55-KIT
Fire-Rated Back-Box Enclosure for use with the LAE6C and LAE6D	AEBC6-000
8" In-Ceiling Speaker, 100 Watts, 8 Ohms	LAE8C-000
Pre-Construction Bracket for LAE8C	AEPC8-KIT
8" In-Wall Speaker, 80 Watts, 8 Ohms	LAE8I-000
Pre-Construction Bracket for LAE8I	AEPI8-KIT
6.5" In-Wall Speaker, 80 Watts, 8 Ohms	LAE6I-000
Pre-Construction Bracket for LAE6I	AEPI6-KIT

### LEVITON ARCHITECTURAL EDITION OUTDOOR SPEAKERS

Description	Part No.
Pair of Leviton Architectural Edition Powered by JBL Indoor/Outdoor All Weather Speakers	LAEAW-000

### LEVITON ARCHITECTURAL EDITION HOME THEATER SPEAKERS

Description	Part No.
Cinema SB250 Bluetooth Soundbar with Wireless Subwoofer	LAESB-000
Two-Way Dual Channel 5 1/2" Shelf-Mounted Center Channel Loudspeaker	LAE5S-000
100 Watt RMS, 200 Watt Dynamic Powered Subwoofer	LAESW-000

### SPEC-GRADE SOUND IN-WALL/IN-CEILING INDOOR SPEAKERS

Description	Part No.
Pair of 6.5" Spec-Grade Two-Way In-Ceiling Loudspeakers 120 peak/60W RMS, 8 Ohms	SGC65-00W
Pair of 6.5" Spec-Grade Two-Way In-Wall Loudspeakers 120 peak/60W RMS, 8 Ohms	SGI65-00W