


Lever Edge™

Residential Switches and Receptacles

The Future of Wiring

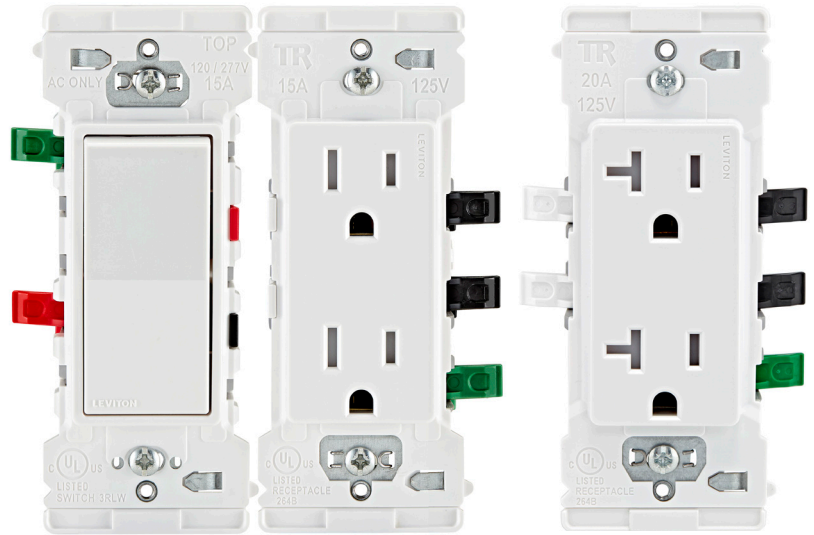

Leviton's **Lever Edge** wiring devices provide the classic appearance and superior performance of Decora® devices in a new, **easy-to-install** design. In addition to the Single Pole Switch, 3-Way Switch, and Tamper-Resistant Duplex Receptacles, the residential line includes tamper-resistant and weather-resistant GFCIs and a Dimmer. Innovative installation features make **Lever Edge** ideal for larger scope jobs, new home construction and MDU projects as well as retrofit applications.


Installers using **Lever Edge** will experience an installation process as unique as it is practical. The color-coded levers provide the foundation for quick installation by helping to rapidly identify the correct terminal for wiring, including a lever terminal for the ground wire. The lever system assures a positive connection has been made. This patented system has a snap feature with an audible 'click' so installers can be confident with every termination.

Applications


Living/Family Rooms, Bedrooms, Kitchens, Bathrooms, Home Offices, Hallways and Basements. The 20A model is ideal for offices, retail space and workshops where equipment requires more power.

Features and Benefits


- Color-coded lever terminals for fast, efficient wiring; reduces risk of miswiring
- Strap's unique tongue and groove alignment feature offers quicker trim out on multi-gang installations
- Lever doors have snap feature to assure connection has been made; audible click confirms lever door is closed
- No exposed metal parts for enhanced safety; eliminates need for electrical tape
- 15 Amp lever connectors work with 14 gauge and 12 gauge stranded and solid copper wire, 20 Amp works with 12 gauge and 10 gauge
- Wire openings prevent wire insulation from being inserted into the terminals
- One standard strip gauge for all devices
- Receptacle allows for split circuit usage
- Easily accessible test openings for circuit testers on switches
- Design eliminates the need for fiber washers to hold in mounting screws
- Strap works with any sized wallplate
- Devices coordinate seamlessly with other Decora devices
- Can be used with Decora and Decora Plus™ screwless wallplates

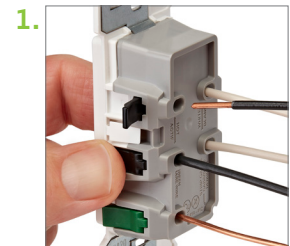

PUSH.
Faster and easier to wire

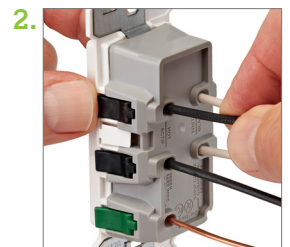

CLICK.
Audible 'click' confirms secure connection

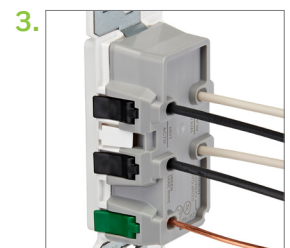

DONE.
Terminate with confidence

Specifications

E5601, Single Pole Switch

E5603, 3-Way Switch

Amperage: 15 A

Body Material: Thermoplastic

Self-Grounding: Yes

HP Rating: 1/2HP-120V 2HP-240V-277V

Max. Amperage: 15 Amp

Strap Material: Plastic and Steel

Termination: Side Lever

Type: Rocker Switch

Voltage: 120/277 VAC

Standards and Certifications:

CSA 22.2 No 111

NOM: NOM Certified

UL 20: File E7458

Warranty: 2-Year Limited

E5325, 15 Amp Duplex Receptacle

Amperage: 15A

NEMA: 5-15R

E5825, 20 Amp Duplex Receptacle

Amperage: 20A

NEMA: 5-20R

Body Material: Thermoplastic

Blade Type: Straight Blade

Feature: Tamper-Resistant

Self-Grounding: Yes

Strap Material: Plastic and Steel

Termination: Side lever

Type: Duplex Receptacle

Voltage: 125 VAC

Standards & Certifications:


CSA C22.2 No. 42: File 152105; Class 6233-01

NOM: NOM Certified


UL 498: File E13399

Warranty: 2-Year Limited

Dimensional Drawings

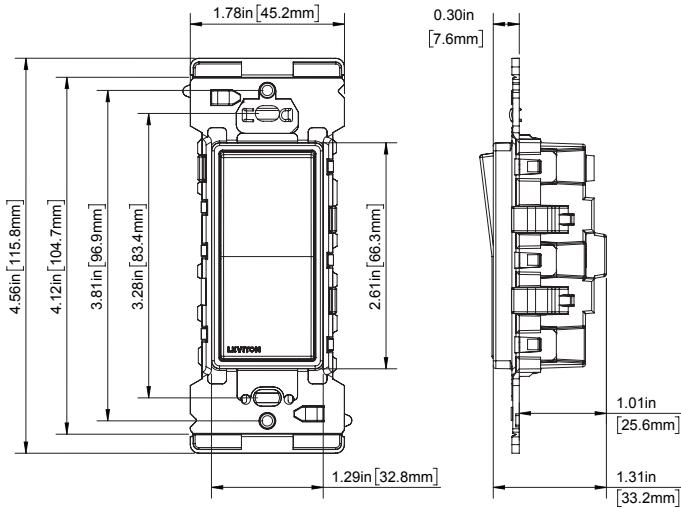

Cat. No. E5601

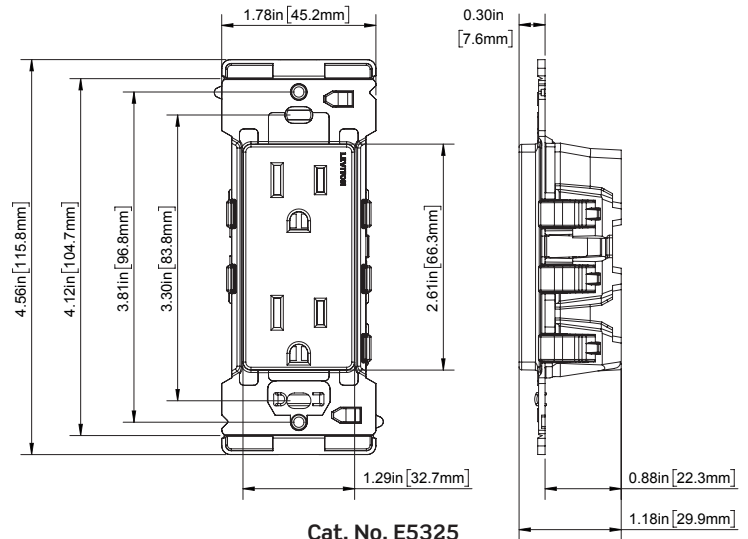

Cat. No. E5325

Ordering Information

Cat. No.	Description	Rating	Color
Switch			
E5601	Single Pole Switch	15 AMP, 120/277V	White
E5603	3-Way Switch	15 AMP, 120/277V	White
Receptacle			
E5325	15 Amp Tamper-Resistant Duplex Receptacle	15 AMP, 125V	White
E5825	20 Amp Tamper-Resistant Duplex Receptacle	20 AMP, 125V	White



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am-5pm EST

For 24/7 product support visit www.leviton.com/support

Visit our Website at: www.leviton.com/leveredge

© 2024 Leviton Manufacturing Co., Inc. All rights reserved.
All trademarks are the property of their respective owners.

